

Twist-Lock® Devices
 50A, 125/250V AC, 3 Pole, 4 Wire Grounding
 Receptacle

HUBBELL

Features

- Thermoset construction offers high heat resistance
- Armored housing provides superior impact resistance
- One piece contacts provide low operating temperatures

Ordering Information

| Description | Device Color | UPC | Catalog Number |
|-------------|--------------|--------------|----------------|
| Phenolic | Black | 783585828107 | CS6369 |

Listings

Listed to UL 498
 Certified to CSA C22.2 No.42

Specifications

| | |
|-----------------|----------|
| Body | Phenolic |
| Face | Phenolic |
| Contacts | Brass |
| Terminal Screws | Steel |
| Insulator | Phenolic |

Performance

Electrical


| | |
|----------------------|--|
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |

Mechanical

| | |
|------------------------|---|
| Terminal Accommodation | #10 AWG - #4 AWG solid or stranded copper wire only |
|------------------------|---|

Environmental

| | |
|------------------------|---|
| Flammability | UL 94 V0 |
| Operating Temperatures | Maximum continuous 75°C; minimum -40°C (w/o impact) |

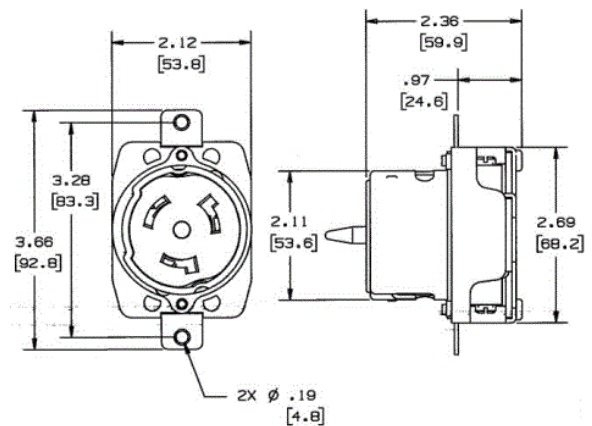

Accessories

| | |
|---------------------------------------|-----------|
| Plug | CS6365C |
| Weatherproof Lift Cover | HBL7774WO |
| Single Gang Stainless Steel Wallplate | SS750 |
| 4" Square Raised Cover | HBL50SC |

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

