

DATE:	LOCATION:
TYPE:	PROJECT:
CATALOG #:	

tradeSELECT®

FEATURES

- 4ft and 8ft lengths
- Switchable CCT, 3500/4000/5000K
- Wide range of applications
- 80+ CRI
- 0–10V dimming
- Surface mount on wall or ceiling
- Universal voltage (120–277V)
- Switchable Lumen Technology



SPECIFICATIONS

OPTICS

- Frosted acrylic lens

INSTALLATION

- Fully assembled for quick installation

ELECTRICAL

- 54,000 hour LEDs at L70 for reduced maintenance

CERTIFICATIONS

- All luminaires are built to UL1598 standards and bear appropriate ETL labels
- Damp location label standard
- DLC® (DesignLights Consortium) Qualified. Please refer to the DLC website for specific product qualifications at www.designlights.org

WARRANTY

- 5 year warranty

ORDERING GUIDE


Catalog No.	UPC	Description	Setting	Lumens			Watts	LPW		
				3500K	4000K	5000K		3500K	4000K	5000K
<input type="checkbox"/> CSL4-LSCS	840141403625	4' LED Striplight, 3800/4500/5200 Switchable Lumens, 3500/4000/5000K Switchable CCT, 0-10V dimming	LOW	4050	4274	4072	30	135	142	136
			MED	4876	5191	4872	38	128	137	128
			HIGH	5402	5770	5405	45	120	128	120
<input type="checkbox"/> CSL8-LSCS	840141403632	8' LED Striplight, 7400/8400/9200 Switchable Lumens, 3500/4000/5000K Switchable CCT, 0-10V dimming	LOW	7387	7771	7404	60	123	130	123
			MED	8283	8664	8257	72	115	120	115
			HIGH	9319	9959	9361	80	116	124	117

Accessories (Order Separately)




- GLH5** 5' adjustable cable for suspension mount

KEY DATA	
Lumen Range	4050–9959
Wattage Range	30–80
Efficacy Range (LPW)	115–142
Reported Life (Hours)	L70/54,000

DIMENSIONS

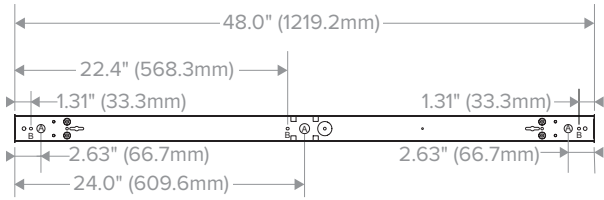

A - 7/8" diameter knockout
B - 5/32" x 1/4" hole

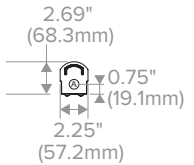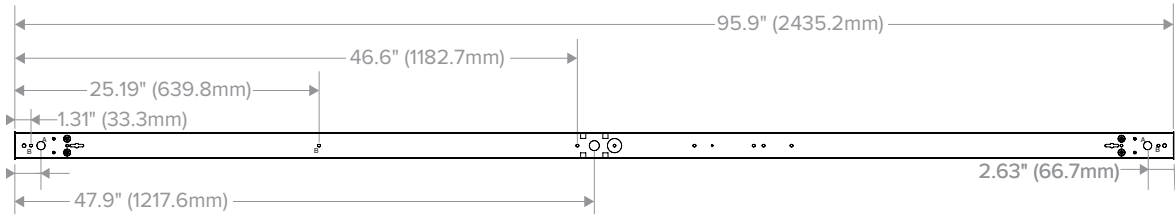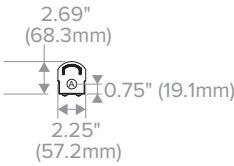

PHOTOMETRY

CSL4-LSCS 4000K 38W

LUMINAIRE DATA

Test No.	EWA-ST048LSCS(38W,4000K)
Description	tradeSELECT® CSL, Striplight
Delivered Lumens	5204
Watts	37.4
Efficacy	139
Spacing Criterion	0° = 1.32 90° = 1.26

ZONAL LUMEN SUMMARY

Zone	Lumens	% Luminaire
0-30	1069	20.5
0-40	1770	34.0
0-60	3241	62.3
0-90	4662	89.6
0-180	5204	100.0

POLAR GRAPH

