

## 3M™ Standard Cable Ties

### 3M™ Miniature Ties (18 lb., 80 N) - Plenum Rated


3M™ Miniature Cable Ties are small lightweight cable ties for use in holding applications up to 18 lb. Ties come in UV-resistant black for outdoor and indoor use as well as natural (white) nylon for an economical solution indoors.

Tensile Strength 18 lb (80 N)  
 Min. Operating Temp. -40°F (-40°C)  
 Max. Operating Temp. 185°F (85°C)  
 Min. Installation Temp. 32°F (0°C)  
 RoHS 2011/65/EU Yes

Agency Approvals



Country of Origin

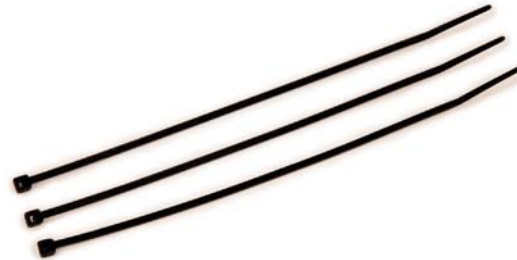

Order No.	UPC	Color	UV Resistance	Length	Width	Thickness	Max. Bundle Dia.	Tensile lbf (N)	Items per Bag (Case)
CT4BK18-C	051128-59273	Black	Yes	4.10" (104 mm)	0.10" (3,0 mm)	0.04" (1,0 mm)	0.75" (19,1 mm)	18 (80)	100 (1000)
CT4BK18-M	051128-59274	Black	Yes	4.10" (104 mm)	0.10" (3,0 mm)	0.04" (1,0 mm)	0.75" (19,1 mm)	18 (80)	1000 (10,000)
CT4NT18-C	051128-59275	Natural	No	4.10" (104 mm)	0.10" (3,0 mm)	0.04" (1,0 mm)	0.75" (19,1 mm)	18 (80)	100 (1000)
CT4NT18-M	051128-59276	Natural	No	4.10" (104 mm)	0.10" (3,0 mm)	0.04" (1,0 mm)	0.75" (19,1 mm)	18 (80)	1000 (10,000)
CT6BK18-C	051128-59277	Black	Yes	6.10" (155 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	1.25" (31,8 mm)	18 (80)	100 (1000)
CT6NT18-C	051128-59278	Natural	No	6.10" (155 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	1.25" (31,8 mm)	18 (80)	100 (1000)
CT6NT18-M	051128-59279	Natural	No	6.10" (155 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	1.25" (31,8 mm)	18 (80)	1000 (10,000)
CT8BK18-C	051128-59280	Black	Yes	8.10" (206 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	2.00" (50,8 mm)	18 (80)	100 (1000)
CT8BK18-M	051128-59281	Black	Yes	8.10" (206 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	2.00" (50,8 mm)	18 (80)	1000 (10,000)
CT8NT18-C	051128-59282	Natural	No	8.10" (206 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	2.00" (50,8 mm)	18 (80)	100 (1000)
CT8NT18-M	051128-59283	Natural	No	8.10" (206 mm)	0.10" (3,0 mm)	0.05" (1,3 mm)	2.00" (50,8 mm)	18 (80)	1000 (10,000)