

Downrods - 1/2" Diameter



Downrod Options 50/50 - Threaded on one end, smooth on the other.

Model Number	Length	Diameter	Finish Option
DR2 (Finish)	2"	1/2"	AB, ABZ, AG, AW, BN, BR, BU, DC, FB, GV, OB, OI, PB, PT, RI, RT, SC, SS, W
DR4 (Finish)	4"	1/2"	AG, AW, BN, BU, CH, DC, HB, OB, OI, RI, SC, SS, W
DR6 (Finish)	6"	1/2"	AB, AG, AO, AW, BN, BR, BS, BU, CH, DC, FB, GV, LB, OB, OI, PB, PR, PT, RI, RT, SC, SS, TS, W
DR8 (Finish)	8"	1/2"	EB, GV, OB
DR12 (Finish)	12"	1/2"	AB, ABZ, AG, AGV, AO, AW, BN, BR, BU, CH, DC, FB, GV, LB, OB, OI, PB, PR, PT, RI, RT, SC, SS, TS, W
DR14 (Finish)	14"	1/2"	ABZ, PR
DR18 (Finish)	18"	1/2"	AB, ABZ, AG, AGV, AO, AW, BN, BR, BU, CH, DC, FB, GV, LB, OB, OI, PB, PR, PT, RI, RT, SC, SS, TS, W
DR24 (Finish)	24"	1/2"	AB, ABZ, AG, AGV, AO, AW, BN, BR, BU, CH, DC, FB, GV, LB, OB, OI, PB, PR, PT, RI, RT, SC, SS, TS, W
DR36 (Finish)	36"	1/2"	AB, ABZ, AG, AGV, AO, AW, BN, BR, BBU, CH, DC, FB, GV, LB, OB, OI, PB, PR, PT, RI, RT, SC, SS, TS, W
DR48 (Finish)	48"	1/2"	AB, ABZ, AG, AGV, AO, AW, BN, BR, BU, CH, DC, FB, GV, OB, OI, PB, PR, PT, RI, RT, SC, SS, TS, W
DR60 (Finish)	60"	1/2"	AB, ABZ, AG, AO, AW, BN, BR, BU, CH, FB, OB, OI, PB, PR, PT, RI, RT, W
DR72 (Finish)	72"	1/2"	AB, ABZ, AG, AO, AW, BN, BR, BU, CH, FB, OB, OI, PB, PR, PT, RI, RT, W



Decorative Downrod Options*

Model Number	Length	Finish Option
DRT12 (Finish)	12"	AG, BU, OB
DRT18 (Finish)	18"	AG, BU, OB
DRT24 (Finish)	24"	AG, BU, OB
DRT36 (Finish)	36"	AG, BU, OB

 
* Ships with Hanging Ball and Matching Flange Cover

Ceiling Fan

FINISH OPTIONS



AB
Antique Brass



ABZ
Aged Bronze
Brushed



AG
Aged Bronze
Textured



AGV
Aged Galvanized



AGVM
Aged Bronze/
Vintage Madera




AO
Athenian Obol



AW
Antique White




AWD
Antique White/
Distressed

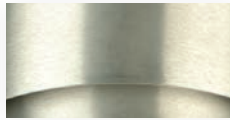


BA
Brushed Aluminum



 
BCW
Biscay Walnut




BN
Brushed Satin Nickel

 

BNK
Brushed Polished Nickel

 


BR
Brown

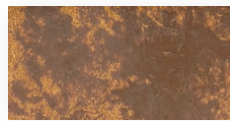

BU
Burnt Sienna




CH
Chrome

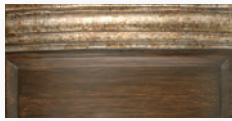

DCVM
Dark Coffee/
Vintage Madera



 ESP
Espresso



FB
Flat Black



 
FW
French White



GV
Galvanized Steel




LB
Legacy Brass



OB
Oiled Bronze



 MWW
Matte White



OBG
Oiled Bronze/
Gilded



 
OBMA
Oiled Bronze/
Mahogany



PB
Polished Brass



PLN
Polished Nickel



PR
Peruvian Bronze




PT
Pewter



RI
Rustic Iron



RT
Rust

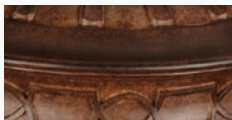


SC
Sedona Clay



SBZ
Spanish Bronze



 SS
Stainless Steel




TI
Titanium



TS
Tarnished Silver



 TW
Textured White



W
White



WP
Weathered Pine