

D-Series LED Floodlights

Stock Solutions

Energy Savings with Style in Stock

The D-Series LED floodlights are the ideal stock solution for distributors looking for super efficient solutions offering the right set of configurations for everyday floodlighting needs. 16 of the most popular configurations are stocked, readily available and offer proven performance from a brand you can trust.

The Configurations You Need

D-Series LED Flood stock solutions offer the key configurations that contractors need for everyday floodlighting. All stock configurations feature a powerful lumen package with a wide flood (6X6) beam pattern in a dark bronze finish. Choose from 4000K or 5000K and a variety of mounting options including adjustable threaded knuckle, adjustable slipfitter or yoke mount.

Energy and Maintenance Savings

Combining up to 84% energy savings with up to 20 years of expected service life makes HID floodlight replacement a “no-brainer” when using D-Series LED floodlights.



DSXF1

DSXF2

DSXF3



Quick Facts:


- Replaces 70W to 400W HID floodlights
- 3,000 lumens to 21,000 lumens
- Super efficient - up to 160 LPW
- All configurations include wide flood optic, 120-277V and dark bronze finish
- Made in North America
- 5-year warranty

D-Series LED Floodlights - Stock Solutions

Luminaire	HID Replacement	Mounting	System Watts	Lumens	LPW	CCT	Part Number	UPC	
DSXF1	70-100W Metal Halide	Threaded Knuckle (1/2" NPT)	21	3,050	145	4000K	DSXF1 LED P1 40K	00190887243321	
						5000K	DSXF1 LED P1 50K	00190887243314	
	150W Metal Halide		4000K	DSXF1 LED P2 40K	00190887243345				
			5000K	DSXF1 LED P2 50K	00190887243338				
DSXF2	175W Metal Halide		4000K	DSXF2 LED P1 40K	00190887243260				
			5000K	DSXF2 LED P1 50K	00190887243253				
	250W Metal Halide		4000K	DSXF2 LED P2 40K	00190887243123				
			5000K	DSXF2 LED P2 50K	00190887243284				
DSXF3	400W Metal Halide	Integral Slipfitter (2-3/8" O.D. tenon)	111	17,450	157	4000K	DSXF3 LED 6 P1 40K IS	00889804560213	
						5000K	DSXF3 LED 6 P1 50K IS	00889804560190	
		Yoke (16-3 SO cord)		17,450	157	4000K	DSXF3 LED 6 P1 40K YKC62	00889804560206	
						5000K	DSXF3 LED 6 P1 50K YKC62	00889804560138	
		Integral Slipfitter (2 3/8" OD tenon)		138	21,000	152	4000K	DSXF3 LED 6 P2 40K IS	00889804560114
							5000K	DSXF3 LED 6 P2 50K IS	00889804560084
		Yoke (16-3 SO cord)			21,000	152	4000K	DSXF3 LED 6 P2 40K YKC62	00889804560107
							5000K	DSXF3 LED 6 P2 50K YKC62	00889804560077

All products listed are standard with MVOLT, wide flood optics and dark bronze finish. If you require a more customized solution, we can quickly ship directly from our factory in Crawfordsville, Indiana.

Product Information

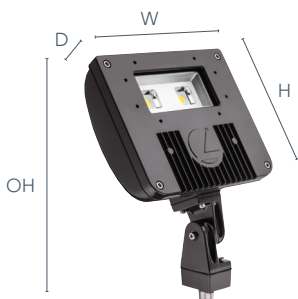

Depth: 3.13" (8.0 cm)
 Width: 8.88" (22.6 cm)
 Height: 7.75" (19.8 cm)
 Overall Height: 12.00" (30.5 cm)
 Weight: 7.2 lbs. (3.3 kg)
 EPA: 0.6 ft² (0.06 m²)

DSXF1 Knuckle for Threaded Pipe



Depth: 3.13" (8.0 cm)
 Width: 12.88" (32.7 cm)
 Height: 7.75" (19.8 cm)
 Overall Height: 12.00" (30.5 cm)
 Weight: 10.5 lbs. (4.8 kg)
 EPA: 0.8 ft² (0.07 m²)

DSXF2 Knuckle for Threaded Pipe



Depth: 4.89" (12.4 cm)
 Width: 12.90" (32.8 cm)
 Height: 13.58" (34.5 cm)
 Overall Height: 16.60" (42.2 cm)
 Weight: 20 lbs. (9.1 kg)
 EPA: 1.4 ft² (0.13 m²)

DSXF3 Yoke with SO Cord



Depth: 4.89" (12.4 cm)
 Width: 12.90" (32.8 cm)
 Height: 13.58" (34.5 cm)
 Overall Height: 20.80" (52.8 cm)
 Weight: 21 lbs. (9.5 kg)
 EPA: 1.4 ft² (0.13 m²)

DSXF3 Integral Slipfitter



DesignLights Consortium® (DLC) Premium qualified product and DLC qualified product. Not all versions of this product may be DLC Premium qualified or DLC qualified. Please check the DLC Qualified Products List at www.designlights.org/QPL to confirm which versions are qualified.

Visit www.lithonia.com for more information