

## DESCRIPTION

White reflector trim in the 6" All-Pro trim family for use in Halo and All-Pro recessed downlighting.

|             |  |      |
|-------------|--|------|
| Catalog #   |  | Type |
| Project     |  |      |
| Comments    |  | Date |
| Prepared by |  |      |

## SPECIFICATION FEATURES

Socket supporting trim, available in high gloss appliance white with white reflector. TS version uses torsion springs to hold trim tight to ceiling.

### Lamp Listings - GU24

|            |                    |
|------------|--------------------|
| H724ICAT   | CF15/R30/GU24      |
| H724ICATL  |                    |
| H724RICAT  | CF13/GU24 (spiral) |
| H724RICATL |                    |

### Lamp Listings - Incandescent

|        |   |
|--------|---|
| ET700  | 85W BR30, 120W BR40, 100W R30, 75W PAR30L, 100W A19 |
| ET700R | 65W BR30, 75W PAR30L                                |

|           |   |
|-----------|---|
| EI700     | 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40 |
| EI700AT   |   |
| EI700ATNB |   |
| EI700NB   |   |
| EI700R    |   |
| EI700RAT  |   |


|          |   |
|----------|---|
| EI700U   | 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40 |
| EI700UAT |   |




**ERT712**  
Gloss White Trim, White Reflector



**ERT712TS**  
Gloss White Trim, White Reflector and Torsion Spring

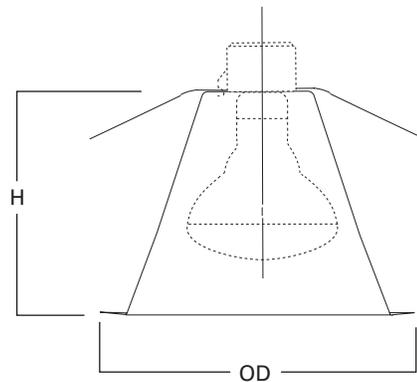

**ERT712**  
Height: 5-3/8" [136mm]  
Outside Diameter: 7-1/4" [184mm]

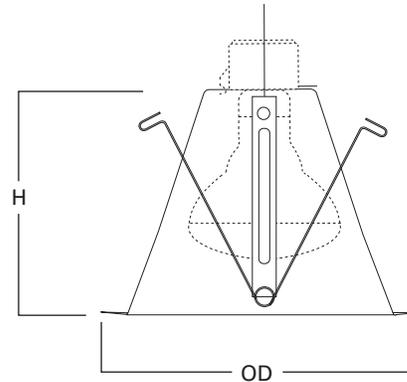

**ERT712TS**  
Height: 5-3/8" [136mm]  
Outside Diameter: 7-1/4" [184mm]

## ERT712

6-Inch White Reflector

## ORDERING INFORMATION

Trim

**ERT712** = 6" High gloss appliance white trim with white reflector  
**ERT712TS** = 6" High gloss appliance white trim with white reflector, torsion spring