

6-INCH INCANDESCENT NEW CONSTRUCTION NON - IC





ET700

**FEATURES**

- All-Nail bar hangers
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated

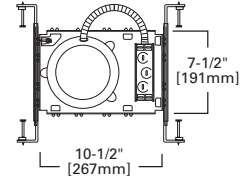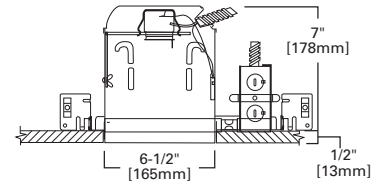

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: ET700 - ERT707WHT

Housing	Trims
ET700=6" Aperture, New Construction, Non-IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT705 Open, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p>ERT706 Open, 65W BR30, 75W R30, 75W PAR30, OD: 8" [203mm]                      ERT706=High Gloss Appliance White Trim</p> <p>ERT707 Metal Baffle, 65W BR30, 75W R30, 75W PAR30, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT709 Large Aperture Metal Baffle, 120W R40, 120W PAR38, OD: 7-1/4" [184mm]                      ERT709=High Gloss Appliance White Trim with Black Baffle                      ERT709WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 75W R30, 75W PAR30, 75W PAR30L, 85W BR30, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT717 Large Aperture Plastic Baffle, 150W PAR38, 120W BR40, 150W R40, OD: 8" [203mm]                      ERT717WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b>                      ERT713 Black Metal Baffle, 75W PAR30L, 85W BR30, 100W R30, 100W A19, 120W BR40, OD: 7-1/4" [184mm]                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 75W A19, 75W PAR30L, 75W PAR30, 85W BR30, 100W R30, 120W BR40, 150W R40, OD: 7-1/4" [184mm]                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 75W PAR30L, 85W BR30, 100W R30, 100W A19, 120W BR40, OD: 7-1/4" [184mm]                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 85W BR30, 90W A19, 100W R30, OD: 7-1/4" [184mm]                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 50W PAR30L, 75W PAR30L, 85W BR30, 90W A19, 100W R30, OD: 7-1/4" [184mm]                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p>
	<p><b>Lenses and Diffusers</b>                      ERT701 Albalite Glass Lens Showerlight, 60W A19, OD: 8" [203mm]                      ERT701=High Gloss Appliance White Trim</p> <p>ERT702 Drop Opal Plastic Lens Showerlight, 60W A19, OD: 8" [203mm]                      ERT702=High Gloss Appliance White Trim with Drop Opal Glass Lens</p> <p>ERT703 Fresnel Glass Lens Showerlight, 60W A19, OD: 8" [203mm]                      ERT703=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>Open</b>                      ERT708 Large Aperture Open, 120W BR40, 150W R40, OD: 8" [203mm]                      ERT708=High Gloss Appliance White Trim</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 65W BR30, 75W R30, 75W PAR30, 150W R40, 150W PAR38, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Regressed Eyeball</b>                      ERT711 Regressed Eyeball, 65W BR30, 75W R30, 75W PAR30, OD: 8" [203mm]                      ERT711=High Gloss Appliance White Trim and Eyeball with Black Baffle</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 60W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 60W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b>                      ERT712 White Reflector, 85W BR30, 120W BR40, 100W R30, 75W PAR30L, 100W A19, OD: 7-1/4" [184mm]                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>

NOTES: <sup>Δ</sup> UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.


6-INCH INCANDESCENT REMODEL NON - IC

**FEATURES**


- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pry-outs and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, IP Rated

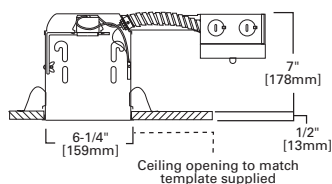

ET700R

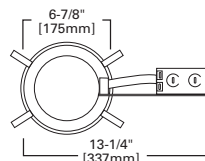

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>A</sup>**

SAMPLE NUMBER: ET700R - ERT707WHT

Housing	Trims
ET700R=6" Aperture, Remodel, Non-IC, 120V Line Voltage	<p><b>Adjustables</b> ERT704 Eyeball, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b> ERT706 Open, 65W R30, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT706=High Gloss Appliance White Trim</p> <p>ERT707 Metal Baffle, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT707=High Gloss Appliance White Trim with Black Baffle ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 75W R30, 75W PAR30L, 85W BR30, OD: 8" [203mm] ERT714=High Gloss Appliance White Trim with Black Baffle ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT717 Large Aperture Plastic Baffle, 150W R40, 120W BR40, OD: 8" [203mm] ERT717WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b> ERT713 Black Metal Baffle, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT713=High Gloss Appliance White Trim with Black Baffle ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 65W BR30, 75W PAR30L, 150W R40, OD: 7-1/4" [184mm] ERT713L=High Gloss Appliance White Trim with Black Baffle ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT713WHT=High Gloss Appliance White Trim with White Baffle ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 85W BR30, 90W A19, 100W R30, OD: 7-1/4" [184mm] ERT725=High Gloss Appliance White Trim with Black Baffle ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 50W PAR30L, 75W PAR30L, 85W BR30, 90W A19, 100W R30, OD: 7-1/4" [184mm] ERT725WHT=High Gloss Appliance White Trim with White Baffle ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p>
	<p><b>Lenses and Diffusers</b> ERT701 Albalite Glass Lens Showerlight, 60W A19, OD: 8" [203mm] ERT701=High Gloss Appliance White Trim</p> <p>ERT702 Drop Opal Plastic Lens Showerlight, 60W A19, OD: 8" [203mm] ERT702=High Gloss Appliance White Trim with Drop Opal Glass Lens</p> <p>ERT703 Fresnel Glass Lens Showerlight, 60W A19, OD: 8" [203mm] ERT703=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>Open</b> ERT708 Large Aperture Open, 120W BR40, 150W R40, OD: 8" [203mm] ERT708=High Gloss Appliance White Trim</p> <p><b>Reflectors</b> ERT710 Specular Reflector, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 150W R40, OD: 7-1/4" [184mm] ERT710=High Gloss Appliance White Trim with Clear Specular Reflector ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b> ERT721 Showerlight with Frosted Glass Lens and Reflector, 60W A19, OD: 8" [203mm] ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 60W A19, OD: 8" [203mm] ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b> ERT712 White Reflector, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT712=High Gloss Appliance White Trim with White Reflector ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>


NOTES: <sup>A</sup> UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT710 Specular Reflector**



ERT710 High Gloss Appliance White Trim with Clear Specular Reflector  
ERT710G High Gloss Appliance White Trim with Gold Reflector

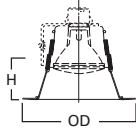



**HOUSING / LAMP:**  
ET700: 65W BR30, 75W R30, 75W PAR30, 150W R40, 150W PAR38  
ET700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 150W R40

**DIMENSIONS:** Height: 2-7/8" [73mm]; OD: 7-1/4" [184mm]

**ERT712 White Reflector**



ERT712TS High Gloss Appliance White Trim with White Reflector, Torsion Spring  
ERT712 High Gloss Appliance White Trim with White Reflector

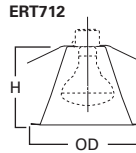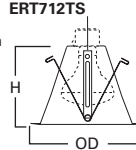


**HOUSING / LAMP:**  
ET700: 85W BR30, 120W BR40, 100W R30, 75W PAR30L, 100W A19  
ET700R: 65W BR30, 75W PAR30L

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT707 Metal Baffle**



ERT707WHT High Gloss Appliance White Trim with White Baffle, Narrow and Wide Trim Rings  
ERT707 High Gloss Appliance White Trim with Black Baffle, Narrow and Wide Trim Rings

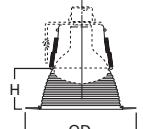


**HOUSING / LAMP:**  
ET700: 65W BR30, 75W R30, 75W PAR30  
ET700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 2-7/8" [73mm]; Wide OD: 8" [203mm]; Narrow OD: 7-1/4" [184mm]

**ERT709 Large Aperture Metal Baffle**



ERT709WHT High Gloss Appliance White Trim with White Baffle, Narrow and Wide Trim Rings  
ERT709 High Gloss Appliance White Trim with Black Baffle, Narrow and Wide Trim Rings

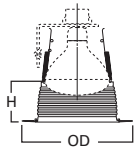



**HOUSING / LAMP:**  
ET700: 120W R40, 120W PAR38

**DIMENSIONS:** Height: 2-5/8" [67mm]; Wide OD: 8" [203mm]; Narrow OD: 7-1/4" [184mm]

**ERT713 Black Metal Baffle**



ERT713 High Gloss Appliance White Trim with Black Baffle  
ERT713TS High Gloss White Trim with Black Baffle Torsion Spring Construction

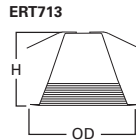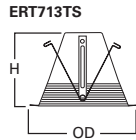



**HOUSING / LAMP:**  
ET700: 75W PAR30L, 85W BR30, 100W R30, 100W A19, 120W BR40  
ET700R: 65W BR30, 75W PAR30L

**DIMENSIONS:** Height: 5" [127mm]; OD: 7-1/4" [184mm]

**ERT713L Black Metal Baffle**



ERT713L High Gloss Appliance White Trim with Black Baffle  
ERT713LTS High Gloss White Trim with Black Baffle Torsion Spring Construction

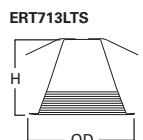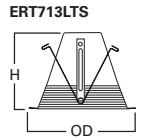



**HOUSING / LAMP:**  
ET700: 75W A19, 75W PAR30L, 75W PAR30, 85W BR30, 100W R30, 120W BR40, 150W R40  
ET700R: 65W BR30, 75W PAR30L, 150W R40

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT713WHT White Metal Baffle**



ERT713WHT High Gloss Appliance White Trim with White Baffle  
ERT713WHTTS High Gloss White Trim with White Baffle Torsion Spring Construction

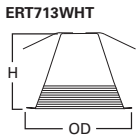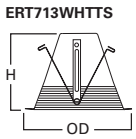


**HOUSING / LAMP:**  
ET700: 75W PAR30L, 85W BR30, 100W R30, 100W A19, 120W BR40  
ET700R: 65W BR30, 75W PAR30L

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT714 Plastic Baffle**



ERT714WHT High Gloss Appliance White Trim with White Baffle  
ERT714 High Gloss Appliance White Trim with Black Baffle

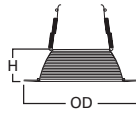


**HOUSING / LAMP:**  
ET700: 75W R30, 75W PAR30, 75W PAR30L, 85W BR30  
ET700R: 75W R30, 75W PAR30L, 85W BR30

**DIMENSIONS:** Height: 2-1/4" [57mm]; OD: 8" [203mm]

**ERT717 Large Aperture Plastic Baffle**



ERT717WHT High Gloss Appliance White Trim and White Baffle

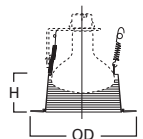


**HOUSING / LAMP:**  
ET700: 150W PAR38, 120W BR40, 150W R40  
ET700R: 150W R40, 120W BR40

**DIMENSIONS:** Height: 2-3/4" [70mm]; OD: 8" [203mm]

**ERT716 Shallow Metal Baffle**



ERT716 High Gloss Appliance White Trim with White Baffle

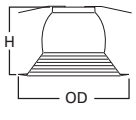


**HOUSING / LAMP:**  
ET700: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
ET700R: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT704 Eyeball**



ERT704 High Gloss Appliance White Trim with White Eyeball

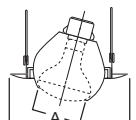


**HOUSING / LAMP:**  
ET700: 75W R30, 75W PAR30, 75W PAR30L  
ET700R: 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

**ERT711 Regressed Eyeball**



ERT711 High Gloss Appliance White Trim and Eyeball with Black Baffle

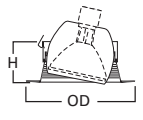

**HOUSING / LAMP:**  
ET700: 65W BR30, 75W R30, 75W PAR30


**DIMENSIONS:** Height: 3" [76mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT706 Open**



ERT706 High Gloss  
Appliance White Trim

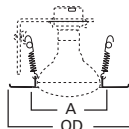

**HOUSING / LAMP:**


ET700: 65W BR30, 75W R30, 75W PAR30  
ET700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-7/8" [98mm]; OD: 8" [203mm]

**ERT708 Large Aperture Open**



ERT708 High Gloss  
Appliance White Trim

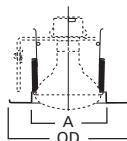

**HOUSING / LAMP:**


ET700: 120W BR40, 150W R40  
ET700R: 120W BR40, 150W R40

**DIMENSIONS:** Height: 5-3/16" [131mm]; OD: 8" [203mm]

**ERT701 Albalite Glass Lens Showerlight**



 ERT701 High Gloss  
Appliance White Trim



**HOUSING / LAMP:**


ET700: 60W A19  
ET700R: 60W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT702 Drop Opal Plastic Lens Showerlight**



ERT702 High Gloss  
Appliance White Trim with  
Drop Opal Lens

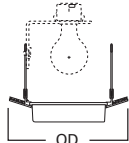

**HOUSING / LAMP:**


ET700: 60W A20  
ET700R: 60W A20

**DIMENSIONS:** OD: 8" [203mm]

**ERT703 Fresnel Glass Lens Showerlight**



ERT703 High Gloss  
Appliance White Trim with  
Fresnel Glass Lens

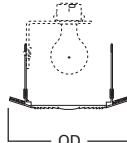

**HOUSING / LAMP:**


ET700: 60W A21  
ET700R: 60W A21

**DIMENSIONS:** OD: 8" [203mm]

**ERT705 Open**



 ERT705 High Gloss  
Appliance White Trim



**HOUSING / LAMP:**


ET700: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-7/8" [98mm]; OD: 8" [203mm]

**ERT721 Showerlight with Frosted Lens and Reflector**



 ERT721 High Gloss  
Appliance White Trim with  
Frosted Glass Lens



**HOUSING / LAMP:**

ET700: 60W A19  
ET700R: 60W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]



**ERT725 Black Metal Baffle/Splay**



ERT725 High Gloss  
Appliance White Trim with  
Black Baffle



ERT725TS High Gloss  
White Trim with Black  
Baffle Torsion Spring  
Construction

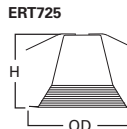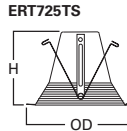

**HOUSING / LAMP:**

ET700: 50W PAR30L, 85W BR30,  
90W A19, 100W R30,  
ET700R: 50W PAR30L, 85W BR30,  
90W A19, 100W R30,

**DIMENSIONS:** Height: 5-3/8" [136mm];  
OD: 7-1/4" [184mm]

 
 
**ERT725WHT White Metal Baffle/Splay**



ERT725WHT High Gloss  
Appliance White Trim with  
White Baffle



ERT725WHTTS High  
Gloss Appliance White  
Trim with White Baffle,  
Torsion Spring



**HOUSING / LAMP:**


ET700: 50W PAR30L, 75W PAR30L,  
85W BR30, 90W A19, 100W R30  
ET700R: 50W PAR30L, 75W PAR30L,  
85W BR30, 90W A19, 100W R30

**DIMENSIONS:** Height: 5-3/8" [136mm];  
OD: 7-1/4" [184mm]

**ERT723 Showerlight with Fresnel Lens and Reflector**



 ERT723 High Gloss  
Appliance White Trim with  
Fresnel Glass Lens



**HOUSING / LAMP:**

ET700: 60W A19  
ET700R: 60W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

6-INCH INCANDESCENT NEW CONSTRUCTION IC





EI700

**FEATURES**

- All-Nail bar hangers
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, IP Rated

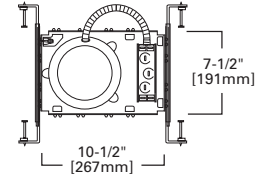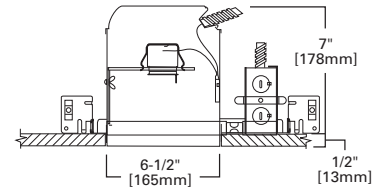

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI700 - ERT707WHT

Housing	Trims
EI700=6" Aperture, New Construction, IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 75W R30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT705 Open, 65 W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p>ERT707 Metal Baffle, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b>                      ERT713 Black Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 75W BR40, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 65W BR30, OD: 7-1/4" [184mm]                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 75W R30, 65W BR30, 50W PAR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Regressed Eyeball</b>                      ERT711 Regressed Eyeball, 50W PAR30, OD: 8" [203mm]                      ERT711=High Gloss Appliance White Trim and Eyeball with Black Baffle</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b>                      ERT712 White Reflector, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40, OD: 7-1/4" [184mm]                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.


6-INCH INCANDESCENT REMODEL IC

**FEATURES**


- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pry-outs and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Insulation Contact

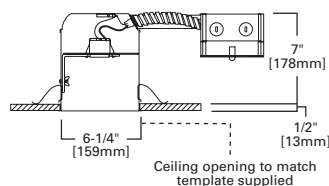

E1700R

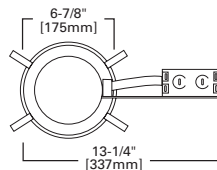

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>A</sup>**

SAMPLE NUMBER: E1700R - ERT707WHT

Housing	Trims
E1700R=6" Aperture, Remodel, IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 75W R30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT705 Open, 65 W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p>ERT707 Metal Baffle, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b>                      ERT713 Black Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 75W BR40, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 65W BR30, OD: 7-1/4" [184mm]                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 75W R30, 65W BR30, 50W PAR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b>                      ERT712 White Reflector, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40, OD: 7-1/4" [184mm]                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>

NOTES: <sup>Δ</sup> Not to be used in direct contact with spray foam insulation. <sup>Δ</sup> UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.



6-INCH INCANDESCENT NEW CONSTRUCTION ICAT





EI700AT

**FEATURES**

- All-Nail bar hangers
- Bar hangers may be shortened for narrow joist spaces
- Quick Connect wiring connectors included in junction box
- NM cable pry-outs and conduit knockouts in junction box
- AIR-TITE™
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

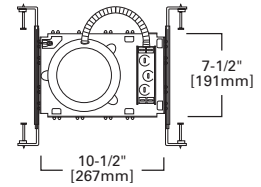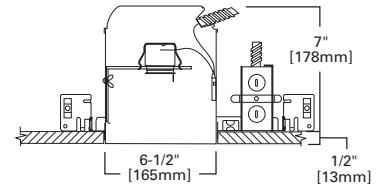

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI700AT - ERT707WHT

Housing	Trims
EI700AT=6" Aperture, New Construction, IC, AIR-TITE™, 120V Line Voltage	<b>Adjustables</b> ERT704 Eyeball, 75W R30, 65W BR30, 75W PAR30L, OD: 8" [203mm] ERT704=High Gloss Appliance White Trim with White Eyeball
	<b>Baffles</b> ERT705 Open, 65 W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT705=High Gloss Appliance White Trim
	ERT707 Metal Baffle, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm] ERT707=High Gloss Appliance White Trim with Black Baffle ERT707WHT=High Gloss Appliance White Trim with White Baffle
	ERT714 Plastic Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 8" [203mm] ERT714=High Gloss Appliance White Trim with Black Baffle ERT714WHT=High Gloss Appliance White Trim with White Baffle
	ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT716=High Gloss Appliance White Trim with White Baffle
	<b>Full Cone Metal Baffle</b> ERT713 Black Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm] ERT713=High Gloss Appliance White Trim with Black Baffle ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction
	ERT713L Black Metal Baffle, 75W BR40, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT713L=High Gloss Appliance White Trim with Black Baffle ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction
	ERT713WHT White Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm] ERT713WHT=High Gloss Appliance White Trim with White Baffle ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction
	ERT725 Black Metal Baffle/Splay, 50W PAR30L, 65W BR30, OD: 7-1/4" [184mm] ERT725=High Gloss Appliance White Trim with Black Baffle ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction
	ERT725WHT White Metal Baffle/Splay, 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT725WHT=High Gloss Appliance White Trim with White Baffle ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction
	<b>Reflectors</b> ERT710 Specular Reflector, 75W R30, 65W BR30, 50W PAR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT710=High Gloss Appliance White Trim with Clear Specular Reflector ERT710G=High Gloss Appliance White Trim with Gold Reflector
	<b>Regressed Eyeball</b> ERT711 Regressed Eyeball, 50W PAR30, OD: 8" [203mm] ERT711=High Gloss Appliance White Trim and Eyeball with Black Baffle
	<b>Showerlight</b> ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm] ERT721=High Gloss Appliance White Trim with Frosted Glass Lens
	ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, OD: 8" [203mm] ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens
	<b>White Cone Reflector</b> ERT712 White Reflector, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40, OD: 7-1/4" [184mm] ERT712=High Gloss Appliance White Trim with White Reflector ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.


6-INCH INCANDESCENT REMODEL ICAT

**FEATURES**


- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pry-outs and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

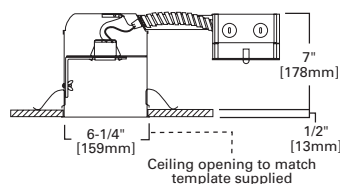

EI700RAT

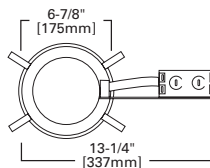

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>A</sup>**

**SAMPLE NUMBER:** EI700RAT - ERT707WHT

Housing	Trims
EI700RAT=6" Aperture, Remodel, IC, AIR-TITE™, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 75W R30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT705 Open, 65 W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p>ERT707 Metal Baffle, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b>                      ERT713 Black Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 75W BR40, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 65W BR30, OD: 7-1/4" [184mm]                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 50W PAR30, 75W PAR30L, 65W BR30, 75W R30, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b>                      ERT712 White Reflector, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40, OD: 7-1/4" [184mm]                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>

**NOTES:** <sup>Δ</sup> Not to be used in direct contact with spray foam insulation. <sup>Δ</sup> UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.



6-INCH INCANDESCENT NEW CONSTRUCTION ICAT





EI700ATNB

**FEATURES**

- All-Nail bar hangers
- Bar hangers may be shortened for narrow joist spaces
- Quick Connect wiring connectors included in junction box
- NM cable pry-outs and conduit knockouts in junction box
- AIR-TITE™
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Thermally protected
- Designed without a socket bracket, for socket supporting trims only

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

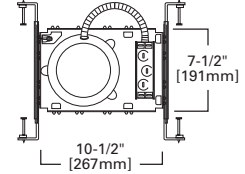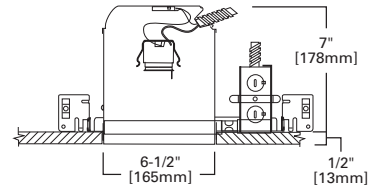

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI700ATNB - ERT713WHT

Housing	Trims
EI700ATNB=6" Aperture, New Construction, IC, AIR-TITE™, 120V Line Voltage, No Socket Bracket	<p><b>Adjustables</b>                      ERT704 Eyeball, 75W R30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT705 Open, 65 W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b>                      ERT713 Black Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 75W BR40, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 65W BR30, OD: 7-1/4" [184mm]                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p><b>Regressed Eyeball</b>                      ERT711 Regressed Eyeball, 65W BR30, 75W R30, OD: 8" [203mm]                      ERT711=High Gloss Appliance White Trim and Eyeball with Black Baffle</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b>                      ERT712 White Reflector, 40W A19, 65W BR30, 75W PAR30, 75W R30, 90W BR40, OD: 7-1/4" [184mm]                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**FEATURES**


- All-Nail bar hangers
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Quick Connect wiring connectors included in junction box
- Housing may be removed from plaster frame for junction box access
- Designed without a socket bracket, for socket supporting trims only
- Die-formed housing and plaster frame
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.


**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact



**6-INCH INCANDESCENT NEW CONSTRUCTION IC**

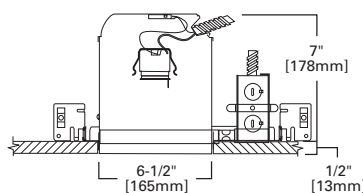

EI700NB

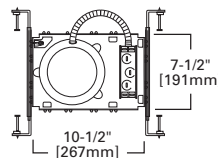

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>A</sup>**

**SAMPLE NUMBER:** EI700NB - ERT713WHT

Housing	Trims
EI700NB=6" Aperture, New Construction, IC, 120V Line Voltage, No-Socket Bracket	<p><b>Adjustables</b>                      ERT704 Eyeball, 75W R30, 65W BR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT705 Open, 65 W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b>                      ERT713 Black Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 75W BR40, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40, OD: 7-1/4" [184mm]                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 50W PAR30L, 65W BR30, OD: 7-1/4" [184mm]                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p><b>Regressed Eyeball</b>                      ERT711 Regressed Eyeball, 65W BR30, 75W R30, OD: 8" [203mm]                      ERT711=High Gloss Appliance White Trim and Eyeball with Black Baffle</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b>                      ERT712 White Reflector, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40, OD: 7-1/4" [184mm]                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>


**NOTES:** Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT710 Specular Reflector**



ERT710 High Gloss Appliance White Trim with Clear Specular Reflector  
ERT710G High Gloss Appliance White Trim with Gold Reflector

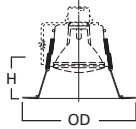

**HOUSING / LAMP:**


EI700: 75W R30, 65W BR30, 50W PAR30, 75W PAR30L  
EI700AT: 75W R30, 65W BR30, 50W PAR30, 75W PAR30L  
EI700R: 50W PAR30, 75W PAR30L, 65W BR30, 75W R30  
EI700RAT: 50W PAR30, 75W PAR30L, 65W BR30, 75W R30

**DIMENSIONS:** Height: 2-7/8" [73mm]; OD: 7-1/4" [184mm]


**ERT712 White Reflector**



ERT712TS High Gloss Appliance White Trim with White Reflector, Torsion Spring  
ERT712 High Gloss Appliance White Trim with White Reflector

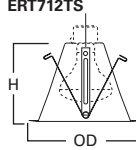

**ERT712**

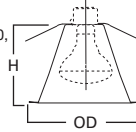

**HOUSING / LAMP:**


EI700: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40  
EI700AT: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40  
EI700ATNB: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40  
EI700NB: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40  
EI700R: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40  
EI700RAT: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 75W R30, 90W BR40

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT707 Metal Baffle**



ERT707WHT High Gloss Appliance White Trim with White Baffle, Narrow and Wide Trim Rings  
ERT707 High Gloss Appliance White Trim with Black Baffle, Narrow and Wide Trim Rings

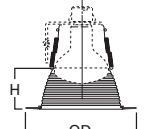

**HOUSING / LAMP:**



EI700: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L  
EI700AT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L  
EI700R: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L  
EI700RAT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L

**DIMENSIONS:** Height: 2-7/8" [73mm]; Wide OD: 8" [203mm]; Narrow OD: 7-1/4" [184mm], Two Trim Rings, Narrow and Wide, Supplied with Trim

**ERT713 Black Metal Baffle**



ERT713 High Gloss Appliance White Trim with Black Baffle  
ERT713TS High Gloss White Trim with Black Baffle Torsion Spring Construction

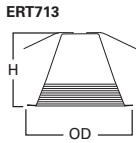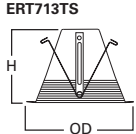

**HOUSING / LAMP:**



EI700: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700AT: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700ATNB: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700NB: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700R: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700RAT: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40

**DIMENSIONS:** Height: 5" [127mm]; OD: 7-1/4" [184mm]

**ERT713L Black Metal Baffle**



ERT713L High Gloss Appliance White Trim with Black Baffle  
ERT713LTS High Gloss White Trim with Black Baffle Torsion Spring Construction

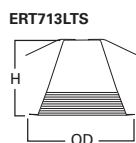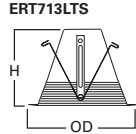

**HOUSING / LAMP:**



EI700: 75W BR40, 65W BR30, 75W PAR30L  
EI700AT: 75W BR40, 65W BR30, 75W PAR30L  
EI700ATNB: 75W BR40, 65W BR30, 75W PAR30L  
EI700NB: 75W BR40, 65W BR30, 75W PAR30L  
EI700R: 75W BR40, 65W BR30, 75W PAR30L  
EI700RAT: 75W BR40, 65W BR30, 75W PAR30L

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT713WHT White Metal Baffle**



ERT713WHT High Gloss Appliance White Trim with White Baffle  
ERT713WHTTS High Gloss White Trim with White Baffle Torsion Spring Construction

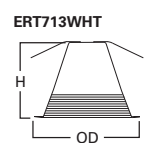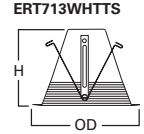

**HOUSING / LAMP:**


EI700: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700AT: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700ATNB: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700NB: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700R: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40  
EI700RAT: 40W A19, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W BR40

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT714 Plastic Baffle**



 ERT714WHT High Gloss Appliance White Trim with White Baffle  
ERT714 High Gloss Appliance White Trim with Black Baffle



**HOUSING / LAMP:**


EI700: 50W PAR30, 65W BR30, 75W PAR30L  
EI700AT: 50W PAR30, 65W BR30, 75W PAR30L  
EI700R: 50W PAR30, 65W BR30, 75W PAR30L  
EI700RAT: 50W PAR30, 65W BR30, 75W PAR30L

**DIMENSIONS:** Height: 2-1/4" [57mm]; OD: 8" [203mm]

**ERT716 Shallow Metal Baffle**



 ERT716WHT High Gloss Appliance White Trim with White Baffle



**HOUSING / LAMP:**


EI700: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
EI700AT: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
EI700ATNB: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
EI700NB: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
EI700R: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
EI700RAT: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT704 Eyeball**



 ERT704 High Gloss Appliance White Trim with White Eyeball



**HOUSING / LAMP:**

EI700: 75W R30, 65W BR30, 75W PAR30L  
EI700AT: 75W R30, 65W BR30, 75W PAR30L  
EI700ATNB: 75W R30, 65W BR30, 75W PAR30L  
EI700NB: 75W R30, 65W BR30, 75W PAR30L  
EI700R: 75W R30, 65W BR30, 75W PAR30L  
EI700RAT: 75W R30, 65W BR30, 75W PAR30L

 
**DIMENSIONS:** Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT711 Regressed Eyeball**



ERT711 High Gloss Appliance White Trim and Eyeball with Black Baffle



**HOUSING / LAMP:**


EI700: 50W PAR30  
EI700AT: 50W PAR30  
EI700ATNB: 65W BR30, 75W R30  
EI700NB: 65W BR30, 75W R30

**DIMENSIONS:** Height: 3" [76mm]; OD: 8" [203mm]

**ERT705 Open**



ERT705 High Gloss Appliance White Trim

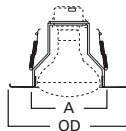

**HOUSING / LAMP:**


EI700: 65W BR30, 75W PAR30, 75W PAR30L  
EI700AT: 65 W BR30, 75W PAR30, 75W PAR30L  
EI700ATNB: 65 W BR30, 75W PAR30, 75W PAR30L  
EI700NB: 65 W BR30, 75W PAR30, 75W PAR30L  
EI700R: 65 W BR30, 75W PAR30, 75W PAR30L  
EI700RAT: 65 W BR30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-7/8" [98mm]; OD: 8" [203mm]

**ERT721 Showerlight with Frosted Lens and Reflector**



 ERT721 High Gloss Appliance White Trim with Frosted Glass Lens



**HOUSING / LAMP:**


EI700: 40W A19  
EI700AT: 40W A19  
EI700ATNB: 40W A19  
EI700NB: 40W A19  
EI700R: 40W A19  
EI700RAT: 40W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]


**ERT725 Black Metal Baffle/Splay**



ERT725 High Gloss Appliance White Trim with Black Baffle

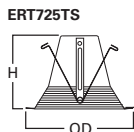

ERT725TS High Gloss White Trim with Black Baffle Torsion Spring Construction

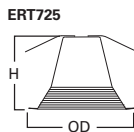

**HOUSING / LAMP:**


EI700: 50W PAR30L, 65W BR30  
EI700AT: 50W PAR30L, 65W BR30  
EI700ATNB: 50W PAR30L, 65W BR30  
EI700NB: 50W PAR30L, 65W BR30  
EI700R: 50W PAR30L, 65W BR30  
EI700RAT: 50W PAR30L, 65W BR30

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]


**ERT725WHT White Metal Baffle/Splay**



ERT725WHT High Gloss Appliance White Trim with White Baffle

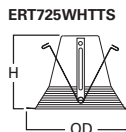

ERT725WHTTS High Gloss Appliance White Trim with White Baffle, Torsion Spring

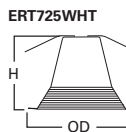

**HOUSING / LAMP:**


EI700: 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L  
EI700AT: 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L  
EI700ATNB: 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L  
EI700NB: 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L  
EI700R: 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L  
EI700RAT: 40W A19, 50W PAR30L, 65W BR30, 75W PAR30L

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT723 Showerlight with Fresnel Lens and Reflector**



 ERT723 High Gloss Appliance White Trim with Fresnel Glass Lens



**HOUSING / LAMP:**

EI700: 40W A19  
EI700AT: 40W A19  
EI700ATNB: 40W A19  
EI700NB: 40W A19  
EI700R: 40W A19  
EI700RAT: 40W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

6-INCH INCANDESCENT NEW CONSTRUCTION IC





EI700U

**FEATURES**

- All-Nail bar hangers
- Quick Connect wiring connectors included in junction box
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact

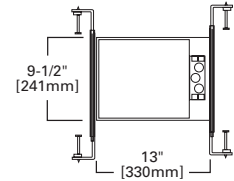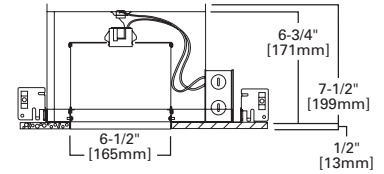

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI700U - ERT707WHT

Housing	Trims
<p><b>EI700U</b>—6" Aperture, New Construction, IC, 120V Line Voltage</p>	<p><b>Adjustables</b>  <b>ERT704 Eyeball, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, OD: 8" [203mm]</b>                      ERT704=High Gloss Appliance White Trim with White Eyeball</p>
	<p><b>Baffles</b>  <b>ERT705 Open, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, OD: 8" [203mm]</b>                      ERT705=High Gloss Appliance White Trim</p>
	<p><b>ERT707 Metal Baffle, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W PAR38, 90W BR40, 100W R40, OD: 7-1/4" [184mm]</b>                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p>
	<p><b>ERT709 Large Aperture Metal Baffle, 90W BR40, OD: 7-1/4" [184mm]</b>                      ERT709=High Gloss Appliance White Trim with Black Baffle                      ERT709WHT=High Gloss Appliance White Trim with White Baffle</p>
	<p><b>ERT714 Plastic Baffle, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]</b>                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p>
	<p><b>Full Cone Metal Baffle</b>  <b>ERT713 Black Metal Baffle, 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40, OD: 7-1/4" [184mm]</b>                      ERT713=High Gloss Appliance White Trim with Black Baffle                      ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p>
	<p><b>ERT713L Black Metal Baffle, 40W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40, OD: 7-1/4" [184mm]</b>                      ERT713L=High Gloss Appliance White Trim with Black Baffle                      ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p>
	<p><b>ERT713WHT White Metal Baffle, 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40, OD: 7-1/4" [184mm]</b>                      ERT713WHT=High Gloss Appliance White Trim with White Baffle                      ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p>
	<p><b>ERT725 Black Metal Baffle/Splay, 40W A19, 75W PAR30L, 85W BR30, 100W R30, OD: 7-1/4" [184mm]</b>                      ERT725=High Gloss Appliance White Trim with Black Baffle                      ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p>
	<p><b>ERT725WHT White Metal Baffle/Splay, 60W A19, 75W PAR30L, 85W BR30, 100W R30, OD: 7-1/4" [184mm]</b>                      ERT725WHT=High Gloss Appliance White Trim with White Baffle                      ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p>
	<p><b>Lenses and Diffusers</b>  <b>ERT701 Albalite Glass Lens Showerlight, 40W A19, OD: 8" [203mm]</b>                      ERT701=High Gloss Appliance White Trim with Albalite Lens</p>
	<p><b>ERT702 Drop Opal Plastic Lens Showerlight, 40W A19, OD: 8" [203mm]</b>                      ERT702=High Gloss Appliance White Trim with Drop Opal Glass Lens</p>
	<p><b>ERT703 Fresnel Glass Lens Showerlight, 40W A19, OD: 8" [203mm]</b>                      ERT703=High Gloss Appliance White Trim with Fresnel Glass Lens</p>
	<p><b>Open</b>  <b>ERT708 Large Aperture Open, 100W R40 (Requires H1999 Socket Extender), OD: 8" [203mm]</b>                      ERT708=High Gloss Appliance White Trim</p>
	<p><b>Reflectors</b>  <b>ERT710 Specular Reflector, 75W PAR30, 75W PAR30L, 85W BR30, 90W BR40, 100W R30, 100W R40, 100W PAR38, OD: 7-1/4" [184mm]</b>                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p>
<p><b>Showerlight</b>  <b>ERT721 Showerlight with Frosted Glass Lens and Reflector, 60W A19, OD: 8" [203mm]</b>                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p>	
<p><b>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 60W A19, OD: 8" [203mm]</b>                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p>	
<p><b>White Cone Reflector</b>  <b>ERT712 White Reflector, 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40, OD: 7-1/4" [184mm]</b>                      ERT712=High Gloss Appliance White Trim with White Reflector                      ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>	

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**FEATURES**


- All-Nail bar hangers
- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.


**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283



**6-INCH INCANDESCENT NEW CONSTRUCTION ICAT**

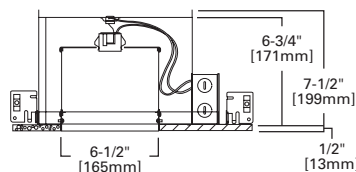

EI700UAT

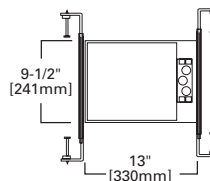

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI700UAT - ERT707WHT

Housing	Trims
EI700UAT=6" Aperture, New Construction, IC AIR-TITE™, 120V Line Voltage	<p><b>Adjustables</b> ERT704 Eyeball, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, OD: 8" [203mm] ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b> ERT705 Open, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, OD: 8" [203mm] ERT705=High Gloss Appliance White Trim</p> <p>ERT707 Metal Baffle, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W PAR38, 90W BR40, 100W R40, OD: 7-1/4" [184mm] ERT707=High Gloss Appliance White Trim with Black Baffle ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT709 Large Aperture Metal Baffle, 90W BR40, OD: 7-1/4" [184mm] ERT709=High Gloss Appliance White Trim with Black Baffle ERT709WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT714=High Gloss Appliance White Trim with Black Baffle ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Full Cone Metal Baffle</b> ERT713 Black Metal Baffle, 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40, OD: 7-1/4" [184mm] ERT713=High Gloss Appliance White Trim with Black Baffle ERT713TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713L Black Metal Baffle, 40W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40, OD: 7-1/4" [184mm] ERT713L=High Gloss Appliance White Trim with Black Baffle ERT713LTS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT713WHT White Metal Baffle, 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40, OD: 7-1/4" [184mm] ERT713WHT=High Gloss Appliance White Trim with White Baffle ERT713WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p>ERT725 Black Metal Baffle/Splay, 40W A19, 75W PAR30L, 85W BR30, 100W R30, OD: 7-1/4" [184mm] ERT725=High Gloss Appliance White Trim with Black Baffle ERT725TS=High Gloss Appliance White Trim with Black Baffle and Torsion Spring Construction</p> <p>ERT725WHT White Metal Baffle/Splay, 60W A19, 75W PAR30L, 85W BR30, 100W R30, OD: 7-1/4" [184mm] ERT725WHT=High Gloss Appliance White Trim with White Baffle ERT725WHTTS=High Gloss Appliance White Trim with White Baffle and Torsion Spring Construction</p> <p><b>Lenses and Diffusers</b> ERT701 Albalite Glass Lens Showerlight, 40W A19, OD: 8" [203mm] ERT701=High Gloss Appliance White Trim with Albalite Lens</p> <p>ERT702 Drop Opal Plastic Lens Showerlight, 40W A19, OD: 8" [203mm] ERT702=High Gloss Appliance White Trim with Drop Opal Glass Lens</p> <p>ERT703 Fresnel Glass Lens Showerlight, 40W A19, OD: 8" [203mm] ERT703=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>Open</b> ERT708 Large Aperture Open, 100W R40 (Requires H1999 Socket Extender), OD: 8" [203mm] ERT708=High Gloss Appliance White Trim</p> <p><b>Reflectors</b> ERT710 Specular Reflector, 75W PAR30, 75W PAR30L, 85W BR30, 90W BR40, 100W R30, 100W R40, 100W PAR38, OD: 7-1/4" [184mm] ERT710=High Gloss Appliance White Trim with Clear Specular Reflector ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b> ERT721 Showerlight with Frosted Glass Lens and Reflector, 60W A19, OD: 8" [203mm] ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 60W A19, OD: 8" [203mm] ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p> <p><b>White Cone Reflector</b> ERT712 White Reflector, 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40, OD: 7-1/4" [184mm] ERT712=High Gloss Appliance White Trim with White Reflector ERT712TS=High Gloss Appliance White Trim with White Reflector and Torsion Spring Construction</p>

NOTES: Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.


Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit www.cooperlighting.com for available options, accessories and ordering information.



**ERT710 Specular Reflector**



ERT710 High Gloss Appliance White Trim with Clear Specular Reflector  
ERT710G High Gloss Appliance White Trim with Gold Reflector

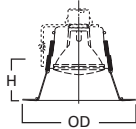

**HOUSING / LAMP:**


EI700U: 75W PAR30, 75W PAR30L, 85W BR30, 90W BR40, 100W R30, 100W R40, 100W PAR38  
EI700UAT: 75W PAR30, 75W PAR30L, 85W BR30, 90W BR40, 100W R30, 100W R40, 100W PAR38

**DIMENSIONS:** Height: 2-7/8" [73mm]; OD: 7-1/4" [184mm]


**ERT712 White Reflector**



ERT712TS High Gloss Appliance White Trim with White Reflector, Torsion Spring  
ERT712 High Gloss Appliance White Trim with White Reflector

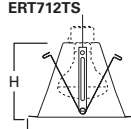

**ERT712**

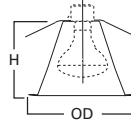

**HOUSING / LAMP:**


EI700U: 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40  
EI700UAT: 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT707 Metal Baffle**



ERT707WHT High Gloss Appliance White Trim with White Baffle, Narrow and Wide Trim Rings  
ERT707 High Gloss Appliance White Trim with Black Baffle, Narrow and Wide Trim Rings

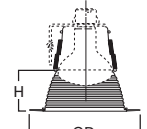

**HOUSING / LAMP:**


EI700U: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W PAR38, 90W BR40, 100W R40  
EI700UAT: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 90W PAR38, 90W BR40, 100W R40

**DIMENSIONS:** Height: 2-7/8" [73mm]; Wide OD: 8" [203mm]; Narrow OD: 7-1/4" [184mm], Two Trim Rings, Narrow and Wide, Supplied with Trim

**ERT709 Large Aperture Metal Baffle**



ERT709WHT High Gloss Appliance White Trim with White Baffle, Narrow and Wide Trim Rings  
ERT709 High Gloss Appliance White Trim with Black Baffle, Narrow and Wide Trim Rings

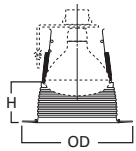

**HOUSING / LAMP:**


EI700U: 90W BR40  
EI700UAT: 90W BR40

**DIMENSIONS:** Height: 2-5/8" [67mm]; Wide OD: 8" [203mm]; Narrow OD: 7-1/4" [184mm], Two Trim Rings, Narrow and Wide, Supplied with Trim


**ERT713 Black Metal Baffle**



ERT713 High Gloss Appliance White Trim with Black Baffle  
ERT713TS High Gloss Appliance White Trim with Black Baffle Torsion Spring Construction

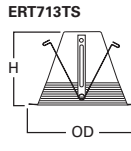

**ERT713**

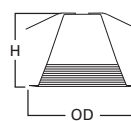

**HOUSING / LAMP:**


EI700U: 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40  
EI700UAT: 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40

**DIMENSIONS:** Height: 5" [127mm]; OD: 7-1/4" [184mm]


**ERT713L Black Metal Baffle**



ERT713L High Gloss Appliance White Trim with Black Baffle  
ERT713LTS High Gloss Appliance White Trim with Black Baffle Torsion Spring Construction

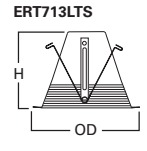

**ERT713LTS**

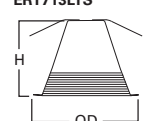

**HOUSING / LAMP:**



EI700U: 40W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40  
EI700UAT: 40W A19, 75W PAR30, 75W PAR30L, 85W BR30, 120W BR40

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT713WHT White Metal Baffle**



ERT713WHT High Gloss Appliance White Trim with White Baffle  
ERT713WHTTS High Gloss Appliance White Trim with White Baffle Torsion Spring Construction

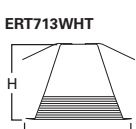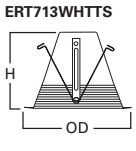

**HOUSING / LAMP:**


EI700U: 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40  
EI700UAT: 60W A19, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, 120W BR40

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT714 Plastic Baffle**



 ERT714WHT High Gloss Appliance White Trim with White Baffle  
ERT714 High Gloss Appliance White Trim with Black Baffle



**HOUSING / LAMP:**


EI700U: 65W BR30, 75W PAR30, 75W PAR30L  
EI700UAT: 65W BR30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 2-1/4" [57mm]; OD: 8" [203mm]


**ERT725 Black Metal Baffle/Splay**



ERT725 High Gloss Appliance White Trim with Black Baffle  
ERT725TS High Gloss Appliance White Trim with Black Baffle Torsion Spring Construction

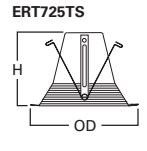

**ERT725**

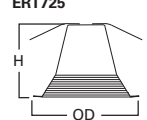

**HOUSING / LAMP:**

EI700U: 40W A19, 75W PAR30L, 85W BR30, 100W R30  
EI700UAT: 40W A19, 75W PAR30L, 85W BR30, 100W R30

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]


Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT725WHT White Metal Baffle/Splay**




ERT725WHT High Gloss Appliance White Trim with White Baffle

ERT725WHTTS High Gloss Appliance White Trim with White Baffle, Torsion Spring

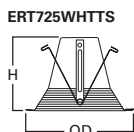

**ERT725WHT**

 

**HOUSING / LAMP:**


EI700U: 60W A19, 75W PAR30L, 85W BR30, 100W R30  
EI700UAT: 60W A19, 75W PAR30L, 85W BR30, 100W R30

**DIMENSIONS:** Height: 5-3/8" [136mm]; OD: 7-1/4" [184mm]

**ERT704 Eyeball**



ERT704 High Gloss Appliance White Trim with White Eyeball

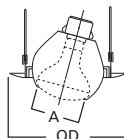

**HOUSING / LAMP:**


EI700U: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30  
EI700UAT: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30

**DIMENSIONS:** Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

**ERT705 Open**



ERT705 High Gloss Appliance White Trim

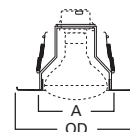

**HOUSING / LAMP:**


EI700U: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30  
EI700UAT: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30

**DIMENSIONS:** Aperture: 3-7/8" [98mm]; OD: 8" [203mm]

**ERT708 Large Aperture Open**



ERT708 High Gloss Appliance White Trim

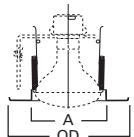

**HOUSING / LAMP:**


EI700U: 100W R40  
(Requires H1999 Socket Extender)  
EI700UAT: 100W R40 (Requires H1999 Socket Extender)

**DIMENSIONS:** Height: 5-3/16" [131mm]; OD: 8" [203mm]

**ERT701 Albalite Glass Lens Showerlight**



 ERT701 High Gloss Appliance White Trim with Albalite Glass Lens



**HOUSING / LAMP:**


EI700U: 40W A19  
EI700UAT: 40W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT702 Drop Opal Plastic Lens Showerlight**



ERT702 High Gloss Appliance White Trim with Drop Opal Lens

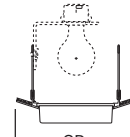

**HOUSING / LAMP:**


EI700U: 40W A19  
EI700UAT: 40W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT703 Fresnel Glass Lens Showerlight**



ERT703 High Gloss Appliance White Trim with Fresnel Glass Lens

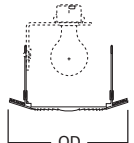

**HOUSING / LAMP:**


EI700U: 40W A19  
EI700UAT: 40W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT721 Showerlight with Frosted Lens and Reflector**



 ERT721 High Gloss Appliance White Trim with Frosted Glass Lens



**HOUSING / LAMP:**

EI700U: 60W A19  
EI700UAT: 60W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT723 Showerlight with Fresnel Lens and Reflector**



ERT723 High Gloss Appliance White Trim with Fresnel Glass Lens



**HOUSING / LAMP:**

EI700U: 60W A19  
EI700UAT: 60W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

6-INCH INCANDESCENT SHALLOW NEW CONSTRUCTION HOUSING IC





EI2700

**FEATURES**

- All-Nail bar hangers
- Quick Connect wiring connectors included in junction box
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Shallow ceiling housing
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact

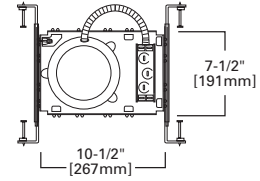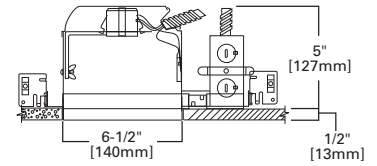

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI2700 - ERT707WHT

Housing	Trims
EI2700=6" Aperture, Shallow Ceiling, New Construction, IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 65W BR30, 75W R30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT707 Metal Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 65W BR30, 50W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Open</b>                      ERT705 Open, 50W PAR30L, 60W BR30, 75W PAR30, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 35W PAR30L, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 35W PAR30L, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p>

**NOTES:** Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**FEATURES**


- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pry-outs and conduit knockouts in junction box

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Insulation Contact



**6-INCH INCANDESCENT SHALLOW REMODEL HOUSING IC**

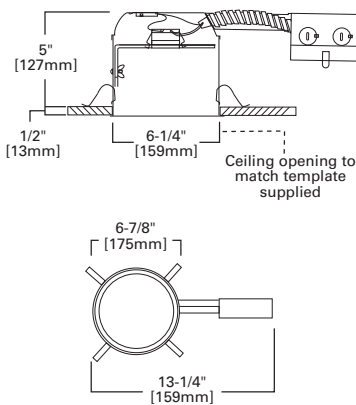

EI2700R

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

**SAMPLE NUMBER:** EI2700R - ERT707WHT

Housing	Trims
EI2700R=6" Aperture, Shallow Ceiling, Remodel, IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 65W BR30, 75W R30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT707 Metal Baffle, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 60W BR30, 50W PAR30, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Open</b>                      ERT705 Open, 50W PAR30L, 60W BR30, 75W PAR30, OD: 8" [203mm]                      ERT705=High Gloss Appliance White Trim</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Frosted Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 40W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p>

**NOTES:** Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

6-INCH INCANDESCENT SHALLOW NEW CONSTRUCTION HOUSING ICAT





EI2700AT

**FEATURES**

- All-Nail bar hangers
- Quick Connect wiring connectors included in junction box
- AIR-TITE™
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, UL/cUL Listed for Insulation Contact, AIR-TITE™ Certified ASTM E283

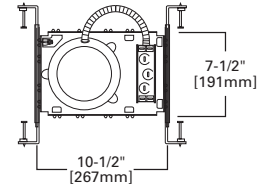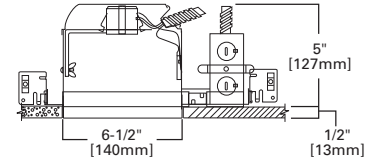

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: EI2700AT - ERT707WHT

Housing	Trims
EI2700AT=6" Aperture, Shallow Ceiling, New Construction, IC AIR-TITE™, 120V Line Voltage	<p><b>Adjustables</b> ERT704 Eyeball, 65W BR30, 75W R30, 75W PAR30L, OD: 8" [203mm] ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b> ERT707 Metal Baffle, 50W PAR30, 65W BR30, 75W PAR30L, OD: 7-1/4" [184mm] ERT707=High Gloss Appliance White Trim with Black Baffle ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 65W BR30, 50W PAR30, 75W PAR30L, OD: 8" [203mm] ERT714=High Gloss Appliance White Trim with Black Baffle ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm] ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Open</b> ERT705 Open, 50W PAR30L, 60W BR30, 75W PAR30, OD: 8" [203mm] ERT705=High Gloss Appliance White Trim</p> <p><b>Reflectors</b> ERT710 Specular Reflector, 50W PAR30, 65W BR30, 75W R30, 75W PAR30L, OD: 7-1/4" [184mm] ERT710=High Gloss Appliance White Trim with Clear Specular Reflector ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b> ERT721 Showerlight with Frosted Glass Lens and Reflector, 35W PAR30L, OD: 8" [203mm] ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 35W PAR30L, OD: 8" [203mm] ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p>

**NOTES:** Δ Not to be used in direct contact with spray foam insulation. Δ UL/cUL Listed for Wet Location with select trims.


Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT710 Specular Reflector**



ERT710 High Gloss  
Appliance White Trim with  
Clear Specular Reflector

ERT710G High Gloss  
Appliance White Trim with  
Gold Reflector

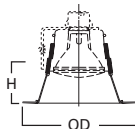

**HOUSING / LAMP:**

EI2700: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L  
EI2700AT: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L  
EI2700R: 50W PAR30, 65W BR30, 75W R30, 75W PAR30L


**DIMENSIONS:** Height: 2-7/8" [73mm]; OD: 7-1/4" [184mm]

**ERT707 Metal Baffle**



ERT707WHT High Gloss  
Appliance White Trim with  
White Baffle, Narrow and  
Wide Trim Rings

ERT707 High Gloss  
Appliance White Trim with  
Black Baffle, Narrow and  
Wide Trim Rings

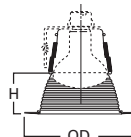

**HOUSING / LAMP:**

EI2700: 50W PAR30, 65W BR30, 75W PAR30L  
EI2700AT: 50W PAR30, 65W BR30, 75W PAR30L  
EI2700R: 65W BR30, 75W PAR30L

 
**DIMENSIONS:** Height: 2-7/8" [73mm]; Wide OD: 8" [203mm];  
Narrow OD: 7-1/4" [184mm], Two Trim Rings,  
Narrow and Wide, Supplied with Trim

**ERT714 Plastic Baffle**



ERT714WHT High Gloss  
Appliance White Trim with  
White Baffle

ERT714 High Gloss  
Appliance White Trim with  
Black Baffle



**HOUSING / LAMP:**


EI2700: 65W BR30, 50W PAR30, 75W PAR30L  
EI2700AT: 65W BR30, 50W PAR30, 75W PAR30L  
EI2700R: 50W PAR30, 60W BR30

**DIMENSIONS:** Height: 2-1/4" [57mm]; OD: 8" [203mm]

**ERT716 Shallow Metal Baffle**



 ERT716WHT High Gloss  
Appliance White Trim with  
White Baffle



**HOUSING / LAMP:**


EI2700: 65W BR30, 75W PAR30, 75W PAR30L  
EI2700AT: 65W BR30, 75W PAR30, 75W PAR30L  
EI2700R: 65W BR30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT704 Eyeball**



ERT704 High Gloss  
Appliance White Trim with  
White Eyeball

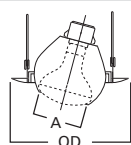

**HOUSING / LAMP:**


EI2700: 65W BR30, 75W R30, 75W PAR30L  
EI2700AT: 65W BR30, 75W R30, 75W PAR30L  
EI2700R: 65W BR30, 75W R30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

**ERT705 Open**



ERT705 High Gloss  
Appliance White Trim

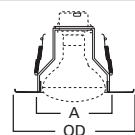

**HOUSING / LAMP:**


EI2700: 50W PAR30L, 60W BR30, 75W PAR30  
EI2700AT: 50W PAR30L, 60W BR30, 75W PAR30  
EI2700R: 60W BR30

**DIMENSIONS:** Aperture: 3-7/8" [98mm]; OD: 8" [203mm]

**ERT721 Showerlight with Frosted Lens and Reflector**



 ERT721 High Gloss  
Appliance White Trim with  
Frosted Glass Lens



**HOUSING / LAMP:**


EI2700: 35W PAR30L  
EI2700AT: 35W PAR30L  
EI2700R: 40W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT723 Showerlight with Fresnel Lens and Reflector**



 ERT723 High Gloss  
Appliance White Trim with  
Fresnel Glass Lens



**HOUSING / LAMP:**

EI2700: 35W PAR30L  
EI2700AT: 35W PAR30L  
EI2700R: 40W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.



6-INCH INCANDESCENT SHALLOW NEW CONSTRUCTION HOUSING NON - IC





ET2700

**FEATURES**

- All-Nail bar hangers
- Quick Connect wiring connectors included in junction box
- Bar hangers may be shortened for narrow joist spaces
- NM cable pry-outs and conduit knockouts in junction box
- Die-formed housing and plaster frame
- Housing may be removed from plaster frame for junction box access
- Thermally protected

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.

**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, UL/cUL Listed for Feed Through, IP Rated

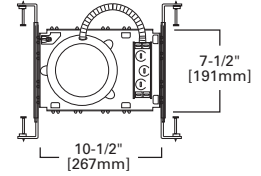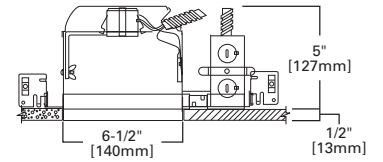

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>Δ</sup>**

SAMPLE NUMBER: ET2700 - ERT707WHT

Housing	Trims
ET2700=6" Aperture, Shallow Ceiling, New Construction, Non-IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT707 Metal Baffle, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 75W R30, 75W PAR30, 85W BR30, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Open</b>                      ERT706 Open, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT706=High Gloss Appliance White Trim</p> <p>ERT708 Large Aperture Open, 120W BR40, 150W R40, OD: 8" [203mm]                      ERT708=High Gloss Appliance White Trim</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 75W PAR30, 75W PAR30L, 85W BR30, 100W R30, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b>                      ERT701 Albalite Glass Lens Showerlight, 60W A19, OD: 8" [203mm]                      ERT701=High Gloss Appliance White Trim with Albalite Lens</p> <p>ERT702 Drop Opal Plastic Lens Showerlight, 60W A19, OD: 8" [203mm]                      ERT702=High Gloss Appliance White Trim with Drop Opal Glass Lens</p> <p>ERT703 Fresnel Glass Lens Showerlight, 60W A19, OD: 8" [203mm]                      ERT703=High Gloss Appliance White Trim with Fresnel Glass Lens</p>

NOTES: Δ UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**FEATURES**


- Quick Connect wiring connectors included in junction box
- Thermally protected
- Die-formed housing
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- NM cable pry-outs and conduit knockouts in junction box
- Shallow ceiling housing

Compliances may not apply to all product configurations. Please consult the product spec sheet for compliance details.


**COMPLIANCES:** UL/cUL Listed - Wet Location, UL/cUL Listed - Damp Location, UL/cUL Listed 1598 Luminaire, IP Rated



**6-INCH INCANDESCENT SHALLOW REMODEL HOUSING NON - IC**

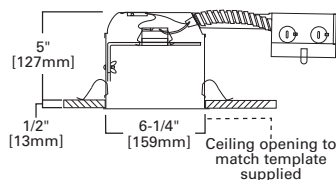

ET2700R

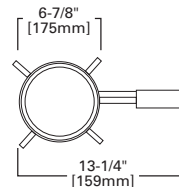

**ORDERING INFORMATION: ORDER HOUSING AND TRIMS SEPARATELY<sup>A</sup>**

**SAMPLE NUMBER:** ET2700R - ERT707WHT

Housing	Trims
ET2700R=6" Aperture, Shallow Housing, Remodel, Non-IC, 120V Line Voltage	<p><b>Adjustables</b>                      ERT704 Eyeball, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT704=High Gloss Appliance White Trim with White Eyeball</p> <p><b>Baffles</b>                      ERT707 Metal Baffle, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 7-1/4" [184mm]                      ERT707=High Gloss Appliance White Trim with Black Baffle                      ERT707WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT714 Plastic Baffle, 75W PAR30, 75W PAR30L, 85W BR30, OD: 8" [203mm]                      ERT714=High Gloss Appliance White Trim with Black Baffle                      ERT714WHT=High Gloss Appliance White Trim with White Baffle</p> <p>ERT716 Shallow Metal Baffle, 40W A19, 65W BR30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT716WHT=High Gloss Appliance White Trim with White Baffle</p> <p><b>Open</b>                      ERT706 Open, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, OD: 8" [203mm]                      ERT706=High Gloss Appliance White Trim</p> <p><b>Reflectors</b>                      ERT710 Specular Reflector, 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 85W BR30, OD: 7-1/4" [184mm]                      ERT710=High Gloss Appliance White Trim with Clear Specular Reflector                      ERT710G=High Gloss Appliance White Trim with Gold Reflector</p> <p><b>Showerlight</b>                      ERT721 Showerlight with Fresnel Glass Lens and Reflector, 60W A19, OD: 8" [203mm]                      ERT721=High Gloss Appliance White Trim with Frosted Glass Lens</p> <p>ERT723 Showerlight with Fresnel Glass Lens and Reflector, 60W A19, OD: 8" [203mm]                      ERT723=High Gloss Appliance White Trim with Fresnel Glass Lens</p>


**NOTES:** <sup>A</sup> UL/cUL Listed for Wet Location with select trims.

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.

**ERT710 Specular Reflector**



ERT710 High Gloss Appliance White Trim with Clear Specular Reflector  
ERT710G High Gloss Appliance White Trim with Gold Reflector

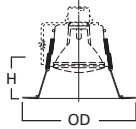


**HOUSING / LAMP:**  
ET2700: 75W PAR30, 75W PAR30L, 85W BR30, 100W R30  
ET2700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L, 85W BR30

**DIMENSIONS:** Height: 2-7/8" [73mm]; OD: 7-1/4" [184mm]

**ERT707 Metal Baffle**



ERT707WHT High Gloss Appliance White Trim with White Baffle, Narrow and Wide Trim Rings  
ERT707 High Gloss Appliance White Trim with Black Baffle, Narrow and Wide Trim Rings

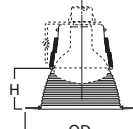


**HOUSING / LAMP:**  
ET2700: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L  
ET2700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 2-7/8" [73mm]; Wide OD: 8" [203mm]; Narrow OD: 7-1/4" [184mm], Two Trim Rings, Narrow and Wide, Supplied with Trim

**ERT714 Plastic Baffle**



 ERT714WHT High Gloss Appliance White Trim with White Baffle  
ERT714 High Gloss Appliance White Trim with Black Baffle




**HOUSING / LAMP:**  
ET2700: 75W R30, 75W PAR30, 85W BR30  
ET2700R: 75W PAR30, 75W PAR30L, 85W BR30

**DIMENSIONS:** Height: 2-1/4" [57mm]; OD: 8" [203mm]

**ERT704 Eyeball**



ERT704 High Gloss Appliance White Trim with White Eyeball

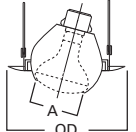


**HOUSING / LAMP:**  
ET2700: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L  
ET2700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-15/16" [100mm]; OD: 8" [203mm]

**ERT716 Shallow Metal Baffle**



ERT716WHT High Gloss Appliance White Trim with White Baffle

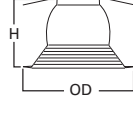


**HOUSING / LAMP:**  
ET2700: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L  
ET2700R: 40W A19, 65W BR30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT706 Open**



ERT706 High Gloss Appliance White Trim

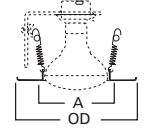


**HOUSING / LAMP:**  
ET2700: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L  
ET2700R: 65W BR30, 75W R30, 75W PAR30, 75W PAR30L

**DIMENSIONS:** Aperture: 3-7/8" [98mm]; OD: 8" [203mm]

**ERT708 Large Aperture Open**



ERT708 High Gloss Appliance White Trim

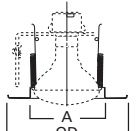


**HOUSING / LAMP:**  
ET2700: 120W BR40, 150W R40

**DIMENSIONS:** Height: 5-3/16" [131mm]; OD: 8" [203mm]

**ERT701 Albalite Glass Lens Showerlight**



ERT701 High Gloss Appliance White Trim

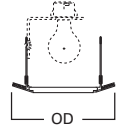


**HOUSING / LAMP:**  
ET2700: 60W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT702 Drop Opal Plastic Lens Showerlight**



ERT702 High Gloss Appliance White Trim with Drop Opal Lens

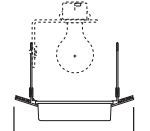


**HOUSING / LAMP:**  
ET2700: 60W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT703 Fresnel Glass Lens Showerlight**



ERT703 High Gloss Appliance White Trim with Fresnel Glass Lens

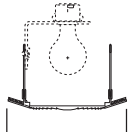


**HOUSING / LAMP:**  
ET2700: 60W A19

**DIMENSIONS:** OD: 8" [203mm]

**ERT721 Showerlight with Frosted Lens and Reflector**



ERT721 High Gloss Appliance White Trim with Frosted Glass Lens

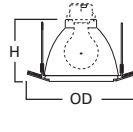


**HOUSING / LAMP:**  
ET2700: 60W A19  
ET2700R: 60W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

**ERT723 Showerlight with Fresnel Lens and Reflector**



ERT723 High Gloss Appliance White Trim with Fresnel Glass Lens

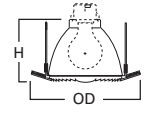

**HOUSING / LAMP:**  
ET2700: 60W A19  
ET2700R: 60W A19

**DIMENSIONS:** Height: 4-1/4" [108mm]; OD: 8" [203mm]

Specifications and dimensions subject to change without notice. Consult your Cooper Lighting Representative or visit [www.cooperlighting.com](http://www.cooperlighting.com) for available options, accessories and ordering information.