



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



EXRM6 Red Led Exit Sign

Lithonia Lighting

Catalog Number	EXRM6
Manufacturer	Lithonia Lighting
Description	
Weight per unit	3.0 (lbs/each)
Product Category	Exit Signs

Features

battery	1.2 volts
Fixture Type	Exit Sign
Lamp Type	LED - Static
Material	THERMOPLASTIC
Number of Lamps	0 lm
pallet quantity	360 kW
Voltage Rating	120/277 VAC
Wattage	2 in

Material, Color, and Finish

Background Color	White
Color	WHITE
housing color	White
Letter Color	RED

Descriptions

Description	RED LED EXIT SIGN
Product Type	Emergency Exit Sign
Special Features	LED lighted exit sign for marking the means of egress in accordance with Life Safety Code NFPA 101.

Manufacturer Information

Brand	LITHONIA LIGHTING
GTIN	00784231874684
Manufacturers Part Number	EXR M6
UPC	784231874684

Taxonomies, Classifications, and Categories

Category Description	Emergency & Exit Lighting
Type	Exit Sign

Packaging

Carton	1
Package	6
Weight Per each	2.95



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

Uses, Certifications, and Standards

Application	Emergency and Safety
Mounting	SURFACE, WALL
standard	UL mA

PRODUCT INFORMATION

EXIT SIGNS



Intended Use
Ideal for applications requiring general-purpose emergency lighting.

Construction
Thermoplastic housing.

Dual voltage 120/277VAC.

LED illuminated exit features low energy consumption.

Fully assembled single-face exit with extra faceplate.

Universal (top, end or back) mounting with canopy included.

Battery back-up models provided with test switch and status indicator for visual and

manual means of monitoring system operation.

One-year warranty.

Listings
UL Listed.


CONTRACTOR
SELECT lightquick **XD**

ORDERING INFORMATION

For additional product information, visit www.lithonia.com.

CATALOG NUMBER	DESCRIPTION	VOLTS	AMPS	WATTS	STANDARD CARTON QTY.
EXR M6	Red	120	.03	3.8	6
EXR M6	Red	277	.02	3.8	6
EXG M6	Green	120	.03	3.8	6
EXG M6	Green	277	.02	3.8	6
EXR EL M6	Red with backup battery	120	.03	3.8	6
EXR EL M6	Red with backup battery	277	.02	3.8	6
EXG EL M6	Green with backup battery	120	.03	3.8	6
EXG EL M6	Green with backup battery	277	.02	3.8	6

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches (centimeters) unless otherwise noted.

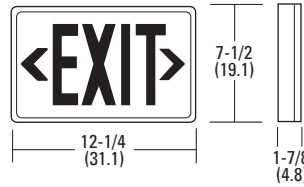

PRODUCT INFORMATION

EXIT-UNIT COMBOS



Intended Use
Ideal for applications requiring general-purpose emergency lighting.

Construction
Thermoplastic housing.

Dual voltage 120/277VAC.

LED illuminated combo sign features low energy consumption.

Fully assembled single-face combo comes with optional extra faceplate.

Top or back mounting capabilities. Canopy provided.

Two 5.4W lamps to provide emergency lighting for 90 minutes, included. High-output option yields 12W extra capacity.

Provided with test switch and status indicator for visual and manual means of monitoring system operation.

One-year warranty.

Listings
UL Listed.

CONTRACTOR
SELECT lightquick **XD**

ORDERING INFORMATION


For additional product information, visit www.lithonia.com.

CATALOG NUMBER	DESCRIPTION	VOLTS	AMPS	WATTS ¹	STANDARD CARTON QTY.
ECR M6	Red	120	.1	5.4	6
ECR M6	Red	277	.05	5.4	6
ECG M6	Green	120	.1	5.4	6
ECG M6	Green	277	.05	5.4	6
ECR HO M6	Red, high output	120	.12	5.4	6
ECR HO M6	Red, high output	277	.06	5.4	6

ACCESSORIES
ORDER SEPARATELY

CATALOG NUMBER	DESCRIPTION	VOLTS	WATTS ¹	STANDARD CARTON QTY.
ELA 6CS M12	Single remote head	6	5.4	12
ELAT 6CS M12	Double remote head	6	5.4	12
ELAT 6CS WP M12	Double remote head, weather proof	6	5.4	12

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches (centimeters) unless otherwise noted.

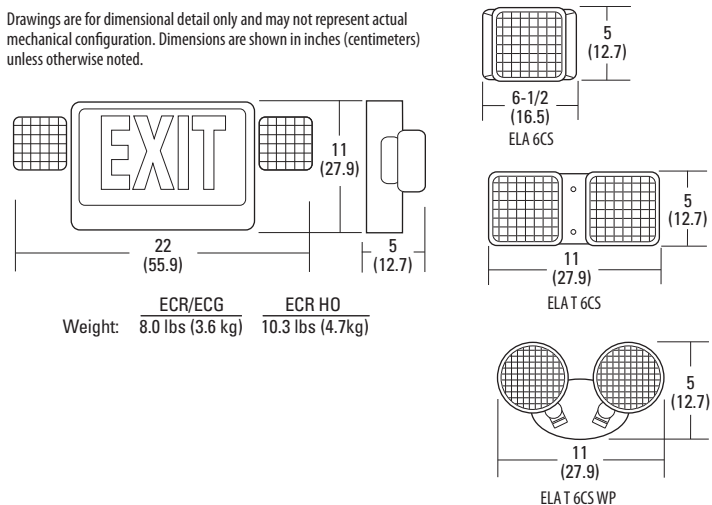

Notes
1 Per lamp head.