

# EZHH150QT

Versatile MH Floodlight with hinged lens frame and Hydroformed reflector. Field adjustable vertical and horizontal lamp positions. 50-150w QT MH. Lamp supplied.

Color: Bronze


Weight: 15.0 lbs

## Lamp Info

Type: ED17  
Watts: 150W  
Shape/Size: N/A  
Base: N/A  
ANSI: N/A  
Hours: 10,000  
Lamp Lumens: 12,500  
Efficacy: 68 LPW

## Ballast Info

Type: CWA-HPF QT  
120V: 1.0/1.6A  
208V: .6/.9A  
240V: .5/.8A  
277V: .5/.7A  
Input Watts: 185W  
Efficiency: 81%

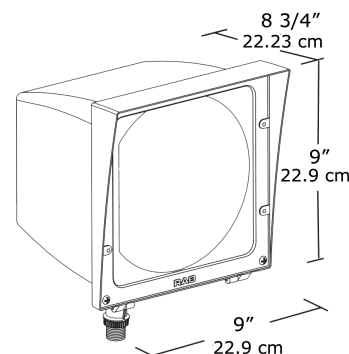

## Technical Specifications

### UL Listing:

Suitable for wet locations. Suitable for mounting within 1.2m (4ft) of the ground.

### Housing:

Precision die cast aluminum. 1/2" NPS threaded arm with locking swivel.

### Reflector:

Hydroformed aluminum. Field adjustable vertical or horizontal.

### Lens Gasket:

High temperature tubular silicone set in die cast retaining groove remains in place during relamping.

### Lens Frame:

Precision die cast aluminum. Hinged for easy access.

### Socket:

Porcelain 4kv Pulse Rated socket with nickel plated screw shell.

### Finish:

Our environmentally friendly polyester powder coatings are formulated for high-durability and long-lasting color, and contains no VOC or toxic heavy metals.

### Ground Mounting:

Use the new MPM19 PVC Mighty Post with aluminum cap for sturdy installation.

### Quad Tap:

Fixture works with 120, 208, 240 and 277 Volts .

### EPA:

0.6

### Patents:

RAB sensor and fixture designs are protected under U.S. and International Intellectual Property laws.



# EZHH150QT

Versatile MH Floodlight with hinged lens frame and Hydroformed reflector. Field adjustable vertical and horizontal lamp positions. 50-150w QT MH. Lamp supplied.

Color: Bronze


Weight: 15.0 lbs

## Lamp Info

Type: ED17  
Watts: 150W  
Shape/Size: N/A  
Base: N/A  
ANSI: N/A  
Hours: 10,000  
Lamp Lumens: 12,500  
Efficacy: 68 LPW

## Ballast Info

Type: CWA-HPF QT  
120V: 1.0/1.6A  
208V: .6/.9A  
240V: .5/.8A  
277V: .5/.7A  
Input Watts: 185W  
Efficiency: 81%

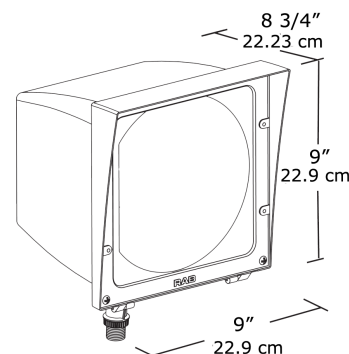

## Technical Specifications

### UL Listing:

Suitable for wet locations. Suitable for mounting within 1.2m (4ft) of the ground.

### Housing:

Precision die cast aluminum. 1/2" NPS threaded arm with locking swivel.

### Reflector:

Hydroformed aluminum. Field adjustable vertical or horizontal.

### Lens Gasket:

High temperature tubular silicone set in die cast retaining groove remains in place during relamping.

### Lens Frame:

Precision die cast aluminum. Hinged for easy access.

### Socket:

Porcelain 4kv Pulse Rated socket with nickel plated screw shell.

### Finish:

Our environmentally friendly polyester powder coatings are formulated for high-durability and long-lasting color, and contains no VOC or toxic heavy metals.

### Ground Mounting:

Use the new MPM19 PVC Mighty Post with aluminum cap for sturdy installation.

### Quad Tap:

Fixture works with 120, 208, 240 and 277 Volts .

### EPA:

0.6

### Patents:

RAB sensor and fixture designs are protected under U.S. and International Intellectual Property laws.

