

EZL-75 Thermal Label Printer and EZL Printer Labels



Quick and cost-effective labeling solution!

EZL-75 Thermal Label Printer

If your labeling needs don't quite justify all the high-end features of T&B's EZL-100 printer, now there's a lower cost solution for simple labeling. The EZL-75 thermal label printer is just as easy to use as the EZL-100 printer. Simply type and print. Or don't even bother typing. Instead, use hot keys to choose among the EZL-75 printer's built-in library of symbols and more than 150 commonly used words for security, location and voice/data/video labeling.



- Hot keys provide one-touch flagging for wires and cables and fixed-length labels for faceplates and security panels
- Incremental alpha and numeric printing makes printing distribution panel labels fast and simple
- 13-character backlit display enhances readability
- Multiple line printing supports up to 2 lines per label
- Durable bumper safeguards against damage in the tool box
- Uses the same label cassettes (up to 1/2" width) as the EZL-100 printer

Specifications

- Dimensions: 4.5" (114mm) W x 7.5" (191mm) H x 2.1" (53mm) D
- Power: 9V DC, using 6 "AA" (not included) batteries or AC adapter
- Weight: 0.8 lbs. (363 grams)

CAT. NO.	DESCRIPTION
EZL-75	Printer (includes (1) 1/2" white nylon quick-load cassette tape, quick start card, and user manual. AC power adapter not included)
EZL-ADP	Adapter for EZL-75 Printer 9V, 1.5A

Surface Applications		Vinyl and Flex Nylon	Perm. Polyester	Heat Shrink
Wire		•		•
Cable		•		•
Curved		•		
Smooth		•	•	
Flat		•	•	
Textured		•	•	
Highly Textured		•		
Length		11.5'	18.0'	5.0"
Width		1/2", 3/4"	3/8", 1/2"	1/4", 3/8"
		3/4"	3/4"	1/2", 3/4"

High-performance labels that last!

Wire Marker Labels for EZL Printers

- Perfect for wire and cable
- Print heat-shrink sleeves on the spot!
- Clear, non-smudging lettering
- Chemical/solvent resistant
- Available in yellow, white, and metallic markers
- Flame retardant, Polyolefin material, 3:1 shrink ratio
- Easy-to-peel, split-back design



Easy barcode printing!

CAT. NO.	LABEL SIZE (IN.)	RECOMMENDED WIRE SIZE (AWG)	LENGTH
Clear Polyester			
EZ-CP12	1/2"	Flat Applications Only	18'
EZ-CP34*	3/4"	Flat Applications Only	18'
Red Vinyl			
EZ-RV34*	3/4"	Any	18'
White Permanent Polyester			
EZ-WP38	3/8"	Flat Applications Only	18'
EZ-WP12	1/2"	Flat Applications Only	18'
EZ-WP34*	3/4"	Flat Applications Only	18'
Metallic Permanent Polyester			
EZ-MP38	3/8"	Flat Applications Only	18'
EZ-MP12	1/2"	Flat Applications Only	18'
EZ-MP34*	3/4"	Flat Applications Only	18'
White Flexible Nylon			
EZ-WN12	1/2"	Any	12.5'
EZ-WN34*	3/4"	Any	12.5'
Yellow Flexible Nylon			
EZ-YN12	1/2"	Any	12.5'
EZ-YN34*	3/4"	Any	12.5'

Heat-Shrink White Polyolefin Labels

EZ-WHS14	1/4"	10 - 16	5'
EZ-WHS38	3/8"	6 - 14	5'
EZ-WHS12	1/2"	4 - 6	5'
EZ-WHS34*	3/4"	2 - 4	5'

Heat-Shrink Yellow Polyolefin Labels

EZ-YHS14	1/4"	10 - 16	5'
EZ-YHS38	3/8"	6 - 14	5'
EZ-YHS12	1/2"	4 - 6	5'
EZ-YHS34*	3/4"	2 - 4	5'

Order in multiples of 5 cassettes.
* Labels fit EZL-100 printer only.

EZL-75 Thermal Label Printer and EZL Printer Labels



Quick and cost-effective labeling solution!

EZL-75 Thermal Label Printer

If your labeling needs don't quite justify all the high-end features of T&B's EZL-100 printer, now there's a lower cost solution for simple labeling. The EZL-75 thermal label printer is just as easy to use as the EZL-100 printer. Simply type and print. Or don't even bother typing. Instead, use hot keys to choose among the EZL-75 printer's built-in library of symbols and more than 150 commonly used words for security, location and voice/data/video labeling.



- Hot keys provide one-touch flagging for wires and cables and fixed-length labels for faceplates and security panels
- Incremental alpha and numeric printing makes printing distribution panel labels fast and simple
- 13-character backlit display enhances readability
- Multiple line printing supports up to 2 lines per label
- Durable bumper safeguards against damage in the tool box
- Uses the same label cassettes (up to 1/2" width) as the EZL-100 printer

Specifications

- Dimensions: 4.5" (114mm) W x 7.5" (191mm) H x 2.1" (53mm) D
- Power: 9V DC, using 6 "AA" (not included) batteries or AC adapter
- Weight: 0.8 lbs. (363 grams)


CAT. NO.	DESCRIPTION
EZL-75	Printer (includes (1) 1/2" white nylon quick-load cassette tape, quick start card, and user manual. AC power adapter not included)
EZL-ADP	Adapter for EZL-75 Printer 9V, 1.5A

Surface Applications		Vinyl and Flex Nylon	Perm. Polyester	Heat Shrink
Wire		•		•
Cable		•		•
Curved		•		
Smooth		•	•	
Flat		•	•	
Textured		•	•	
Highly Textured		•		
Length		11.5'	18.0'	5.0"
Width		1/2", 3/4"	3/8", 1/2"	1/4", 3/8"
		3/4"	3/4"	1/2", 3/4"

High-performance labels that last!

Wire Marker Labels for EZL Printers

- Perfect for wire and cable
- Print heat-shrink sleeves on the spot!
- Clear, non-smudging lettering
- Chemical/solvent resistant
- Available in yellow, white, and metallic markers
- Flame retardant, Polyolefin material, 3:1 shrink ratio
- Easy-to-peel, split-back design

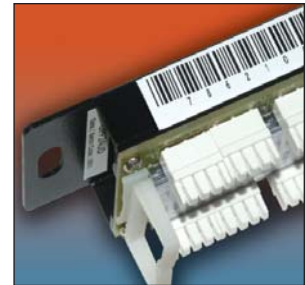

Easy barcode printing!

CAT. NO.	LABEL SIZE (IN.)	RECOMMENDED WIRE SIZE (AWG)	LENGTH
Clear Polyester			
EZ-CP12	1/2"	Flat Applications Only	18'
EZ-CP34*	3/4"	Flat Applications Only	18'
Red Vinyl			
EZ-RV34*	3/4"	Any	18'
White Permanent Polyester			
EZ-WP38	3/8"	Flat Applications Only	18'
EZ-WP12	1/2"	Flat Applications Only	18'
EZ-WP34*	3/4"	Flat Applications Only	18'
Metallic Permanent Polyester			
EZ-MP38	3/8"	Flat Applications Only	18'
EZ-MP12	1/2"	Flat Applications Only	18'
EZ-MP34*	3/4"	Flat Applications Only	18'
White Flexible Nylon			
EZ-WN12	1/2"	Any	12.5'
EZ-WN34*	3/4"	Any	12.5'
Yellow Flexible Nylon			
EZ-YN12	1/2"	Any	12.5'
EZ-YN34*	3/4"	Any	12.5'

Heat-Shrink White Polyolefin Labels

EZ-WHS14	1/4"	10 - 16	5'
EZ-WHS38	3/8"	6 - 14	5'
EZ-WHS12	1/2"	4 - 6	5'
EZ-WHS34*	3/4"	2 - 4	5'

Heat-Shrink Yellow Polyolefin Labels

EZ-YHS14	1/4"	10 - 16	5'
EZ-YHS38	3/8"	6 - 14	5'
EZ-YHS12	1/2"	4 - 6	5'
EZ-YHS34*	3/4"	2 - 4	5'

Order in multiples of 5 cassettes.
* Labels fit EZL-100 printer only.