




GE
Lighting

97571 - F13BX/841/ECO

GE Ecolux® Biax® T4 - Facilities; Retail Display; Hospitality; Office; Restaurant; Warehouse

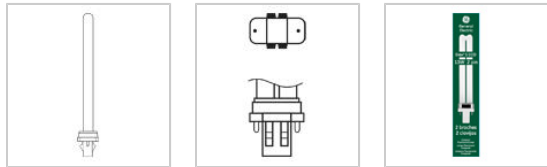

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Remove and install by grasping only plastic portion of the lamp.

NOTES

- Based on 60Hz reference circuit.
- Fluorescent lamp lumens decline during life

GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Plug-In
Bulb	T4
Base	GX23
Equivalent Wattage	60.0 W
Rated Life	10000.0 hrs
Starting Temperature (MIN)	0.0 °C
LEED-EB MR Credit	423 picograms Hg per mean lumen hour
Additional Info	TCLP compliant
Primary Application	Facilities;Retail Display;Hospitality;Office;Restaurant;Warehouse

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	825.0
Mean Lumens	710.0
Nominal Initial Lumens per Watt	63
Color Temperature	4100.0 K
Color Rendering Index (CRI)	82.0

ELECTRICAL CHARACTERISTICS

Wattage	13.0
Voltage	120.0
Lamp Current	0.285 A
Current Crest Factor (MAX)	1.7
Supply Current Frequency	60.0 Hz

DIMENSIONS

Maximum Overall Length (MOL)	7.3000 in(185.4 mm)
Nominal Length	7.000 in(177.8 mm)
Base Face to Top of Lamp	6.690 in(169.9 mm)

PRODUCT INFORMATION

Product Code	97571
Description	F13BX/841/ECO
ANSI Code	60901-IEC-0013-1
Standard Package	BUNDLE
Standard Package GTIN	
Standard Package Quantity	100
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	100
UPC	043168975711