




# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

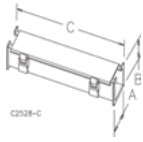

## **F44L60 4X4X60 N12 STRT SCT CLMP HC** *Hoffman Enclosures, Inc.*

Catalog Number	F44L60
Manufacturer	Hoffman Enclosures, Inc.
Description	Straight Section Lay-In Hinged Cover Type 12, 4.00X4.00X60.00, Gray, Steel
Weight per unit	27.0 (lbs/each)
Product Category	20101115153159

### **Features**

ip rating	IP54
Material	MILD STEEL

### **Material, Color, and Finish**

Color	Gray
Color Code	ANSI 61
Finish	Galvanized

### **Dimensions and Weight**

Height	4
Width	4

### **Descriptions**

Description	4X4X60 N12 STRT SCT CLMP HC
extra long description	NVENT HOF F44L60 60.00in Straight S
Features	Lay-in NEMA Type 12 Wireway fittings are used primarily in industrial applications to protect wiring against exposure to oil and other contaminants. This gasketed wireway features quick-release latches for easy access and an opening on one side so wires and cables can be laid in along the entire run without pulling.
Long Description	Straight Section Lay-in Hinged Cover Type 12, 4.00x4.00x60.00, Gray, Steel
Product Type	60.00IN Straight Section

### **Manufacturer Information**

Brand	Nvent Hoffman
GTIN	00783510182908
Manufacturers Part Number	F44L60
UPC	783510182908

### **Taxonomies, Classifications, and Categories**

Category Description	STEEL WIRE WAY JUNCTION BOXES
Type	Straight Section



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

## Packaging

Carton	1
Weight Per each	27

## Uses, Certifications, and Standards

Application	Power Distribution
nema rating	12 Indoor, dust-resistant