


Product Number: 22305

Order Abbreviation: FBO28/841XP/6/SS/ECO

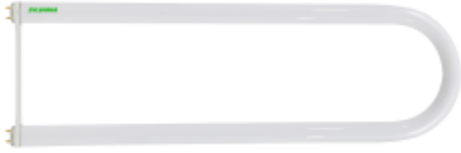

General Description: 28W, 22.5" MOL, T8 OCTORN XP Extended Performance CURVALUME SUPERSAVER fluorescent lamp, 6" leg spacing, 4100K color temperature, rare earth phosphor, 85 CRI, minimum starting voltage of 550V, suitable for instant or programmed rapid start operation, ECOLOGIC

*** Full Case Required**

Product Information

Abbrev. With Packaging Info.	FBO28841XP6SSECO 16/CS 1/SKU
Base	Medium Bipin
Bulb	T8
Color Rendering Index (CRI)	85
Color Temperature/CCT (K)	4100
Family Brand Name	OCTRON® XP® CURVALUME® SUPERSAVER® ECOLOGIC®
Initial Lumens at 25C	2550
Nominal Voltage (V)	120.00
Nominal Wattage (W)	28.00