


# FF42QT

White light in a compact package. Compact Fluorescent 42 watt with quad tap electronic ballast. Operating temperature 0&deg;F. Lamp supplied.

Color: Bronze

Weight: 5.4 lbs

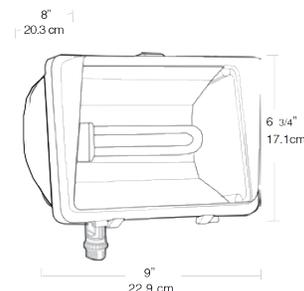

## Lamp Info

Type: 42W Triple  
 Watts: 42W  
 Shape/Size: N/A  
 Base: N/A  
 ANSI: N/A  
 Hours: 12,000  
 Lamp Lumens: 3,200  
 Efficacy: 70 LPW

## Ballast Info

Type: Elec HPF QT  
 120V: 0.38A  
 208V: 0.3A  
 240V: 0.2A  
 277V: 0.17A  
 Input Watts: 46W  
 Efficiency: 91%

## Technical Specifications

### UL Listing:

Suitable for wet locations. Suitable for mounting within 1.2m (4ft) of the ground.

### Sockets:

Porcelain with all copper current carrying components.

### Housing:

Precision die cast aluminum, 1/2" NPS threaded arm with locking swivel fits all standard mounting boxes .

### Reflector:

Anodized semi-specular aluminum.

### Lens:

Thermal tempered shock resistant glass.

### Lens Gasket:

High temperature tubular silicone set in die cast retaining groove remains in place during relamping .

### Socket:

Glazed porcelain 4kv pulse rated with nickel plated screw shell and spring contacts .

### Finish:

Our environmentally friendly polyester powder coatings are formulated for high-durability and long-lasting color, and contains no VOC or toxic heavy metals.

### Quad Tap:

Fixture works with 120, 208, 240 and 277 Volts .

### EPA:

0.43.

### Patents:

Pat. D420,458.

**Ballast Minimum Starting Temperature:**  
 0°F.