

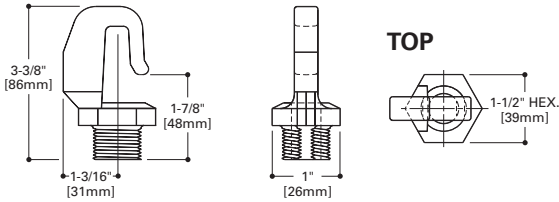
 









F-BAY MOUNTING ACCESSORIES

Mounting Accessories	Designation	Description
Single Point Mount 	HB-SPM = Galvanized Single Monopoint Hanging Kit with Hub (HBI only, supplied separately) HB-SPM-S = Galvanized Surface Mount Hanging Kit with Hub (HBI only, supplied separately)	Suitable for three-quarter inch (3/4") conduit mounting or for use with fixture hook, loop or safety hook. Use chain or cable set to meet NEC requirements for single point mounting, as well as to prevent cantilevering and rotation of fixture from one central location.
	HBL-SPM = Galvanized Single Monopoint Hanging Kit with Hub (HBE and HBL only, supplied separately) HBL-SPM-S = Galvanized Surface Mount Hanging Kit with Hub (HBE and HBL only, supplied separately)	
	I5/I8-SPM = Galvanized Single Monopoint Hanging Kit with Hub (I5 and I8 only, supplied separately)	
Mounting Methods	Designation	Description
Hook and Safety Hook 	FH-1 = Fixture Hook 	Fixture Hook two and one-half inch (2-1/2") (must be used with TCB, HB-SPM or HBL-SPM)
	FL-1 = Fixture Loop 	
Loop 		

Fixture Series	AYC	HB/AYC	SPM/RH-1 FH-1 FL-1	Single Toggle	"Y" Toggle	Loop Hanger
HBI		X	X		X	
HBE		X	X		X	
HBL		X	X		X	
I5	X		X	X		X
I8	X		X	X		X
ABI		X	X		X	
MBF	X			X	X ³	
VT1						X
VT4					X	

NOTES: 3. Continuous row mount only between fixtures.

F-BAY MOUNTING METHODS

Mounting Methods	Designation	Description
	<p>HBAYC-CHAIN/SET-U= Hook style mounting chain set for HBI, HBE, HBL and ABI</p>	<p>Two (2) Hook style V-hangers, thirty-six Inch (36") Chain Sets with S-hooks</p>
<p>"Y" Toggle</p> 	<p>Y-Toggle-10= Mounting Toggle and Ten Foot (10') Cable</p>	<p>Ten Foot (10'), Y Toggle #2 Cable</p>
	<p>Y-Toggle-25= Mounting Toggle and Twenty-five Foot (25') Cable</p>	<p>Twenty-Five Foot (25'), Y Toggle #2 Cable</p>
<p>Loop Hanger</p>  	<p>Loop-10</p>	<p>Ten Foot (10') Loop Hanger #2 Cable</p>
	<p>Loop-30</p>	<p>Thirty Foot (30') Loop Hanger #2 Cable</p>
<p>Single Toggle</p>  	<p>Toggle-10</p>	<p>Ten Foot (10') Single Toggle #2 Cable</p>
	<p>Toggle-30</p>	<p>Thirty Foot (30') Single Toggle #2 Cable</p>