

ADJUSTABLE FLOOR BOX KITS



with a Variety of Metal & Plastic Covers **Arlington**



EASY RECEPTACLE INSTALLATION IN FLOOR HEIGHTS UP TO 2"

UL LISTED • Adjusts to Floor Height up to 2"

ADJUSTABLE FLOOR BOX KITS

INSTALL A RECEPTACLE IN THE FLOOR, THE EASY WAY!

LOW COST... EASY INSTALLATION

Arlington's UL LISTED, Adjustable **FLOOR BOXES** give installers a low cost, convenient way to install a receptacle in a new or existing floor.

We have a floor box kit to fit nearly any application or jobsite condition including our single gang *adjustable boxes*. They fit varying floor heights up to 2" in new work or retrofit.

Our adjustable box is available with non-metallic or metal covers that hide miscut flooring. Gaskets inside the cover prevent water intrusion – and threaded plugs or flip lids protect the box when it's not in use.

Non-metallic
18.3 cu inch box



**Round or Rectangular
Plastic, Brass or
Nickel-plated Brass COVERS**
with a single flip lid,
two flip lids or two threaded plugs



Arlington




1
Box mounts to
joist in new work




In retrofit
cut a
2-3/8" x 3-3/4"
hole in floor
(template
provided)

Box
adjusts to
floor height
up to 2"

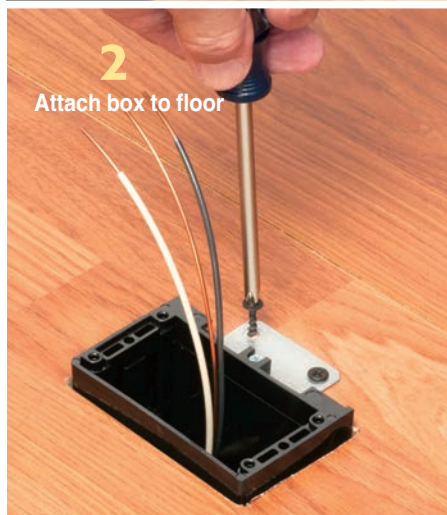

2
Attach box to floor

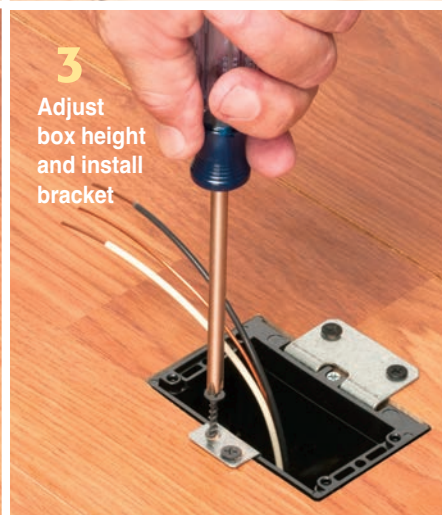

3
Adjust
box height
and install
bracket



4
Attach your
cover of choice
to the box...
with threaded plugs or flip lids

FLBAR101LA



FLBAFR101MB

COVERS WITH SINGLE FLIP LID



FLBAFR101MB

SINGLE Gang
COVER SHAPE


FLBAFR101NL



FLBAFR101BR

FLBAFR101MB
Brass coverFLBAFR101LA
Plastic cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	PKG	PKG

METAL COVER with SINGLE FLIP LID

FLBAFR101MB	00749	Non-metallic box, Brass single flip lid	1	4
FLBAFR101NL	00750	Non-metallic box, Nickel-plated single flip lid	1	4

NON-METALLIC COVER with SINGLE FLIP LID

FLBAFR101BR	00711	Non-metallic box, Brown non-metallic cover w single flip lid	1	4
FLBAFR101BL	00710	Non-metallic box, Black non-metallic cover w single flip lid	1	4
FLBAFR101CA	00712	Non-metallic box, Caramel non-metallic cover w single flip lid	1	4
FLBAFR101LA	00713	Non-metallic box, Light Almond non-metallic cover w single flip lid	1	4
FLBAFR101W	00714	Non-metallic box, White non-metallic cover w single flip lid	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" round plastic or metal cover/flip lid assembly, (2) #6-32 x 1-1/4" screws, (4) #6 drywall screws, (1) NM900 plug, (1) NM94 connector, (1) metal clip and (1) plug.

COVERS WITH TWO FLIP LIDS



FLBAF101MB

SINGLE Gang
COVER SHAPE


FLBAF101CA



FLBAF101NL



FLBAF101LA

FLBAF101MB
Brass cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	PKG	PKG

METAL COVER, RECTANGULAR with TWO FLIP LIDS

FLBAF101MB	13805	Non-metallic box, Brass w two flip lids	1	4
FLBAF101NL	13806	Non-metallic box, Nickel-plated w two flip lids	1	4

NON-METALLIC COVER, RECTANGULAR with TWO FLIP LIDS

FLBAF101BR	04343	Non-metallic box, Brown non-metallic cover w two flip lids	1	4
FLBAF101BL	04342	Non-metallic box, Black non-metallic cover w two flip lids	1	4
FLBAF101CA	52301	Non-metallic box, Caramel non-metallic cover w two flip lids	1	4
FLBAF101LA	04341	Non-metallic box, Light Almond non-metallic cover w two flip lids	1	4
FLBAF101W	04340	Non-metallic box, White non-metallic cover w two flip lids	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 3-3/4" x 4-5/8" plastic or 4" x 4-5/8" metal cover assembly w/ two flip lids, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

ADJUSTABLE FLOOR BOX KITS

ADJUSTS TO FINISHED FLOOR HEIGHT

with a Variety of Metal & Plastic Covers

COVERS WITH TWO THREADED PLUGS

SINGLE Gang

COVER SHAPE



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT STD	PKG
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH		

METAL COVER, ROUND with TWO THREADED PLUGS

FLBAR101MB	52261	Non-metallic box, Brass w two threaded plugs	1	4
FLBAR101NL	52451	Non-metallic box, Nickel-plated w two threaded plugs	1	4

NON-METALLIC COVER, ROUND with TWO THREADED PLUGS

FLBAR101BR	04351	Non-metallic box, Brown non-metallic cover w threaded plugs	1	4
FLBAR101BL	04350	Non-metallic box, Black non-metallic cover w threaded plugs	1	4
FLBAR101LA	04349	Non-metallic box, Light Almond non-metallic cover w threaded plugs	1	4
FLBAR101W	04348	Non-metallic box, White non-metallic cover w threaded plugs	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

SINGLE Gang

COVER SHAPE



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT STD	PKG
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH		

METAL COVER, RECTANGULAR with TWO THREADED PLUGS

FLBA101MB	52259	Non-metallic box, Brass w two threaded plugs	1	4
FLBA101NL	52450	Non-metallic box, Nickel-plated w two threaded plugs	1	4

NON-METALLIC COVER, RECTANGULAR with TWO THREADED PLUGS

FLBA101BR	04347	Non-metallic box, Brown non-metallic cover w threaded plugs	1	4
FLBA101BL	04346	Non-metallic box, Black non-metallic cover w threaded plugs	1	4
FLBA101LA	04345	Non-metallic box, Light Almond non-metallic cover threaded plugs	1	4
FLBA101W	04344	Non-metallic box, White non-metallic cover w threaded plugs	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 4-1/4" x 5-1/8" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.



Arlington®

Patented/Other patents pending

Distributed by

1 Stauffer Industrial Park. Scranton, PA 18517

800.233.4717 • www.aifittings.com • EMAIL sales@aifittings.com

ADJUSTABLE FLOOR BOX KITS



with a Variety of Metal & Plastic Covers **Arlington**



EASY RECEPTACLE INSTALLATION IN FLOOR HEIGHTS UP TO 2"

UL LISTED • Adjusts to Floor Height up to 2"

ADJUSTABLE FLOOR BOX KITS

INSTALL A RECEPTACLE IN THE FLOOR, THE EASY WAY!

LOW COST... EASY INSTALLATION

Arlington's UL LISTED, Adjustable **FLOOR BOXES** give installers a low cost, convenient way to install a receptacle in a new or existing floor.

We have a floor box kit to fit nearly any application or jobsite condition including our single gang *adjustable boxes*. They fit varying floor heights up to 2" in new work or retrofit.

Our adjustable box is available with non-metallic or metal covers that hide miscut flooring. Gaskets inside the cover prevent water intrusion – and threaded plugs or flip lids protect the box when it's not in use.

Non-metallic
18.3 cu inch box



**Round or Rectangular
Plastic, Brass or
Nickel-plated Brass COVERS**
*with a single flip lid,
two flip lids or two threaded plugs*



Arlington




1
Box mounts to joist in new work




In retrofit cut a
2-3/8" x 3-3/4"
hole in floor
(template
provided)

Box
adjusts to
floor height
up to 2"

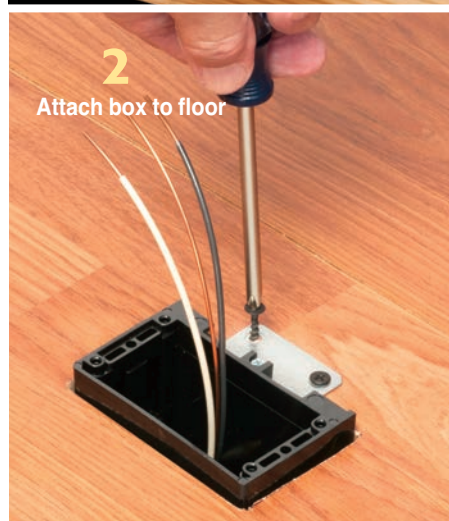

2
Attach box to floor

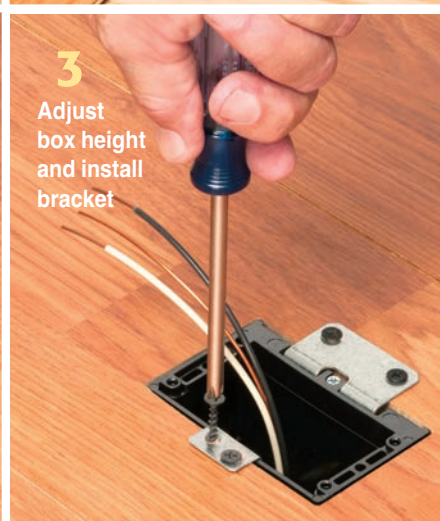

3
Adjust
box height
and install
bracket



4
Attach your
cover of choice
to the box...
with threaded plugs or
flip lids

FLBAR101LA



FLBAFR101MB

COVERS WITH SINGLE FLIP LID




FLBAFR101MB

SINGLE Gang
COVER SHAPE


FLBAFR101NL



FLBAFR101BR

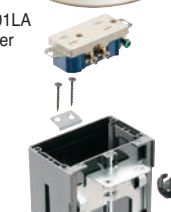FLBAFR101MB
Brass coverFLBAFR101LA
Plastic cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	PKG	PKG

METAL COVER with SINGLE FLIP LID

FLBAFR101MB	00749	Non-metallic box, Brass single flip lid	1	4
FLBAFR101NL	00750	Non-metallic box, Nickel-plated single flip lid	1	4

NON-METALLIC COVER with SINGLE FLIP LID

FLBAFR101BR	00711	Non-metallic box, Brown non-metallic cover w single flip lid	1	4
FLBAFR101BL	00710	Non-metallic box, Black non-metallic cover w single flip lid	1	4
FLBAFR101CA	00712	Non-metallic box, Caramel non-metallic cover w single flip lid	1	4
FLBAFR101LA	00713	Non-metallic box, Light Almond non-metallic cover w single flip lid	1	4
FLBAFR101W	00714	Non-metallic box, White non-metallic cover w single flip lid	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" round plastic or metal cover/flip lid assembly, (2) #6-32 x 1-1/4" screws, (4) #6 drywall screws, (1) NM900 plug, (1) NM94 connector, (1) metal clip and (1) plug.

COVERS WITH TWO FLIP LIDS



FLBAF101MB

SINGLE Gang
COVER SHAPE


FLBAF101CA



FLBAF101NL



FLBAF101LA

FLBAF101MB
Brass cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	PKG	PKG

METAL COVER, RECTANGULAR with TWO FLIP LIDS

FLBAF101MB	13805	Non-metallic box, Brass w two flip lids	1	4
FLBAF101NL	13806	Non-metallic box, Nickel-plated w two flip lids	1	4

NON-METALLIC COVER, RECTANGULAR with TWO FLIP LIDS

FLBAF101BR	04343	Non-metallic box, Brown non-metallic cover w two flip lids	1	4
FLBAF101BL	04342	Non-metallic box, Black non-metallic cover w two flip lids	1	4
FLBAF101CA	52301	Non-metallic box, Caramel non-metallic cover w two flip lids	1	4
FLBAF101LA	04341	Non-metallic box, Light Almond non-metallic cover w two flip lids	1	4
FLBAF101W	04340	Non-metallic box, White non-metallic cover w two flip lids	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 3-3/4" x 4-5/8" plastic or 4" x 4-5/8" metal cover assembly w/ two flip lids, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

ADJUSTABLE FLOOR BOX KITS

ADJUSTS TO FINISHED FLOOR HEIGHT

with a Variety of Metal & Plastic Covers

COVERS WITH TWO THREADED PLUGS

SINGLE Gang

COVER SHAPE



FLBAR101LA



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT STD
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	PKG PKG

METAL COVER, ROUND with TWO THREADED PLUGS

FLBAR101MB	52261	Non-metallic box, Brass w two threaded plugs	1 4
FLBAR101NL	52451	Non-metallic box, Nickel-plated w two threaded plugs	1 4

NON-METALLIC COVER, ROUND with TWO THREADED PLUGS

FLBAR101BR	04351	Non-metallic box, Brown non-metallic cover w threaded plugs	1 4
FLBAR101BL	04350	Non-metallic box, Black non-metallic cover w threaded plugs	1 4
FLBAR101LA	04349	Non-metallic box, Light Almond non-metallic cover w threaded plugs	1 4
FLBAR101W	04348	Non-metallic box, White non-metallic cover w threaded plugs	1 4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

SINGLE Gang

COVER SHAPE



FLBA101LA



FLBA101MB



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT STD
		ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	PKG PKG

METAL COVER, RECTANGULAR with TWO THREADED PLUGS

FLBA101MB	52259	Non-metallic box, Brass w two threaded plugs	1 4
FLBA101NL	52450	Non-metallic box, Nickel-plated w two threaded plugs	1 4

NON-METALLIC COVER, RECTANGULAR with TWO THREADED PLUGS

FLBA101BR	04347	Non-metallic box, Brown non-metallic cover w threaded plugs	1 4
FLBA101BL	04346	Non-metallic box, Black non-metallic cover w threaded plugs	1 4
FLBA101LA	04345	Non-metallic box, Light Almond non-metallic cover threaded plugs	1 4
FLBA101W	04344	Non-metallic box, White non-metallic cover w threaded plugs	1 4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 4-1/4" x 5-1/8" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.



Arlington®

Patented/Other patents pending

Distributed by

1 Stauffer Industrial Park. Scranton, PA 18517

800.233.4717 • www.aifittings.com • EMAIL sales@aifittings.com