



 


GE
Lighting

81514 - FLE29HLX/2XL/827

GE Soft White Spiral® T4 - Facilities; Retail Display; Hospitality; Office; Restaurant

a product of
ecomagination

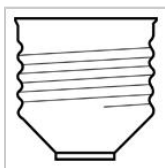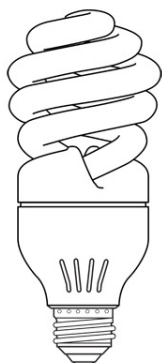

GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T4
Base	Medium Screw (E26)
Equivalent Wattage	100.0 W
Rated Life	12000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	133 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	2200.0
Mean Lumens	1760.0
Nominal Initial Lumens per Watt	75
Color Temperature	2700.0 K
Color Rendering Index (CRI)	82.0

ELECTRICAL CHARACTERISTICS

Wattage	29.0
Input Voltage	120.0 V

DIMENSIONS

Maximum Overall Length (MOL)	6.3000 in(160.0 mm)
Nominal Length	6.300 in(160.0 mm)

PRODUCT INFORMATION

Product Code	81514
Description	FLE29HLX/2XL/827
Standard Package	Case
Standard Package GTIN	10043168815144
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard	10
Package	
UPC	043168815147

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Remove and install by grasping only plastic portion of the lamp.

Warning

- Risk of Electric Shock
 - Do not open - no user serviceable parts inside.
 - Do not use where directly exposed to water.