

Security

Accent

Perimeter

Entrance Ways

Tunnels

Overpasses



Specifications



- CONSTRUCTION** Die-cast heavy-gauge aluminum housing for superior corrosion resistance.
Non-yellowing tempered glass flat lens with a weather-tight silicone gasket.
- ELECTRICAL** Tray-mounted ballast with integral heat sink for maximum heat dissipation.
Deluxe glazed porcelain socket pulse rated for 4 kV.
57 watt to 175 watt capacity.
- OPTICS** Lamp types include Pulse Start Metal Halide and Compact Fluorescent.
HID lamp types are medium base.
Full cut-off optics.
Die-formed specular reflector.
- MOUNTING** Direct mounts to wall or other vertical surfaces.
- FINISH** Polyester powder coat, electrostatically applied, which is preceded by a five step pre-treatment process including an iron phosphate priming stage for superior coating adhesion. This process meets or exceeds all ASTM testing requirements, including those for 1,000 hour salt spray endurance testing. Designer colors may be specified.
- LISTINGS** UL/cUL 1598 listed, suitable for wet locations.
- WARRANTY** Mechanical, finish and electrical shall be covered by a limited 1-year warranty. See terms and conditions for details.



Some luminaires use fluorescent or high intensity discharge (HID) lamps that contain small amounts of mercury. Such lamps are labeled 'Contain Mercury' and/or with the symbol 'Hg'. Lamps that contain mercury must be disposed of in accordance with local requirements. Information regarding lamp recycle and disposal can be found at www.lamprecycle.org.

PROJECT
FIXTURE TYPE
CATALOG#

1611 Clovis R. Barker Road
San Marcos, Texas 78666
Toll Free Phone: (800) 545-1326
Fax: (866) 713-6002
www.qualitylighting.com
e-mail: Quality.Info@Philips.com

600

ORDERING EXAMPLE 613100PMALFS6

ORDERING INFORMATION

SERIES	LAMP BASE	DISTRIBUTION	WATTAGE	SOURCE	LAMP	OPTIONS	FINISH	VOLTAGE	ACCESSORIES
6	1	3	70 100 150	PMA HF	L	FS FSS	TSA TDB TBK TWHT TGR TGN RAL(*)	1 2 3 4 5 6 8	P110A P150A P150M P150E P150F 630 600L

SERIES	LAMP BASE	DISTRIBUTION	WATTAGE	SOURCE	LAMP	OPTIONS	FINISH	VOLTAGE
<input type="checkbox"/> 6	<input type="checkbox"/> 1 Medium	<input type="checkbox"/> 3 Type III	<input type="checkbox"/> PMA <input type="checkbox"/> 70 (ED17) <input type="checkbox"/> 100 (ED17) <input type="checkbox"/> 150 (ED17) <input type="checkbox"/> HF <input type="checkbox"/> 42 (PL-T)	<input type="checkbox"/> PMA Pulse Start Metal Halide <input type="checkbox"/> HF Compact Fluorescent	<input type="checkbox"/> L Lamp Included & Installed	<input type="checkbox"/> FS Single Fusing <input type="checkbox"/> FSS Double Fusing	<input type="checkbox"/> TSA Textured Satin Aluminum <input type="checkbox"/> TDB Textured Dark Bronze <input type="checkbox"/> TBK Textured Black <input type="checkbox"/> TWHT Textured White <input type="checkbox"/> TGR Textured Gray <input type="checkbox"/> TGN Textured Green <input type="checkbox"/> RAL(*) Custom Color (*= Specify RAL #)	<input type="checkbox"/> 1 120 <input type="checkbox"/> 2 208 <input type="checkbox"/> 3 240 <input type="checkbox"/> 4 277 <input type="checkbox"/> 5 480 <input type="checkbox"/> 6 120/277 <input type="checkbox"/> 8 120-277


NOTES:
1) 42W Compact Fluorescent units not available in 480V.

ACCESSORIES

- | | |
|--|--|
| <input type="checkbox"/> P110A
Aimable Pencil Type
Photocontrol - 120 V | <input type="checkbox"/> P150F
Light Leveler
Photocontrol -
Multi-Tap |
| <input type="checkbox"/> P150A
Light Leveler
Photocontrol - 120 V | <input type="checkbox"/> 630
Wire Guard |
| <input type="checkbox"/> P150M
Light Leveler
Photocontrol - 208,
240, and 277 V | <input type="checkbox"/> 600L
Latches for Toolless
entry |
| <input type="checkbox"/> P150E
Light Leveler
Photocontrol - 480 V | |

DIMENSIONS

Front View

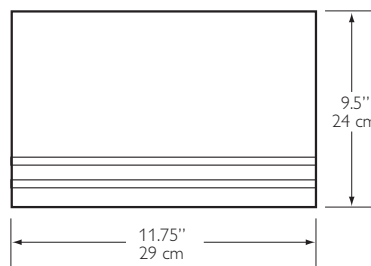

Side View

