


Single Speed Fans with Lights (On/Off)

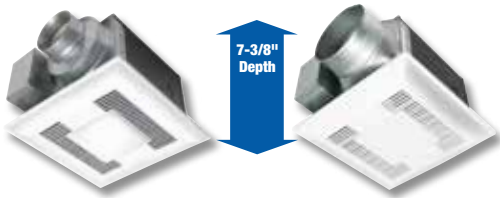

FV-08VQL6 80 CFM 4" or 6" Duct
FV-11VQL6 110 CFM 4" or 6" Duct
FV-15VQL6 150 CFM 6" Duct



WhisperLite Key Benefits:

- Quiet, yet powerful — ideal for new and remodel residential applications
- Integrated dual 4" or 6" duct adaptor on 80-110 CFM models
- Fits in 2 x 8 construction
- Large volume (190-390) CFM options available for light commercial use
- UL listed for tub/shower enclosure when used with a GFCI protected circuit
- Can be used to comply with ASHRAE 62.2, LEED, IAP, California Title 24 and WA Ventilation Code



INCLUDES: (2) 13W ENERGY STAR rated self ballasted GU24 base CFL/lamps and a 4W night light. 3500Kelvin/ HighCRI/997 Lumens per lamp/75 Lumens Per Watt/10,000 hours, rated average life/equivalent to (2) 75W incandescent lamps.



(product shown with 3" duct adaptor)



INCLUDED:
4" to 3" adaptor



FV-05VFL4 50 CFM 4" or 3" Duct
FV-08VFL4 80 CFM 4" or 3" Duct
FV-11VFL4 110 CFM 4" or 3" Duct

WhisperFit-Lite Key Benefits:

- Low profile housing design – Ideal for remodeling projects and manufactured structured homes
- Fits in 2 x 6 and 2 x 8 construction
- Detachable 4" to 3" duct adaptor included
- UL listed for tub/shower enclosure when used with a GFCI protected circuit
- Can be used to comply with ASHRAE 62.2, LEED, IAP, California Title 24 and WA Ventilation Code



INCLUDES: (2) 13W ENERGY STAR rated self ballasted GU24 base CFL/lamps and a 4W night light. 3500Kelvin/ HighCRI/997 Lumens per lamp/75 Lumens Per Watt/10,000 hours, rated average life/equivalent to (2) 75W incandescent lamps.



**Lowest profile,
Actually fits
in a 2 x 4!**



FV-08VSL3 80 CFM 4" Oval Duct
FV-10VSL3 100 CFM 4" Oval Duct

Fits in nearly every ceiling cavity.

Optional 24 gauge, fire code rated 4" oval to 3" round duct adaptor, sold separately (Model # FV-VS43R)

WhisperValue-Lite Key Benefits:

- Ideal for residential construction (single and multi-family) and manufactured homes
- 3-3/8" housing depth – lowest profile ENERGY STAR fan available
- L-shaped bracket simplifies installation and provides strong support
- UL approved for ceiling or wall mount – actually fits in a 2 x 4 stud bay
- Wall installation eliminates the need for a radiation damper
- Can be used to comply with ASHRAE 62.2, LEED, IAP, California Title 24 and WA Ventilation Code

WhisperValue-Lite U-Can Contractor Pack

Universal Housing Can	Motor/Grille Assembly	Complete Fan Unit	Master Pack
FV-08-10VSLA3	FV-08VSLB3	FV-08VSL3	4
FV-08-10VSLA3	FV-10VSLB3	FV-10VSL3	4

The Contractor Pack includes 4 complete fans.

The housing and motor/grille are packaged separately for flexibility during installation.

*Must order in quantities of 4, shipment will contain 1 box with 4 units.

Complete Specifications on pages 28-37.

WhisperControl Cross Reference on pages 24-25.

Single Speed Fans with Lights (On/Off)



WhisperGreen LED		FV-08VKSE3				FV-08VKME3						
Characteristics												
Static pressure in inches w. g.	0.1	0.25	0.1	0.25	0.1	0.25	0.1	0.25	0.1	0.25	0.1	0.25
Air Volume (CFM)	80	86	70	73	60	61	50	54	40	44	30	39
Noise (sones)	<0.3	0.7	<0.3	0.5	<0.3	0.4	<0.3	0.4	<0.3	0.4	<0.3	0.4
Power Consumption (Watts)	7.5	13.3	5.8	11	5.1	9.5	4.3	8.4	4.1	7.1	3.4	6.5
Energy Efficiency (CFMs/Watt)	11.1	6.2	12.3	7.2	12.5	6.8	12.3	6.5	10.3	6.2	9.1	5.5
Speed	878	1200	830	1159	797	1149	770	1136	793	1120	740	1111
Current	0.07	0.11	0.06	0.10	0.05	0.09	0.05	0.08	0.05	0.07	0.04	0.06
Power Rating (V/Hz)	120/60		120/60		120/60		120/60		120/60		120/60	



WhisperGreen-Lite		FV-08VKL4		FV-11VKL4		
Characteristics						
Static pressure in inches w. g.	0.1	0.25	0.1	0.25		
Air Volume (CFM)	80	79	110	108		
Noise (sones)	<0.3	0.6	0.7	1.1		
Power Consumption (Watts)	7.4	12.4	12.5	18.0		
Energy Efficiency (CFMs/Watt)	11.2	6.6	8.9	6.0		
Speed	866	1166	1019	1256		
Current	0.01	0.02	0.25	0.34		
Power Rating (V/Hz)	120/60		120/60			



WhisperLite		FV-08VQL6		FV-11VQL6		FV-15VQL6		
Characteristics								
Static pressure in inches w. g.	0.1	0.25	0.1	0.25	0.1	0.25		
Air Volume (CFM)	80	62	110	90	150	128		
Noise (sones)	<0.3	0.4	0.5	0.6	0.9	1.0		
Power Consumption (Watts)	14.9	14.7	23.4	23.0	31.8	30.9		
Energy Efficiency (CFMs/Watt)	5.5	4.3	4.7	3.9	4.8	4.2		
Speed	863	1117	1006	1193	800	988		
Current	0.12	0.12	0.20	0.19	0.27	0.26		
Power Rating (V/Hz)	120/60		120/60		120/60			



WhisperFit-Lite		FV-05VFL4				FV-08VFL4				FV-11VFL4			
Characteristics	4" Duct		3" Duct		4" Duct		3" Duct		4" Duct		3" Duct		
	Static pressure in inches w. g.	0.1	0.25	0.1	0.25	0.1	0.25	0.1	0.25	0.1	0.25	0.1	0.25
Air Volume (CFM)	50	34	50	35	80	67	70	60	110	95	90	78	
Noise (sones)	<0.3	0.4	<0.3	0.5	0.5	0.8	0.6	0.8	1.3	1.4	1.5	1.5	
Power Consumption (Watts)	14.8	14.7	14.8	14.6	28.4	28.1	28.3	28.0	32.6	32.1	32.1	31.6	
Energy Efficiency (CFMs/Watt)	3.6	2.4	3.4	2.4	2.8	2.4	2.6	2.3	3.4	3.0	3.0	2.7	
Speed	692	962	747	983	803	1005	908	1064	897	1068	1077	1177	
Current	0.12	0.12	0.12	0.12	0.24	0.24	0.24	0.24	0.27	0.27	0.27	0.27	
Power Rating (V/Hz)	120/60				120/60				120/60				



WhisperValue-Lite		FV-08VSL3		FV-10VSL3	
Characteristics	4" Oval Duct		4" Oval Duct		
Static pressure in inches w. g.	0.1	0.25	0.1	0.25	
Air Volume (CFM)	80	72	100	91	
Noise (sones)	1.0	1.2	1.4	1.5	
Power Consumption (Watts)	22.5	22.9	30.2	30.3	
Energy Efficiency (CFMs/Watt)	3.6	3.1	3.3	3.0	
Speed (RPM)	825	1021	918	1087	
Current (amps)	0.19	0.19	0.26	0.26	
Power Rating (V/Hz)	120/60		120/60		



WhisperRecessed		FV-08VRL1	
Characteristics			
Static pressure in inches w. g.	0.1	0.25	
Air Volume (CFM)	80	66	
Noise (sones)	0.8	0.7	
Power Consumption (Watts)	20.5	19.5	
Energy Efficiency (CFMs/Watt)	4.0	3.4	
Speed	1378	1501	
Current	0.17	0.17	
Power Rating (V/Hz)	120/60		