


GROUND CLAMPS Heavy Duty & with 360° Adapters for Rigid Conduit G SERIES



HEAVY DUTY BRONZE

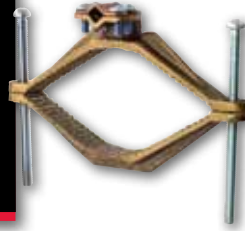

- Heavy duty bronze adapters have serrations that match the serrations on the ground clamp, assuring positive lock.
- All adapters fit all clamps for the ultimate flexibility.
- Assembled with zinc plated steel hardware.
- Used to connect grounding conductor to rigid conduit on water pipe.
- UL Listed 467 Grounding and Bonding.

All dimensional data is listed in inches.

CAT. NO.	PIPE SIZE (IPS)	GROUND WIRE RANGE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	STD. CTN. QTY.
G-3	1/2-1	8-4/0 STR	2.320	0.748	1.437	20
G-4	1 1/4-2	8-4/0 STR	3.528	0.850	2.706	10
G-15	2 1/2-4	8-4/0 STR	6.125	0.964	3.962	6
G-16	4 1/2-6	8-4/0 STR	7.916	0.933	4.565	3

FOR RIGID CONDUIT



- Used to connect grounding conductor to rigid conduit on water pipe.

All dimensional data is listed in inches.

CAT. NO.	CONDUIT HUB SIZE	PIPE SIZE (IPS)	GROUND WIRE RANGE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	STD. CTN. QTY.
G-5	1/2	1/2 - 1	10 SOL - 2/0 STR	2.200	0.748	2.437	15
G-6	1/2	1 1/4 - 2	10 SOL - 2/0 STR	3.667	0.791	3.195	10
G-18	1/2	2 1/2 - 4	10 SOL - 2/0 STR	6.125	0.961	4.812	6
G-19	1/2	4 1/2 - 6	10 SOL - 2/0 STR	8.125	1.263	4.740	3
G-7	3/4	1/2 - 1	10 SOL - 3/0 STR	2.200	0.748	1.437	15
G-8	3/4	1 1/4 - 2	10 SOL - 3/0 STR	3.616	0.791	3.298	8
G-21	3/4	2 1/2 - 4	10 SOL - 3/0 STR	6.125	0.961	4.943	6
G-22	3/4	4 1/2 - 6	10 SOL - 3/0 STR	8.227	1.244	5.050	3
G-9	1	1/2 - 1	10 SOL - 3/0 STR	2.315	0.747	3.159	12
G-10	1	1 1/4 - 2	10 SOL - 3/0 STR	3.616	0.816	3.561	8
G-24	1	2 1/2 - 4	10 SOL - 3/0 STR	6.125	0.940	5.191	6
G-25	1	4 1/2 - 6	10 SOL - 3/0 STR	8.225	1.260	5.245	3