




BURNDY Catalog Number
UPC Number
Description
Status

GB29
 7818102312722
 2/0-250 CU-BAR 1 PC GRD
 Active

Web Use
 BURNDY Product Line

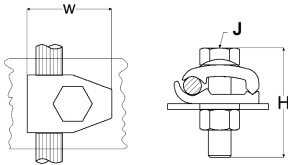

Dimensional

Width (in) 1.88
 Height (in) 2.32
 Size (Hex) or Size (Bolt) 1/2
 Thickness 0.25
 Size (Hex) or Size (Bolt) - in 0.50
 Width (Fraction) 1-7/8

General

Product Description Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 2/0 AWG (Sol) -250 kcmil, 1/2" Stud, 2 IN Width

Conductor(s)

Bar Thickness (Range) N/A
 Copper Solid Size (Range) 2/0 AWG-4/0 AWG
 Copper Stranded (Range) 2/0 AWG-250 kcmil

Physical

Installation Torque 480
 Type of Plating Unplated
 Plated (Yes or No) N
 Product Material Copper Alloy

Approvals / Certifications

Rated for Direct Burial Y
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 UL Recognized N
 CULUS N
 Industry Standards UL467

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109


Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175



BURNDY Catalog Number
UPC Number
Description
Status

GB29
 7818102312722
 2/0-250 CU-BAR 1 PC GRD
 Active

Web Use
 BURNDY Product Line

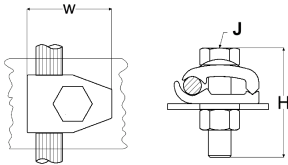

Dimensional

Width (in) 1.88
 Height (in) 2.32
 Size (Hex) or Size (Bolt) 1/2
 Thickness 0.25
 Size (Hex) or Size (Bolt) - in 0.50
 Width (Fraction) 1-7/8

General

Product Description Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 2/0 AWG (Sol) -250 kcmil, 1/2" Stud, 2 IN Width

Conductor(s)

Bar Thickness (Range) N/A
 Copper Solid Size (Range) 2/0 AWG-4/0 AWG
 Copper Stranded (Range) 2/0 AWG-250 kcmil

Physical

Installation Torque 480
 Type of Plating Unplated
 Plated (Yes or No) N
 Product Material Copper Alloy

Approvals / Certifications

Rated for Direct Burial Y
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 UL Recognized N
 CULUS N
 Industry Standards UL467

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175