


Copper Short Barrel Two Hole Compression Lug - GL-N Series

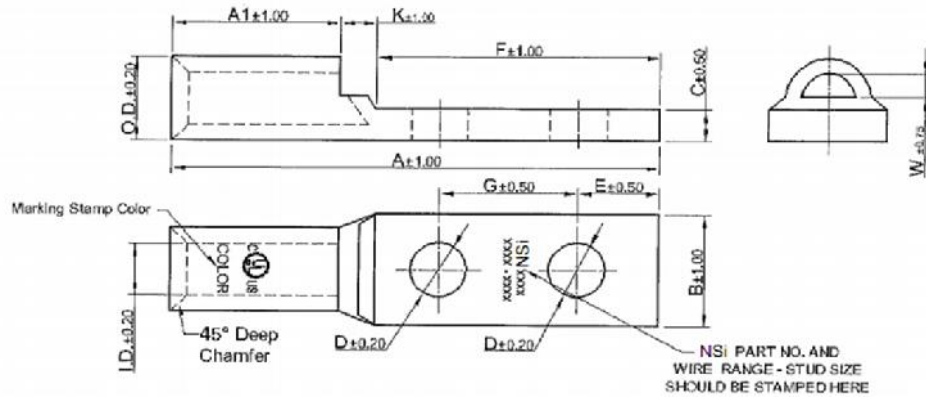

Drawn - SD
Approved - KM
Material - Copper

Title - Copper Short Barrel Two Hole Compression Lug - GL-N Series



Part Number	Wire Range	Stud Size	Hole Spacing	Color Code	I.D mm	Inches	O.D. mm	Inches	A mm	Inches	A1 mm	Inches	B mm	Inches	C mm	Inches	D mm	Inches	E mm	Inches	F mm	Inches	G mm	Inches	K mm	Inches	W mm	Inches
GL6N-141	6	1/4"	5/8"	BLUE	5.20	0.20	7.50	0.30	53.00	2.09	18.00	0.71	10.70	0.42	2.10	0.08	6.40	0.25	7.10	0.28	32.00	1.26	15.90	0.63	3.00	0.12	1.30	0.05
GL6N-143	6	1/4"	1"	BLUE	5.20	0.20	7.50	0.30	67.00	2.64	18.00	0.71	10.70	0.42	2.10	0.08	6.40	0.25	7.10	0.28	46.00	1.81	25.40	1.00	3.00	0.12	1.30	0.05
GL6N-38	6	3/8"	1"	BLUE	5.20	0.20	7.50	0.30	67.00	2.64	18.00	0.71	12.40	0.49	2.20	0.09	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	3.00	0.12	1.30	0.05
GL4N-141	4	1/4"	5/8"	GRAY	6.40	0.25	8.70	0.34	53.00	2.09	18.00	0.71	12.40	0.49	2.20	0.09	6.40	0.25	7.10	0.28	32.00	1.26	15.90	0.63	3.00	0.12	1.70	0.07
GL4N-143	4	1/4"	1"	GRAY	6.40	0.25	8.70	0.34	68.00	2.68	19.00	0.75	12.40	0.49	2.20	0.09	6.40	0.25	7.10	0.28	46.00	1.81	25.40	1.00	3.00	0.12	1.70	0.07
GL4N-38	4	3/8"	1"	GRAY	6.40	0.25	8.70	0.34	68.00	2.68	19.00	0.75	12.40	0.49	2.20	0.09	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	3.00	0.12	1.70	0.07
GL2N-141	2	1/4"	5/8"	BROWN	8.00	0.31	10.70	0.42	58.00	2.28	21.00	0.83	15.30	0.60	2.60	0.10	6.40	0.25	7.10	0.28	32.00	1.26	15.90	0.63	4.00	0.16	2.00	0.08
GL2N-38	2	3/8"	1"	BROWN	8.00	0.31	10.70	0.42	72.00	2.83	21.00	0.83	15.30	0.60	2.60	0.10	10.50	0.41	7.10	0.28	46.00	1.81	25.40	1.00	4.00	0.16	2.00	0.08
GL2N-142	2	1/4"	3/4"	BROWN	8.00	0.31	10.70	0.42	60.00	2.36	21.00	0.83	15.30	0.60	2.60	0.10	6.40	0.25	7.10	0.28	35.00	1.38	19.10	0.75	4.00	0.16	2.00	0.08
GL2N-143	2	1/4"	1"	BROWN	8.00	0.31	10.70	0.42	71.00	2.80	21.00	0.83	15.30	0.60	2.60	0.10	6.40	0.25	7.10	0.28	46.00	1.81	25.40	1.00	4.00	0.16	2.00	0.08
GL10N-38	1/0 AWG	3/8"	1"	PINK	9.90	0.39	13.20	0.52	72.00	2.83	21.00	0.83	18.90	0.74	3.20	0.13	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	5.00	0.20	2.50	0.10
GL20N-38	2/0 AWG	3/8"	1"	BLACK	11.20	0.44	14.30	0.56	76.00	2.99	24.00	0.94	20.70	0.81	3.00	0.12	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	6.00	0.24	2.50	0.10
GL20N	2/0 AWG	1/2"	1 3/4"	BLACK	11.20	0.44	14.30	0.56	106.00	4.17	24.00	0.94	20.70	0.81	3.00	0.12	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	6.00	0.24	2.50	0.10
GL30N	3/0 AWG	1/2"	1 3/4"	ORANGE	12.50	0.49	15.80	0.62	109.00	4.29	25.00	0.98	22.90	0.90	3.20	0.13	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	8.00	0.31	3.00	0.12
GL30N-38	3/0 AWG	3/8"	1"	ORANGE	12.50	0.49	15.80	0.62	79.00	3.11	25.00	0.98	22.90	0.90	3.20	0.13	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	8.00	0.31	3.00	0.12
GL40N	4/0 AWG	1/2"	1 3/4"	PURPLE	13.90	0.55	17.50	0.69	109.00	4.29	25.00	0.98	25.40	1.00	3.40	0.13	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	8.00	0.31	3.50	0.14
GL40N-38	4/0 AWG	3/8"	1"	PURPLE	13.90	0.55	17.50	0.69	79.00	3.11	25.00	0.98	25.40	1.00	3.40	0.13	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	8.00	0.31	3.50	0.14
GL250N	250	1/2"	1 3/4"	YELLOW	15.10	0.59	19.10	0.75	112.00	4.41	27.00	1.06	27.70	1.09	3.80	0.15	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	9.00	0.35	4.00	0.16
GL250N-38	250	3/8"	1"	YELLOW	15.10	0.59	19.10	0.75	82.00	3.23	27.00	1.06	27.70	1.09	3.80	0.15	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	9.00	0.35	4.00	0.16
GL300N	300	1/2"	1 3/4"	WHITE	16.70	0.66	20.70	0.81	112.00	4.41	27.00	1.06	30.20	1.19	3.80	0.15	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	9.00	0.35	4.20	0.17
GL350N	350	1/2"	1 3/4"	RED	17.80	0.70	22.20	0.87	115.00	4.53	28.00	1.10	32.40	1.28	4.20	0.17	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	11.00	0.43	4.20	0.17
GL350N-38	350	3/8"	1"	RED	17.80	0.70	22.20	0.87	85.00	3.35	28.00	1.10	32.40	1.28	4.20	0.17	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	11.00	0.43	4.50	0.18
GL400N	400	1/2"	1 3/4"	BLUE	19.40	0.76	24.10	0.95	119.00	4.69	30.00	1.18	35.20	1.39	4.50	0.18	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	13.00	0.51	4.80	0.19
GL500N	500	1/2"	1 3/4"	BROWN	21.30	0.84	27.00	1.06	124.00	4.88	35.00	1.38	39.10	1.54	5.50	0.22	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	13.00	0.51	4.80	0.19
GL500N-38	500	3/8"	1"	BROWN	21.30	0.84	27.00	1.06	94.00	3.70	35.00	1.38	39.10	1.54	5.50	0.22	10.50	0.41	9.70	0.38	46.00	1.81	25.40	1.00	13.00	0.51	5.00	0.20
GL600N	600	1/2"	1 3/4"	GREEN	23.50	0.93	30.20	1.19	128.00	5.04	38.00	1.50	43.60	1.72	6.40	0.25	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	14.00	0.55	6.00	0.24
GL750N	750	1/2"	1 3/4"	BLACK	26.50	1.04	33.30	1.31	140.00	5.51	47.00	1.85	48.30	1.90	6.80	0.27	13.00	0.51	15.70	0.62	76.00	2.99	44.50	1.75	17.00	0.67	6.50	0.26