

Look Great

OUTDOORS!

UL/CSA LISTED SUPPORTS & ENCLOSURES

GARD-N-POST™

Arlington's **Gard-N-Posts™** are the attractive, safe and easy way to install light fixtures and devices outdoors!

We offer a variety of styles, from 9" to 73" tall that function as supports or enclosures – or both!

Made of non-metallic, heavy-duty plastic, our damage-resistant Gard-N-Post holds up against abuse from lawn maintenance equipment.

Most have built-in stabilizers that deliver rigid support and require no assembly. The angle-cut at the bottom allows for easy access to underground wires (Not applicable to GPD9 deck/post mount style or the GPLN15GR low profile support.)

Plus, the colorant runs throughout the post, so there's no chipping or loss of color.

For added convenience, **GP19**, **GP26** and **GP37**, our most popular sizes, come with a supplied separator so you can install power and low voltage outlets in the same post.

Some styles come with a metal grounding bushing in place, ready for the installation of an NPT fixture. And some have KOs that make them UL Listed enclosures.

Whatever your need, there's a Gard-N-Post to fit!



Four permanent colors. No chipping!

*GP19 • GP26 • GP37
One post. Two openings.*



Power



Low voltage separator



Low Voltage



Arlington



CSA Listed with grounding lugs

Patented. Other patents pending.


800.233.4717 • www.aifittings.com • EMAIL sales@aifittings.com

FOR ANY OUTDOOR LIGHT FIXTURE UP TO 18 LBS

GP19 19.5"

GP26 26"

- Openings on both sides of the post allow for back-to-back power – use the supplied low voltage separator to install power and low voltage outlets in the same post
- Built-in stabilizers require no assembly and deliver rigid support
- Designed for easy access to underground wiring
- Four 1/2" KOs for a UL Listed enclosure
- For any outdoor light fixture up to 18 lbs, with 1/2" or 3/4" NPT threads, and/or a GFCI wiring device
- Four colors
- Competitively priced

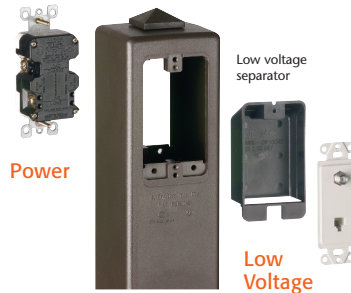

Patented.
Other patents pending.

GP19 19.5" Height

CATALOG NUMBER	UPC/DCI/NAED MFG. #01 8997	COLOR	UNIT PKG	STD PKG
GP19B	77086	Black	1	6
GP19BR	77087	Bronze	1	6
GP19G	77088	Green	1	6
GP19W	77089	White	1	6

Note: Add suffix 'GC' for orders in Canada

GP26 26" Height

CATALOG NUMBER	UPC/DCI/NAED MFG. #01 8997	COLOR	UNIT PKG	STD PKG
GP26B	77090	Black	1	6
GP26BR	77092	Bronze	1	6
GP26G	77094	Green	1	6
GP26W	77096	White	1	6

Note: Add suffix 'GC' for orders in Canada

Includes:
Installed 3/4" x 1/2" NPT metal reducing bushing, locknut with copper ground wire for fixture installation, (2) blank device plates, gaskets and screws, plug for top hole (when fixture is not installed), low voltage separator, removable KO plate.