



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



GRC3834 3/8"-3/4" 1/0 Ground Clamp

Nsi Industries

Catalog Number	GRC3834
Manufacturer	Nsi Industries
Description	Ground Rod Clamp, 1 In Overall Length, Silicon Bronze (Body) Material, #10 to #1/0 Awg Conductor Size, 0.13 LB
Weight per unit	0.1300 (lbs/each)
Product Category	Ground Rods & Grounding System

Material, Color, and Finish

Clamp Material	10 SOL - 1/0 STR
Insulation Material	Silicon Bronze

Descriptions

Also Known As...	Tear Drop Acorn
Description	3/8"-3/4" 1/0 GROUND CLAMP

Manufacturer Information

GTIN	00662381005571
sub brand	Grounding
UPC	662381005571

Taxonomies, Classifications, and Categories

Category Description	SERVICE ENTRANCE FITTINGS: Weatherheads & Grounding Fittings & Ground Rods
Type	Ground Rod Clamps Range Taking

Packaging

Carton	25
Weight Per each	0.13

Uses, Certifications, and Standards

Application	Grounding Wire
standard	UL467

GROUNDING

Ground Clamps

Heavy Duty Silicon Bronze & Range Taking Rod Clamp

GRC Series



SPECIFICATIONS

- UL Listed for Direct Burial in Earth & Concrete.


FEATURES

Heavy Duty Silicon Bronze (GRC-H)

- Ground rod clamps are made from silicon bronze for maximum strength.
- A silicon bronze screw furnishes maximum clamping force.
- All standard duty and heavy duty ground clamps are UL Listed for direct burial in earth or concrete.
- *Available with silicon bronze screws by adding suffix -SB.

Range Taking Rod Clamp (GRC)

- This heavy duty ground rod clamp replaces all existing ground rod clamps, eliminating the need to stock several different sizes and types.
- UL listed for direct burial in earth and concrete, heavy duty construction enables it to handle large ground wires up to 1/0 AWG – much larger than a standard ground rod clamp.
- Suitable for 3/8", 1/2", 5/8", 3/4" ground rods.
- *Available with silicon bronze screws by adding suffix -SB.

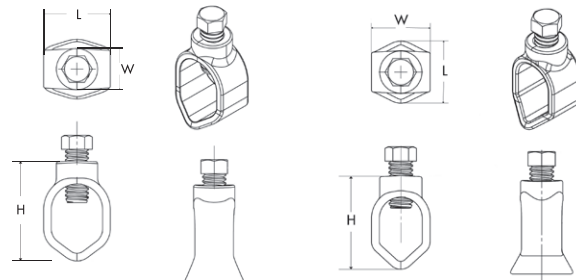

GRC-34H

GRC-58H

CAT. NO.	FIG. NO.	CERTIFICATION	GROUND WIRE RANGE (IN.)	GROUND ROD SIZE (IN.)	REBAR SIZE (IN.)	GROUND WIRE MAXIMUM (IN.)	STD. CTN. QTY.
GRC-34H*	1	UL	8 SOL – 1/0 STR	3/4	–	1/0 STR	20
GRC-50H*	1	UL	10 SOL – 2 STR	1/2	–	2 STR	25
GRC-58H*	1	UL	10 SOL – 1/0 STR	5/8	–	1/0 STR	20
GRC-100H*	1	UL	8 SOL – 4/0 STR	1	–	4/0 STR	10
GRC-3834*	2	cULus	10 SOL – 1/0 STR	3/8, 1/2, 5/8	3/8, 1/2, 5/8	1/0 STR	25



Scan QR code
for mobile access to
Grounding drawings.