

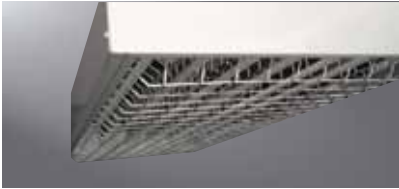





	Designation	Description
<p><b>Open</b></p> 	<p><b>Blank=</b> No Guard</p>	<p>For maximum light output</p>
<p><b>I5 / I8 Lens</b></p> <p><b>Frosted Acrylic Lens</b></p> 	<p><b>I5-FRM/LENS=</b> Frosted Acrylic Lens and Frame (use with general distribution reflector, I5 only)</p> <hr/> <p><b>I8-FRM/FL PK=</b> Frosted Acrylic Lens and Frame (use with general distribution reflector, I8 only)</p> <hr/> <p><b>I5-FRM/CL PK=</b> Clear Acrylic Lens and Frame (use with general distribution reflector, I5 only)</p> <hr/> <p><b>I8-FRM/CL PK=</b> Clear Acrylic Lens and Frame (use with general distribution reflector, I8 only)</p>	<p>Lens in white door frame with "Herringbone" patterned end rail</p>
<p><b>I5/I8 Wireguard</b></p> <p><b>Heavy Duty Wireguard</b></p> 	<p><b>WG/I5-4FT-B=</b> Four Foot (4') Heavy Duty Wireguard (for I5)</p> <hr/> <p><b>WG/I8-4FT-B=</b> Four Foot (4') Heavy Duty Wireguard (for I8)</p>	<p>Finished in White. Can be used alone or in combination with other shielding</p>
<p><b>I5/I8 Baffle</b></p> <p><b>TBW</b></p> 	<p><b>90800PPK BAFFLE 4FT I5 WITH HDW (WHITE)=</b> Four Foot (4') Thin Blade White Baffle (for I5)</p> <hr/> <p><b>BAFFLE 4FT I8 (WHITE) 11571919=</b> Four Foot (4') Thin Blade White Blade Baffle (for I8)</p>	<p>Thin Blade White Baffle with twenty-three Degree (23°) longitudinal shielding</p>
<p><b>I5/I8 Louver</b></p> <p><b>Asymmetric Louver</b></p> 	<p><b>90801P PK=</b> Asymmetric Directional Louver (use with general distribution reflector)</p>	<p>Can be oriented in either direction for flexibility</p>



## F-BAY HBI, HBL and HBE DOOR FRAMES and WIREGUARDS

HBI Lens and Wireguard	Designation
<b>Prismatic and Clear Acrylic Lens</b> 	<b>HBI-FRM/LENS PK</b> = Prismatic Acrylic Lens and Door Frame for HBI
	<b>HBI-FRM/CL PK</b> = Clear Acrylic Lens and Door Frame for HBI
<b>Wireguard</b> 	<b>HBI-FRM/WG PK</b> = Frame and Wireguard for HBI
	<b>HBI-FRM/LENS/WG PK</b> = Frame and Prismatic Acrylic Lens with Wireguard for HBI
	<b>HBI-FRM/CL/WG PK</b> = Frame and Clear Lens with Wireguard for HBI
<b>Drop Wireguard</b> 	<b>HBI-FRM/DROP/WG PK</b> = Frame and Drop Wireguard for HBI
	<b>HBI-FRM/CL/DROP/WG PK</b> = Drop Wireguard, Clear Acrylic Lens and Door Frame for HBI
<b>Heavy Duty Stock Wireguard</b> 	<b>SWG/HBI-4FT-B</b> = Heavy Duty Wireguard for Field Installation
HBL Wireguard	Designation
<b>Wireguard</b> 	<b>WG-HBL6-4FT-B</b> = Field Installable, Wireguard for HBL 4 and 6 Lamp
	<b>WG-HBL8-4FT-B</b> = Field Installable, Wireguard for HBL 8 and 10 Lamp
HBE Door Frame	Designation
<b>HBE Door Frame</b> 	<b>HBE-___-FRM/LENS WDF PK</b> = Prismatic Acrylic Lens and Extruded Aluminum Door Frame <sup>1</sup>
	<b>HBE-___-FRM/CL WDF PK</b> = Clear Acrylic Lens and Extruded Aluminum Door Frame <sup>1</sup>
	<b>HBE-___-FRM/LENS/WG WDF PK</b> = Four (4) and Six (6) Lamp Frame and Prismatic Lens with Wireguard <sup>1</sup>
	<b>HBE-___-FRM/LENS/WG PK</b> = Eight (8) and Ten (10) Lamp Frame and Prismatic Lens with Wireguard <sup>1</sup>
	<b>HBE-___-FRM/CL/WG PK</b> = Four (4) and Six (6) Lamp Frame and Clear Acrylic Lens with Wireguard <sup>1</sup>
	<b>HBE-___-FRM/CL/WG WDF PK</b> = Eight (8) and Ten (10) Lamp Frame and Clear Acrylic Lens with Wireguard <sup>1</sup>

NOTES: 1. Specify "4/6LT" or "8/10LT" when ordering HBE Door Frame accessories.

