

Twist-Lock® Devices  
 15A, 125V, 2 Pole, 2 Wire Non-Grounding  
 Insulgrip® Connector

# HUBBELL

## Features

- Ribbed nylon housing provides secure, impact and chemical resistant grip
- Superior cord grip design protects terminations from excess strain
- Integral VARI-SIZE insert accommodates a wide range of cord diameters

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black and white nylon.	.220"- .720" (5.8-18.3)	783585177908	HBL7506C

## Listings

Listed to UL 498  
 Fed. Spec W-C-596  
 Certified to CSA C22.2 No. 42

## Specifications



Housing / Cord Clamp	Nylon
Terminal Retainer	Clear polycarbonate
Contacts	Brass
Terminal Screws	#8-32 Brass (Phillips / Slotted / Robertson)
Terminal Clamp	Cold rolled steel – nickel plated
Assembly Screws	Steel – nickel plated

## Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Terminal Accommodation	#18 AWG - #10 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
<b>Environmental</b>	
Flammability	HB or better per UL94/CSA 22.2 No.0.17
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)



15A 125V  
 NEMA L1-15P  
 UL Listed  
 0.5 HP

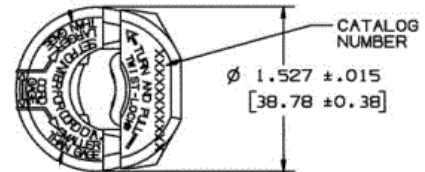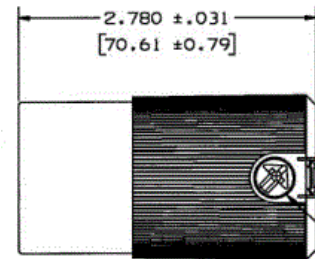

## Accessories

Plug	HBL7545C
Weatherproof Boot	HBL6024
Flanged Inlet	HBL7524C
Weatherproof Boot	HBL6023

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

