

# Straight Blade Devices 50A, 125/250V, 3 Pole, 4 Wire Grounding Plug

# HUBBELL

## Features

- Gripping ribs provide secure gripping area
- Supertough nylon housing
- Catalog number, ratings and certifications molded in face

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Plug, nylon	.625"-1.310" (15.9-33.3)	783585015323	HBL9451C

## Listings

UL Listed File E1706  
CSA Certified

## Specifications

Housing	Supertough Nylon
Blade Holder	Reinforced Thermoplastic Polyester
Blades	Brass
Box Terminals	Copper Alloy
Mounting Screw	Stainless steel

## Performance

### Electrical


Current Interrupting Certified for current interrupting at full rated current  
Dielectric Voltage Withstands 2,000V minimum

### Mechanical

Product Identification Ratings are a permanent part of the device  
Terminal Accommodation #12 AWG through #4 AWG copper wire only  
Terminal Identification Terminals identified in accordance with UL 498 and CSA

### Environmental

Flammability UL 94 HB  
IP Suitability IP20  
Operating Temperatures Maximum continuous 75°C; minimum -40°C (w/o impact)

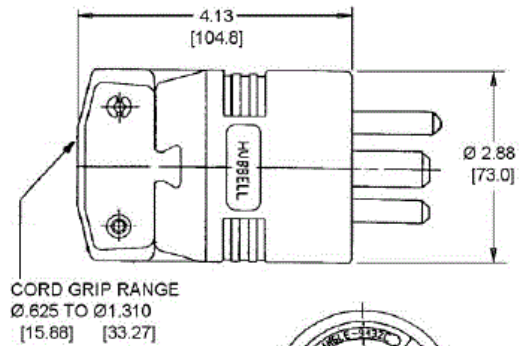

## Resources

Customer Use Drawing  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

