



The HALO® HLS series is an LED low profile surface mount fixture designed to install from below the ceiling into most 3-1/2" and 4" junction boxes. The fixture is available in 4", 6", and 9" and is wet location rated making it perfect for almost all residential applications. The 9" fixture has a motion sensor option for hands-free illumination. The HLS series comes in dedicated CCT and is 120V phase cut dimming down to 10%. Get the benefit of buying in bulk by purchasing in 6 packs or 12 packs.

Product Features

- Low profile surface mount fixture for ceiling or wall mounting
- Below the ceiling installation, no clips or plates needed
- 4" & 6" are bulk packed 6PK and 12PK for value pricing
- Installs in many 3-1/2" and 4" ceiling junction and pancake boxes
- Dedicated CCT: 3000K / 4000K / 5000K; 90+ CRI
- 120V input, phase dimming down to 10% ⁽¹⁾
- Wet location rated ⁽²⁾
- Motion sensor option available



LEARN MORE



4"



HLS4079xx1EWH
4-inch Surface Downlight
3000K, 4000K, 5000K

6"



HLS6099xx1EWH
6-inch Surface Downlight
3000K, 4000K, 5000K

9"



HLS9129xx1EWH
9-inch Surface Downlight
3000K, 4000K, 5000K



9"



HLSMS9129xx1EWH
9-inch Surface Downlight with Motion Sensor
3000K, 4000K, 5000K

Motion Sensor Benefits

- **Convenience / Safety** lights come on as you enter the space
- **Energy saving** reduces the amount of energy used
- **Cost savings** reduces energy consumption
- **Sleek design** perfect for residential applications

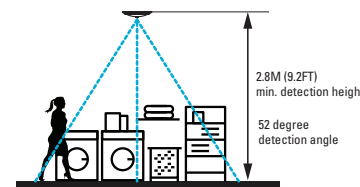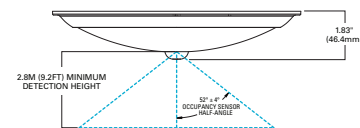

1. Dimming not available for HLSMS9
2. Damp location rated only

Catalog Number	Material Number	Description	UPC
HLS4079301EWH-6BP	13598872	4", 750 lumens, 90 CRI, 120V, 3000K, Wet Location Rated, 6 Bulk Pack	080083256662
HLS4079401EWH-6BP	13598873	4", 750 lumens, 90 CRI, 120V, 4000K, Wet Location Rated, 6 Bulk Pack	080083256686
HLS4079501EWH-6BP	13598874	4", 750 lumens, 90 CRI, 120V, 5000K, Wet Location Rated, 6 Bulk Pack	080083256709
HLS4079301EWH-12BP	13598875	4", 750 lumens, 90 CRI, 120V, 3000K, Wet Location Rated, 12 Bulk Pack	080083256723
HLS4079401EWH-12BP	13598876	4", 750 lumens, 90 CRI, 120V, 4000K, Wet Location Rated, 12 Bulk Pack	080083256747
HLS4079501EWH-12BP	13598877	4", 750 lumens, 90 CRI, 120V, 5000K, Wet Location Rated, 12 Bulk Pack	080083256761
HLS6099301EWH-6BP	13598878	6", 900 lumens, 90 CRI, 120V, 3000K, Wet Location Rated, 6 Bulk Pack	080083256785
HLS6099401EWH-6BP	13598879	6", 900 lumens, 90 CRI, 120V, 4000K, Wet Location Rated, 6 Bulk Pack	080083256808
HLS6099501EWH-6BP	13598880	6", 900 lumens, 90 CRI, 120V, 5000K, Wet Location Rated, 6 Bulk Pack	080083256822
HLS6099301EWH-12BP	13598881	6", 900 lumens, 90 CRI, 120V, 3000K, Wet Location Rated, 12 Bulk Pack	080083256846
HLS6099401EWH-12BP	13598882	6", 900 lumens, 90 CRI, 120V, 4000K, Wet Location Rated, 12 Bulk Pack	080083256860
HLS6099501EWH-12BP	13598883	6", 900 lumens, 90 CRI, 120V, 5000K, Wet Location Rated, 12 Bulk Pack	080083256884
HLS9129301EWH	13598884	9", 1200 lumens, 90 CRI, 120V, 3000K, Wet Location Rated	080083256907
HLS9129401EWH	13598885	9", 1200 lumens, 90 CRI, 120V, 4000K, Wet Location Rated	080083256921
HLS9129501EWH	13598886	9", 1200 lumens, 90 CRI, 120V, 5000K, Wet Location Rated	080083256945
HLSMS9129301EWH	13598887	9", 1200 lumens, 90 CRI, 120V, 3000K, Motion Sensor	080083256969
HLSMS9129401EWH	13598888	9", 1200 lumens, 90 CRI, 120V, 4000K, Motion Sensor	080083256983
HLSMS9129501EWH	13598889	9", 1200 lumens, 90 CRI, 120V, 5000K, Motion Sensor	080083257003

See spec sheet for "-CA" skus.



Cooper Lighting Solutions
1121 Highway 74 South
Peachtree City, GA 30269
P: 770-486-4800
cooperlighting.com

Canada Sales
5925 McLaughlin Road
Mississauga, Ontario L5R 1B8
P: 905-501-3000
F: 905-501-3172

© 2023 Cooper Lighting Solutions
All Rights Reserved
Publication No. BR51890523
March 2023

Product availability, specifications, and compliances are subject to change without notice.