

**Description**

The HALO Home Smart Plug-In Lamp Dimmer enables convenient control for standard floor and table lamps using the HALO Home mobile app. Combine with more HALO Home light fixtures and accessories to create groups and scenes throughout the home. Smart Plug-In Lamp Dimmer is for lamps only.

Catalog #		Type
Project		
Comments		Date
Prepared by		

**Specification Features**

**Features**

- Manual ON/OFF and brightness control with the side panel push button
- Using the HALO Home app with the Lamp Dimmer you can program the following controls:
  - On/Off
  - Dimming
  - Groups
  - Scheduling
  - Scenes

**Driver**

- Grounded 3-wire power connection for safety
- Power: 120VAC, 60Hz
- For use with 110/120V compatible sockets

**Compatible Products**

- 2.5A; 300W Incandescent or 150W Dimmable CFL/LED
- Maximum load for the Bluetooth-controlled outlet: 2.5A, 300W Incandescent or 150W Dimmable CFL/LED.

**Factory Reset**

- Hold the ON button for more than 15 seconds
- Constant flashing of blue status indicator light indicates successful reset.


**Compliance**

- cULus certified
- EMI/RFI emissions per FCC 47CFR Part 15 consumer limits
- Operating Temperature Range: -30 C to +45C

**Warranty**

Five year limited warranty, consult website for details.  
www.cooperlighting.com

**Dimensions**

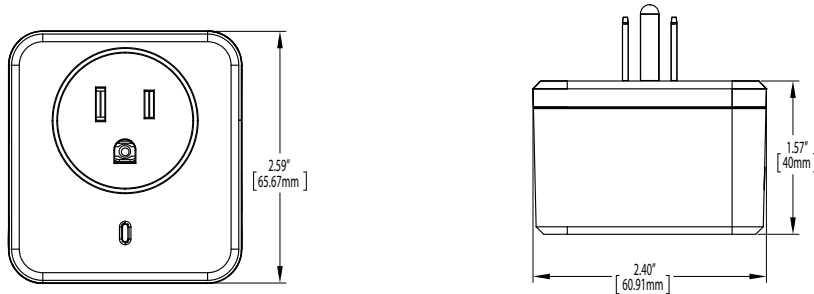

**Ordering Information**

SAMPLE NUMBER: HWP1BLE40AWH

Device	Driver	Finish
HWP1 = Smart Plug-In Lamp Dimmer	BLE40A=Bluetooth wireless mesh 4.0 control	WH=White



**HALO Home  
HWP1**

**Smart Plug-In Lamp  
Dimmer**

**Lamps Only**

