

# IC-Rated 600 Lumen Downlights, Gen 4

Refined, ultra-efficient, high-performance illumination for residential, retail and commercial applications



# Juno® IC-Rated 600 Lumen LED Downlights, Gen 4

Featuring improved 90 CRI color rendering

The Generation 4 line of recessed LED downlights is just what you'd expect from Juno. It's the most all-inclusive LED downlight lineage, including 4", 5", and 6" apertures with higher performance, better color rendering and new Patented Hyperbolic trims. Juno Generation 4 Recessed LED downlights are ENERGY STAR® certified and are compliant with the latest California Title 24 energy code.

## Juno 4" IC-Rated 600 Lumen Generation 4 LED Downlights

### 4" New Construction



Shown with universal voltage driver.

12¼" L x 6¾" W x 6" H  
Ceiling cutout: 4½"

#### IC1LED & IC1RLED G4 Series

Dedicated 4" LED new construction and remodel housings with integral light engine and choice of dimmable drivers. The eldoLED driver option delivers smooth and flicker-free deep dimming performance. Shallow housing construction allows for fit in 2 x 6 construction. Air-Loc® gasket kit (Remodel only) supplied with housing. IC housing designed for use with IC or non-IC construction. Wide flood optic provided as standard. Also available with WarmDim® technology.



### 4" Remodel



Shown with dedicated 120 volt driver.

14½" L x 4¾" W x 4¾" H  
Ceiling cutout: 4¾"

Example: IC1LED G4 06LM 27K 90CRI 120 FRPC

Series	Gen	Lumens	CCT	CRI	Distribution	Voltage/Driver	Territory
<b>IC1LED</b> 4" New Construction Housing	<b>G4</b>	<b>06LM</b> 600 Lumens	<b>27K</b> 2700K	<b>90CRI</b> 90 CRI	<b>(blank)</b> Medium Flood (45°)	<b>120 FRPC</b> 120V Only; Forward Phase/ELV Dimming	<b>CP**</b> Chicago Plenum
<b>IC1RLED</b> 4" Remodel Housing			<b>30K</b> 3000K <b>35K</b> 3500K <b>40K</b> 4000K			<b>MVOLT ZT10</b> Multi-Volt (120-277V), 0-10, 10% dim	
					<b>WFL</b> Wide Flood (65°)	<b>MVOLT ZT1</b> Multi-Volt (120-277V), 0-10, 1% dim	
						<b>MVOLT EZ1*</b> Multi-Volt (120-277V) eldoLED 0-10V, 1% dim	
						<b>MVOLT EZ10*</b> Multi-Volt (120-277V) eldoLED 0-10V, 10% dim	

\*A+ Capable

\*\*New Construction Only

Refer to the specification sheet for the list of factory qualified dimmer model numbers.



A+ Capable configurations support A+ Certified Solutions. A+ Certified solutions from Acuity Brands help you quickly and confidently select and implement lighting systems that are both compatible and consistent. Go to [www.acuitybrands.com/APLUS](http://www.acuitybrands.com/APLUS) or contact your local Acuity Brands representative for more information.

## 4" LED Downlight Trims

### Downlights



**Pinhole with Integral Shield**  
**13 WH**  
2" Aperture



**Baffle**  
**14 BWH** Black  
**14 BSC** Black  
**14 BBRZ** Black  
**14 BBL** Black  
**14 BWH** White  
3¾" Aperture



**Cone**  
**17 CWH** Clear Alzak®  
**17 GWH** Gold Alzak®  
**17 BWH** Black Alzak®  
**17 PTSC** Pewter Alzak®  
**17 WWH** Gloss White  
**17 HZWH** Haze  
**17 WHZWH** Wheat Haze  
**17 WHZBRZ** Wheat Haze  
3¾" Aperture

### Decorative



**Beveled Cylinder**  
**4103 FROSTWH**  
**4103 FROSTSC**  
3" Aperture



**Beveled Cone**  
**4104 HZSC** Haze  
**4104 WHZABZ** Wheat Haze  
3¾" Aperture



**Glass Cylinder**  
**4150 MESHSC**  
2½" Aperture

### Patented Hyperbolic



**17HYP2 CWH** Clear Alzak®  
**17HYP2 BWH** Black Alzak®  
**17HYP2 WWH** White  
**17HYP2 HZWH** Haze  
**17HYP2 WHZWH** Wheat Haze  
**17HYP2 WHZBRZ** Wheat Haze

 
### Lensed



**Wall Wash**  
**39 CWH** Clear Alzak®  
**39 HZWH** Haze  
**39 WWH** Gloss White  
**39 WHZWH** Wheat Haze



**Drop Opal**  
**11 WH**



**Frosted Lens with Clear Center**  
**12 WWH**  
**12 WSC**  
**12 WBRZ**



**Beveled Dome - Lensed**  
**4101 ABZ**  
**4101 SC**  
**4101 WH**



**Beveled Lens**  
**4102 ABZ**  
**4102 SC**  
**4102 WH**


### Square Trims



**13SQ WH** White Trim



**17SQ HZWH** Haze, White Trim  
**17SQ WWH** White, White Trim  
**17SQ BWH** Black, White Trim  
**17SQ WHZWH** Wheat Haze

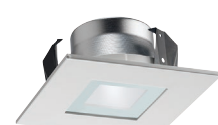

**Frosted Lens with Clear Center**  
**12SQ WWH** White Trim

# Juno 5" IC-Rated 600 Lumen Generation 4 LED Downlights

## 5" New Construction



Shown with universal voltage driver.

15 1/2" L x 9 1/8" W x 4 3/8" H  
Ceiling cutout: 5 5/8"

**IC20LED & IC20RLED G4 Series**  
Dedicated 5" LED new construction and remodel housings with integral light engine and choice of dimmable drivers. The eldoLED driver option delivers smooth and flicker-free deep dimming performance. Shallow housing construction allows for fit in 2 x 6 construction. Air-Loc gasket kit (Remodel only) supplied with housing. IC housing designed for use with IC or non-IC construction. Wide flood optic provided as standard. Also available with WarmDim® technology.



## 5" Remodel



Shown with dedicated 120 volt driver.

13 1/2" L x 5 5/8" W x 4 3/8" H  
Ceiling cutout: 5 1/2"

Example: IC20LED G4 06LM 27K 90CRI 120 FRPC

Series	Gen	Lumens	CCT	CRI	Voltage/Driver
<b>IC20LED</b> 5" New Construction Housing	<b>G4</b>	<b>06LM</b> 600 Lumens	<b>27K</b> 2700K	<b>90CRI</b> 90 CRI	<b>120 FRPC</b> 120V Only; Forward Phase/ELV Dimming
			<b>30K</b> 3000K		
			<b>35K</b> 3500K		<b>MVOLT ZT1</b> Multi-Volt (120-277V), 0-10, 1% dim
			<b>40K</b> 4000K		<b>MVOLT EZ1*</b> Multi-Volt (120-277V) eldoLED 0-10V, 1% dim
<b>IC20RLED</b> 5" Remodel Housing					<b>MVOLT EZ10*</b> Multi-Volt (120-277V) eldoLED 0-10V, 10% dim

\*A+ Capable

Refer to the specification sheet for the list of factory qualified dimmer model numbers.

**Note:** ENERGY STAR® and T24 certification is dependent on trim finish and LED color temperature. See housing spec sheet for specific information for each trim.

 
\*\*Do not use reflector shipped with trim for LED housing. Discard or recycle reflector.



A+ Capable configurations support A+ Certified Solutions. A+ Certified solutions from Acuity Brands help you quickly and confidently select and implement lighting systems that are both compatible and consistent. Go to [www.acuitybrands.com/APlus](http://www.acuitybrands.com/APlus) or contact your local Acuity Brands representative for more information.

## 5" LED Downlight Trims

### Downlights



#### Downlight Baffle

205 WWH White  
205 BWH Black  
205 BSC Black  
205 BBRZ Black

4 3/8" Aperture



#### Downlight Cone

204 CWH Clear Alzak®  
204 GWH Gold Alzak®  
204 BWH Black Alzak®  
204 PTSC Pewter Alzak®  
204 WWH Gloss White  
204 HZWH Haze  
204 WHZWH Wheat Haze  
204 WHZBRZ Wheat Haze

4 3/8" Aperture

### Wall Wash



213G3 WWH White  
213G3 BWH Black

### Patented Hyperbolic



204HYP2 CWH Clear Alzak®  
204HYP2 BWH Black Alzak®  
204HYP2 WWH White  
204HYP2 HZWH Haze  
204HYP2 WHZWH Wheat Haze  
204HYP2 WHZBRZ Wheat Haze

### Lensed



#### Flat Glass Shower Trim\*\*

210N ABZ  
210N SC  
210N WH



#### Frosted Lens with Clear Center\*\*

212N BRZ  
212N SC  
212N WH



#### White Baffle, Regressed Frosted Dome Lens\*\*

2130 WWH White  
2130 BWH Black



#### Beveled Frame, Frosted Dome Lens\*\*

5101 ABZ  
5101 SC  
5101 WH



# Juno 6" IC-Rated 600 Lumen Generation 4 LED Downlights

## 6" New Construction



Shown with universal voltage driver.

15¼" L x 9⅞" W x 4⅞" H  
Ceiling cutout: 6⅞"

### IC22LED & IC22RLED G4 Series

Dedicated 6" LED new construction and remodel housings with integral light engine and choice of dimmable drivers. The eldoLED driver option delivers smooth and flicker-free deep dimming performance. Shallow housing construction allows for fit in 2 x 6 construction. Air-Loc® gasket kit (Remodel only) supplied with housing. IC housing designed for use with IC or non-IC construction. Wide flood optic provided as standard. Also available with WarmDim® technology.



## 6" Remodel



Shown with dedicated 120 volt driver.

14½" L x 7¼" W x 5⅞" H  
Ceiling cutout: 6⅞"

Example: IC22LED G4 06LM 27K 90CRI 120 FRPC

Series	Gen	Lumens	CCT	CRI	Distribution	Voltage/Driver			
IC22LED 6" New Construction Housing	G4	06LM 600 Lumens	27K 2700K 30K 3000K 35K 3500K 40K 4000K	90CRI 90 CRI	(blank) Medium Flood (45°)	120 FRPC 120V Only; Forward Phase/ELV Dimming			
		IC22RLED 6" Remodel Housing						WFL Wide Flood (65°)	MVOLT ZT10 Multi-Volt (120-277V), 0-10, 10% dim
								MVOLT ZT1 Multi-Volt (120-277V), 0-10, 1% dim	
						MVOLT EZ1* Multi-Volt (120-277V) eldoLED 0-10V, 1% dim			
						MVOLT EZ10* Multi-Volt (120-277V) eldoLED 0-10V, 10% dim			

\*A+ Capable

Refer to the specification sheet for the list of factory qualified dimmer model numbers.

**Note:** ENERGY STAR® and T24 certification is dependent on trim finish and LED color temperature. See housing spec sheet for specific information for each trim.

\*\*Do not use reflector shipped with trim for LED housing. Discard or recycle reflector.



A+ Capable configurations support A+ Certified Solutions. A+ Certified solutions from Acuity Brands help you quickly and confidently select and implement lighting systems that are both compatible and consistent. Go to [www.acuitybrands.com/APIus](http://www.acuitybrands.com/APIus) or contact your local Acuity Brands representative for more information.

Photo Credits:

Cover: Private Residence, St. Charles, IL (Pictureboy Photography)



All trademarks referenced are property of their respective owners. Specifications subject to change without notice. Printed in the U.S.A.

## 6" LED Downlight Trims

### Downlights



#### Downlight Baffle

24 WWH White  
24 BWH Black  
24 BSC Black  
24 BBRZ Black  
24 BBL Black

5¾" Aperture



#### Downlight Cone

27 CWH Clear Alzak®  
27 GWH Gold Alzak®  
27 BWH Black Alzak®  
27 PTSC Pewter Alzak®  
27 WWH Gloss White  
27 HZWH Haze  
27 WHZWH Wheat Haze  
27 WHZBRZ Wheat Haze

5¾" Aperture

### Decorative



#### Octagonal

9024 WWH  
5¾" Aperture



#### Luminous Disc (Frosted)

9324 SC  
3¼" Aperture



#### Metal Band

9524 SC  
5⅞" Aperture



#### Luminous Collar (Frosted)

9702  
6⅜" Aperture

### Wall Wash



#### Wall Wash

262G3 WWH White  
262G3 BWH Black

### Lensed



#### Albalite

20 PW Shower/Closet Light  
20 WH



#### Drop Opal

21 PW Shower/Closet Light  
21 WH



#### Fresnel

22 WH



#### Frosted Lens\*\*

239 WH



#### Frosted Lens with Clear Center

242 BRZ  
242 SC  
242 WH



#### Decorative Swirled Etched Opal Glass\*\*

243 WH



#### White Baffle, Regressed Frosted Dome Lens\*\*

2330 WWH White  
2330 BWH Black



#### Beveled Frame, Frosted Dome Lens\*\*

6101 ABZ  
6101 SC  
6101 WH

### Patented Hyperbolic



27HYP2 CWH Clear Alzak®  
27HYP2 BWH Black Alzak®  
27HYP2 WWH White  
27HYP2 HZWH Haze  
27HYP2 WHZWH Wheat Haze  
27HYP2 WHZBRZ Wheat Haze