


REMOVABLE CAP
TO TIGHTEN SCREW
(REPLACE WHEN COMPLETE)

REMOVABLE CAP
FOR DUAL ENTRY
(INSERT IN OTHER SIDE)


IPLD350-5 SHOWN

PART NUMBER	NO. OF PORTS	LENGTH
IPLD350-3	3	3.52
IPLD350-4	4	4.57
IPLD350-5	5	5.62
IPLD350-6	6	6.67
IPLD350-8	8	8.77
IPLD350-10	10	10.87
IPLD350-11	11	11.92
IPLD350-12	12	12.97
IPLD350-13	13	14.02
IPLD350-14	14	15.07
IPLD350-16	16	17.17
IPLD350-18	18	19.27

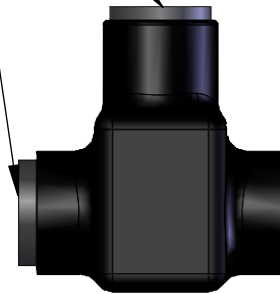

WIRE ENTRY POINT
WIRE RANGE: 350MCM - #10AWG
PRE-FILLED W/ OXIDE INHIBITOR

5/16 INTERNAL HEX PRESSURE SCREW

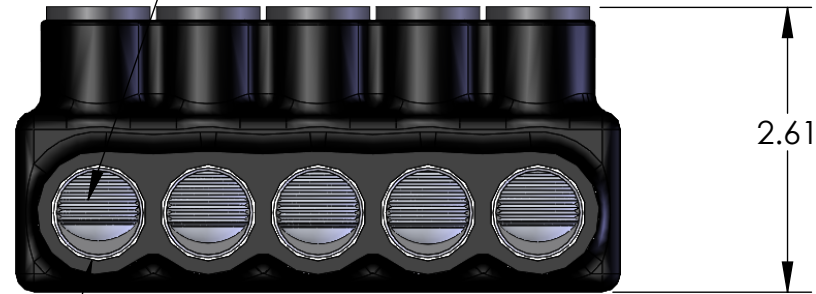

CONTACT NSi FOR SALES @ 800.321.5847

		POLARIS SALES . CO . INC	
PROPRIETARY AND CONFIDENTIAL		11625 PROSPEROUS DRIVE ODESSA, FL 33556	
THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF POLARIS SALES CO. INC. ANY REPRODUCTION IN PART OR AS A WHOLE WITHOUT THE WRITTEN PERMISSION OF POLARIS SALES CO. INC. IS PROHIBITED.		TITLE: INSULATED DUAL ENTRY 350 CONNECTOR	
NAME	DATE	DWG. NO. IPLD350-SERIES	
DRAWN BY L. HILL	8-6-09		
MATERIAL: N/A		SCALE: 1:2	SHEET: 1 OF 1

NOTES:

- CONNECTOR MANUFACTURED FROM 6061-T6 ALUMINUM ALLOY.
- UL LISTED PER UL486A/B SPECIFICATIONS FOR 600V.
- DUAL RATED FOR 90°C COPPER AND/OR ALUMINUM CONDUCTOR.
- COLD TEMPERATURE RATED TO -45°C.
- HIGH DIELECTRIC STRENGTH INSULATION IS ABRASION, CHEMICAL AND UV RESISTANT.