



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685



## KLKR3 3A 600V Fa Class CC Fuse

Littelfuse

Catalog Number	KLKR3
Manufacturer	Littelfuse
Description	Class CC Fuse, V Ac:200 Ka (RMS Symmetrical);V DC:20 Ka (Self-Certified) Response Time, 3 A, 600 V Ac:300 V DC, Melamine (Body) Material, 0.41 In Diameter, 1.50 In Overall Length, 0.03 LB
Weight per unit	0.0300 (lbs/each)
Product Category	Renewable & Non-Renewable

### Descriptions

Description	3A 600V FA CLASS CC FUSE
Special Features	Fast-Acting

### Manufacturer Information

GTIN	00079458260472
sub brand	KLKR Series
UPC	079458260472

### Taxonomies, Classifications, and Categories

Category Description	MIDGET FUSES
Type	CLASS CC

### Packaging

Carton	1
Package	10
Weight Per each	0.03

### Uses, Certifications, and Standards

standard	248-4 UL Listed/CSA
----------	---------------------

# CLASS CC KLKR SERIES FUSES

600 VAC • 300 VDC • Fast-Acting • 1/10-30 A



## Description

KLKR Series Class CC fuses are fast-acting fuses intended for general purpose branch circuit protection. Their compact size, fast-acting overload response, and highly current-limiting design make them ideal for use in OEM equipment and control panels.

## Features/Benefits

- Meets UL and CSA standards
- Class CC fuses are the smallest 600 V, 200,000 A.I.R. fuses approved for branch circuit protection
- Rejection feature prevents use of fuses with lower interrupting ratings or voltage ratings when used with corresponding fuse holders
- Extremely current limiting reduces damage caused by heating and magnetic effects of short-circuit currents

## Applications

- General purpose protections for equipment requiring fast overload protection

## Specifications

<b>Voltage Rating</b>	AC: 600 V DC: 300 V
<b>Amperage Rating</b>	1/10 – 30 A
<b>Interrupting Rating</b>	AC: 200 kA rms symmetrical DC: 20 kA
<b>Material</b>	Body: Melamine Caps: Nickel-plated Bronze
<b>Fuse Weight</b>	1/10 – 1 A: .030 lb (13.61g) 1 1/2 – 30 A: .034 lb (15.42g)
<b>Approvals</b>	AC: Standard 248-4, Class CC UL Listed 1/10-30 A (File: E81895) CSA Certified 1/10-30 A (File: LR29862) DC: Littelfuse self-certified
<b>Environmental</b>	RoHS Compliant
<b>Country of Origin</b>	Mexico

## Ordering Information

AMPERAGE RATINGS				
1/10	1/2	2 1/2	6	12
1/8	3/4	3	7	15
2/10	1	3 1/2	8	20
1/4	1 1/2	4	9	25
3/10	2	5	10	30

AMPERAGE	PART NUMBER	ORDERING NUMBER
12	KLKR 12	KLKR012.T


## Web Resources

For additional informations, visit:  
[www.littelfuse.com/klkr](http://www.littelfuse.com/klkr)

## Recommended Fuse Holders

L60030C Series  
LPSC Touch-Safe Series

## Dimensions Inches (mm)

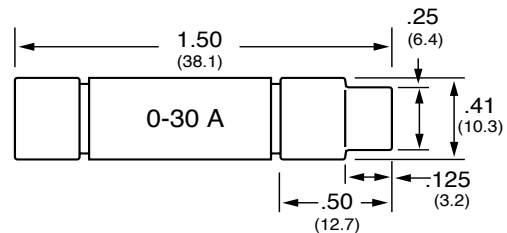

# CLASS CC KLKR SERIES FUSES

## Electrical Specifications

ORDERING NUMBER	AMPERAGE RATING	VOLTAGE RATING		INTERRUPTING RATING		WATTS LOSS AT 100% RATED CURRENT (W)	WATTS LOSS AT 80% RATED CURRENT (W)	TOTAL CLEARING I <sup>2</sup> T (A <sup>2</sup> SEC) 200 kA	AGENCY APPROVALS		RoHS
		AC	DC	AC	DC				UL	CSA	
KLKR001.T	1	600	300	200 kA	20 kA	0.38	0.20	80	•	•	•
KLKR006.T	6	600	300	200 kA	20 kA	1.36	0.77	210	•	•	•
KLKR012.T	12	600	300	200 kA	20 kA	1.58	0.83	6520	•	•	•
KLKR015.T	15	600	300	200 kA	20 kA	2.3	1.37	314	•	•	•
KLKR020.T	20	600	300	200 kA	20 kA	2.3	1.39	900	•	•	•
KLKR030.T	30	600	300	200 kA	20 kA	3.75	2.10	1720	•	•	•

## Peak Let-Thru Curve

