



KT-VTLED19-2A-8XX-VDIM-P

VAPOR TIGHT FIXTURE

DESCRIPTION

2' 19W LED Vapor Tight Fixture | 120–277V Input | 0–10V Dimming | Premium Series

APPLICATION

Used for commercial and industrial rugged or outdoor applications



PRODUCT FEATURES


- Traditional design, narrow body, Vapor Tight fixture, suitable for rugged, demanding applications
- Powered by Keystone 120-277V, 0–10V dimming LED driver, 10% minimum
- Smooth, diffused, impact resistant polycarbonate lens provides even lit appearance
- Stainless steel, tamper resistant lens clips (screws not included)
- Includes mounting hardware, cordgrip, and hole plug for out-of-the-box installation
- Compatible with Keystone motion and occupancy sensors, featuring high-end trim and daylight sensing.
- NEMA 4X rated enclosure
- IP66 Ingress Protection
- IK10 Impact Rating
- Ambient operating temperature: -40°C/-40°F to 50°C/122°F
- LED chip lifetime: L70 >100,000 hours @ 25°C/77°F ambient fixture temperature
- PF: > 0.95
- THD: < 20%
- UL Certified for Wet Locations
- ETL Sanitation Listed NSF/ANSI Standard 2 - Food Equipment, Splash Zone (Not for Direct Food Zone)
- DesignLights Consortium® (DLC) qualified product. *Not all product variations listed on this page are DLC premium. Visit <https://qpl.designlights.com> to confirm if the product meets the DLC Standard or Premium designation*

PRODUCT SPECIFICATIONS

Catalog Number	Color Temperature	Nominal Length	Input Voltage	Wattage	CRI	Lumen Output	Efficacy
KT-VTLED19-2A-840-VDIM-P	4000K	2 ft.	120–277V	19W	> 82.0	2,430	128 lm/W
KT-VTLED19-2A-850-VDIM-P	5000K	2 ft.	120–277V	19W	> 82.0	2,465	130 lm/W

PHOTOMETRIC SPECIFICATIONS

LUMINOUS INTENSITY DISTRIBUTION

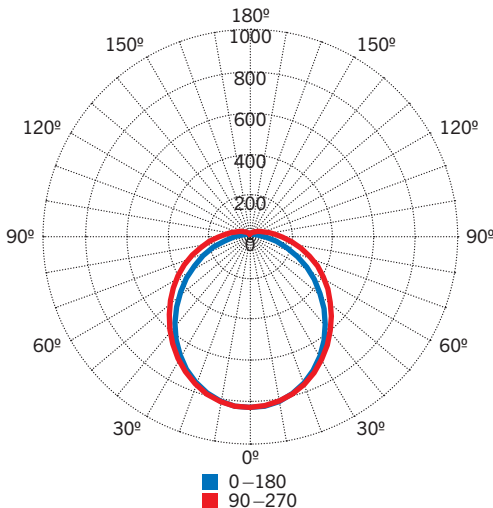

ZONAL LUMEN SUMMARY

Degree	Flux (Lumens)	% Luminaire	Degree	Flux (Lumens)	% Luminaire
0~10°	78.3 lm	3.10%	0~100°	2,471.5 lm	97.95%
0~20°	300.8 lm	11.92%	0~110°	2,500.7 lm	99.11%
0~30°	633.1 lm	25.09%	0~120°	2,514.1 lm	99.64%
0~40°	1,026.4 lm	40.68%	0~130°	2,519.0 lm	99.83%
0~50°	1,429.2 lm	56.64%	0~140°	2,520.4 lm	99.89%
0~60°	1,796.7 lm	71.21%	0~150°	2,521.5 lm	99.93%
0~70°	2,094.0 lm	82.99%	0~160°	2,522.4 lm	99.97%
0~80°	2,298.9 lm	91.11%	0~170°	2,523.0 lm	99.99%
0~90°	2,413.3 lm	95.65%	0~180°	2,523.2 lm	100.00%



KT-VTLED19-2A-8XX-VDIM-P

VAPOR TIGHT FIXTURE

ACCESSORIES

SENSORS

Factory-Installable OR Field-Installable (field-installable purchased separately)

✓	SUFFIX*	CATALOG NUMBER	DESCRIPTION	UPC	EASY CODE
	/MW3	KTS-MW3-UV-KO-K2	Microwave Multifunction Occupancy/Daylight Sensor Kit, Includes 120-277V input to 12V DC convertor, IP65 12V input sensor head, nomex sleeve, extension neck	843654134352	TBV-76




* For factory installation of accessory, add suffix to fixture part number (see ordering examples and instructions on last page of spec sheet).

CORD SETS

Factory-Installable OR Field-Installable (field-installable purchased separately)

✓	SUFFIX*	CATALOG NUMBER	DESCRIPTION	UPC	EASY CODE
	/515P6	KT-CS-515P-6-18/3	Cord set for high bay; 125V NEMA 5-15P; straight blade plug; 6' SJTOW cable; 18/3 wire	843654140124	UKH-26
	/L715P10	KT-CS-L715P-10-16/3	Cord set for high bays; 277V NEMA L7-15P; twist lock plug; 10' SJTOW cable; 16/3 wire	843654140131	SFV-88
	/L615P10	KT-CS-L615P-10-16/3	Cord set for high bays; 250V NEMA L6-15P; twist lock plug; 10' SJTOW cable; 16/3 wire	843654140148	ZQS-05
	/L515P10	KT-CS-L515P-10-16/3	Cord set for high bays; 125V NEMA L5-15P; twist lock plug; 10' SJTOW cable; 16/3 wire	843654140155	GVH-22
	/L715P6	KT-CS-L715P-6-16/3	Cord set for high bays; 277V NEMA L7-15P; twist lock plug; 6' SJTOW cable; 16/3 wire	843654140162	DVU-44
	/L615P6	KT-CS-L615P-6-16/3	Cord set for high bays; 250V NEMA L6-15P; twist lock plug; 6' SJTOW cable; 16/3 wire	843654140179	LCW-66
	/L515P6	KT-CS-L515P-6-16/3	Cord set for high bays; 125V NEMA L5-15P; twist lock plug; 6' SJTOW cable; 16/3 wire	843654140186	POC-82
	/NP10	KT-CS-NP-10-16/3	Cord for high bays; no plug; inners 1/2" strip on both ends; 10' SJTOW cable; 16/3 wire	843654140193	YOH-90
	/NP6	KT-CS-NP-6-16/3	Cord for high bays; no plug; inners 1/2" strip on both ends; 6' SJTOW cable; 16/3 wire	843654140216	HUB-73
	/NP15	KT-CS-NP-15-16/3	Cord for high bays; no plug; inners 1/2" strip on both ends; 15' SJTOW cable; 16/3 wire	843654140209	EYD-18

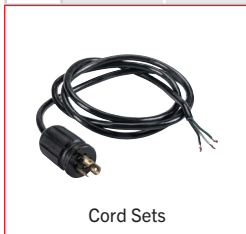

* For factory installation of accessory, add suffix to fixture part number (see ordering examples and instructions on last page of spec sheet).
Note: For cord sets not listed here, please contact your Keystone sales rep.

(Accessories continued on next page)



KT-VTLED19-2A-8XX-VDIM-P

VAPOR TIGHT FIXTURE

MOUNTS AND BRACKETS

Field-Installable / Field-Use ONLY (purchased separately)

CATALOG NUMBER	DESCRIPTION	UPC	EASY CODE
KT-VTLED-45SM-1-KIT	45° steel surface mount kit for all Keystone vapor tight fixtures	843654123455	JDN-49
KT-VTLED-TPSCREW-KIT	Screws for tamper-proofing vapor tight fixtures. Includes 14 screws	NA	NA



Screws
KT-VTLED-TPSCREW-KIT


(Accessories continued on next page)



KT-VTLED19-2A-8XX-VDIM-P

VAPOR TIGHT FIXTURE

PHYSICAL SPECIFICATIONS

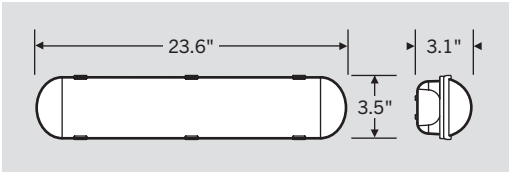

ORDERING INFORMATION

CATALOG NUMBER	PACK QUANTITY	UPC	EASY CODE	DLC PRODUCT ID
KT-VTLED19-2A-840-VDIM-P-CP	4	843654122113	PJU-14	PXB0LJOW
				PLTP9MN4
KT-VTLED19-2A-850-VDIM-P-CP	4	843654122120	MJJ-77	P5G4KSEA
				PUG7HVIE

CATALOG NUMBER BREAKDOWN

KT-VTLED19-2A-8XX-VDIM-P

1	2	3	4	5	6	7	8	9	10				
1 Keystone Technologies	2 Vapor Tight LED Fixture	3 Wattage	4 2' Nominal Length	5 Lamp Type	6 80 CRI	7 Color Temperature	8 0–10V Dimming	9 Premium Series	10 Sensor Options				
								<table border="1"> <tr> <td></td> <td>No Option</td> </tr> <tr> <td>/MW3</td> <td>Microwave Sensor Included</td> </tr> </table>			No Option	/MW3	Microwave Sensor Included
	No Option												
/MW3	Microwave Sensor Included												

ORDERING EXAMPLES

FIXTURE WITH MULTIPLE FACTORY-INSTALLED ACCESSORIES*

KT-VTLED19-2A-8XX-VDIM-P/MW3/NP10/TPSCREW

FIXTURE WITH TWO FACTORY-INSTALLED ACCESSORIES*

KT-VTLED19-2A-8XX-VDIM-P/MW3/NP10

FIXTURE WITH SINGLE FACTORY-INSTALLED ACCESSORY

KT-VTLED19-2A-8XX-VDIM-P/MW3

FIXTURE WITH NO FACTORY-INSTALLED ACCESSORIES

KT-VTLED19-2A-8XX-VDIM-P

KEYSTONE FIXTURE

CATALOG NUMBER
KT-VTLED19-2A-8XX-VDIM-P

SENSORS

✓ SUFFIX	CATALOG NUMBER
✓ /MW3	KTS-MW3-UV-KO-K2

CORD SETS

✓ SUFFIX	CATALOG NUMBER
✓ /NP10	KT-CS-NP-10-16/3

MOUNTS AND BRACKETS

✓ SUFFIX	CATALOG NUMBER
✓ /TPSCREW	KT-VTLED-TPSCREW-KIT

* When ordering more than one factory-installed accessory, use multiple suffixes as shown in the ordering examples above.
 Note: All accessories can also be ordered separately for field installation using just their regular Catalog Number, UPC, or Easy Code.