



# ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

## KT-LED4.5FST19-E26-822-A REPLACEMENT LAMP

### DESCRIPTION


4.5W ST19 Shape | 2200K | >80 CRI | Edison Shape Amber Bulb



RoHS  
Compliant

**2YEAR**  
WARRANTY

<b>LAMP TYPE:</b> Filament ST19
<b>BASE TYPE:</b> E26 (Medium)
<b>WATTAGE:</b> 4.5W
<b>COLOR TEMPERATURE:</b> 2200K
<b>COLOR RENDERING INDEX (CRI):</b> >80
<b>WARRANTY:</b> 2 Years
<b>RATED LIFE:</b> L70 (15,000 Hours)

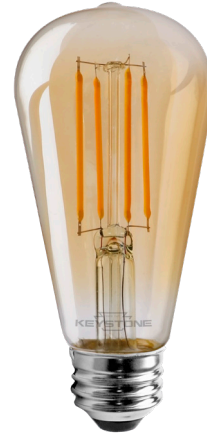

### TYPICAL APPLICATIONS

- Chandeliers
- Vanity Fixtures
- Decorative Accent Lighting
- Wall Sconces
- Pendant Lights

### PRODUCT FEATURES

- Energy Efficient, 80%+ Energy Savings over Legacy Equivalents
- Lower Heat Generation than Legacy Equivalents
- Filament style LED construction offers unique traditional appearance for decorative and mood sensitive applications
- PF >0.60
- Complies with Part 15 of FCC
- Smooth, uniform dimming
- Operating temperature range -4°F/-20°C to 95°F/35°C
- Long Life minimizes replacement and maintenance costs
- ANSI complaint construction ensures fitment for intended applications
- Meets Energy Star requirements
- UL Listed

### ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Light Distribution	Dimmable	Efficacy
KT-LED4.5FST19-E26-822-A	ST19 bulb. Amber edison bulb, dimmable	2200K	120V	4.5W	40W halogen	E26	350	>80	360°	Yes	78 lm/W




# ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

## KT-LED4.5FST19-E26-822-A REPLACEMENT LAMP

### PHYSICAL CHARACTERISTICS

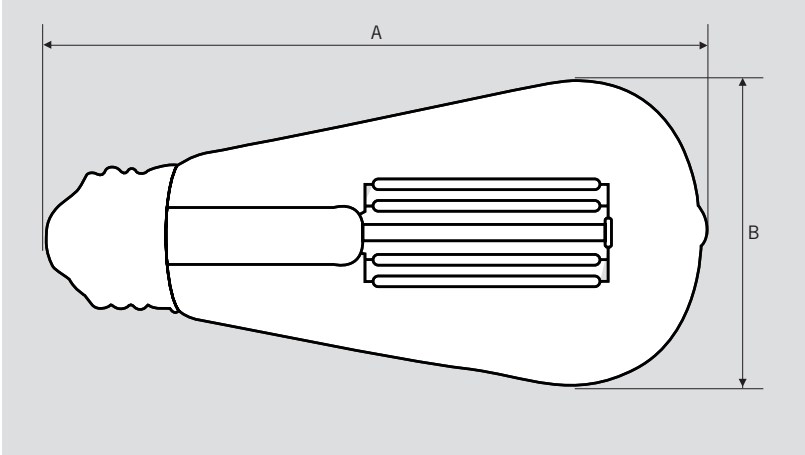

### PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	10.24" x 7.87" x 12.20"
Carton Weight	5.3 lbs

### LAMP DIMENSIONS

A (Length)	4.92"
B (Diameter)	2.28"

BASE TYPE: E26 (Medium)

### ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ITEM STATUS
KT-LED4FST19-E26-822-A	24 pcs	Active

### CATALOG NUMBER BREAKDOWN

# KT-LED4.5FST19-E26-822-A

1 2 3 4 5 6 7 8 9

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Filament Bulb
- 5 Lamp Shape
- 6 Base Type
- 7 800 Series
- 8 Color Temperature
- 9 Amber Bulb