



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED5.5FG25-E26-9XX-C

REPLACEMENT LAMP

DESCRIPTION

5.5W G25 Lamp | 2700–5000K | ≥90 CRI | Clear Globe



LAMP TYPE: Filament G25

BASE TYPE: E26 (Medium)

WATTAGE: 5.5W

COLOR TEMPERATURE: 2700–5000K

COLOR RENDERING INDEX (CRI): ≥90

WARRANTY: 3 Years

RATED LIFE: L70 (15,000 Hours)



TYPICAL APPLICATIONS

- Chandeliers
- Vanity Fixtures
- Decorative Accent Lighting
- Wall Sconces
- Pendant Lights

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, uniform dimming
- Filament-style LED construction offers unique traditional appearance for decorative and mood-sensitive applications
- HiCRI LEDs offer enhanced color rendering vs. 80 CRI LEDs, providing ideal clarity, representation, uniformity of illuminated area/objects
- Long life minimizes replacement and maintenance costs
- Suitable for use in damp locations
- Operating temperature range –4°F/–20°C to 95°F/35°C
- PF >0.70
- Rated for open, recessed, and enclosed fixtures
- ANSI compliant construction ensures fitment for intended applications
- UL Listed
- Meets Energy Star requirements
- Complies with Part 15 of FCC
- Title 20 compliant

ELECTRICAL AND PERFORMANCE SPECIFICATIONS


Keystone Catalog Number	Description	Color Temp*	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Lumens	Efficacy	CRI	Base Type	Beam Angle	Dimmable
KT-LED5.5FG25-E26-927-C	G25 filament globe bulb; Clear; Dimmable	2700K	120V	5.5W	60W incandescent	500 lm	91 lm/W	≥90	E26	360°	Yes
KT-LED5.5FG25-E26-930-C	G25 filament globe bulb; Clear; Dimmable	3000K	120V	5.5W	60W incandescent	500 lm	91 lm/W	≥90	E26	360°	Yes
KT-LED5.5FG25-E26-950-C	G25 filament globe bulb; Clear; Dimmable	5000K	120V	5.5W	60W incandescent	500 lm	91 lm/W	≥90	E26	360°	Yes

* Color Uniformity: CCT (Correlated Color Temperature) range as per guidelines outlined in ANSI C78.377-2017

KT-LED5.5FG25-E26-9XX-C

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

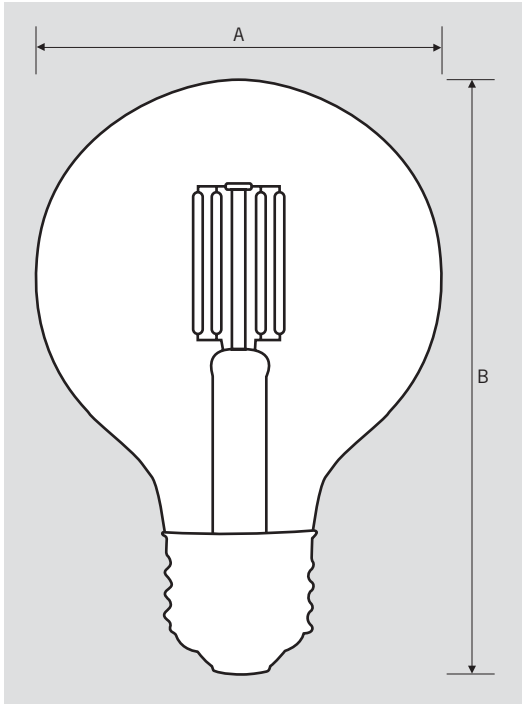

LAMP DIMENSIONS

A (Diameter)	3.15"
B (Length)	4.53"

BASE TYPE: E26 (Medium)

RATED LIFE

L70 (Hours)	15,000
-------------	--------

PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	15.54" × 11.42" × 11.82"
Carton Weight	5.52 lbs

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ITEM STATUS	EASY CODE	UPC
KT-LED5.5FG25-E26-927-C	24 pcs	Active	USC-83	843654123790
KT-LED5.5FG25-E26-930-C	24 pcs	Active	OUQ-04	843654123806
KT-LED5.5FG25-E26-950-C	24 pcs	Active	DUY-22	843654123813

CATALOG NUMBER BREAKDOWN

KT-LED5.5FG25-E26-9XX-C

1 2 3 4 5 6 7 8 9

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Filament Bulb
- 5 Lamp Shape
- 6 Base Type
- 7 900 Series
- 8 Color Temperature
- 9 Clear Bulb