



LED Beveled Recessed Downlights

Product Specifications



For quick, easy, and affordable LED upgrades, switch to TCP’s LED Downlights. TCP downlights have both E26 and direct wire options, PMMA plastic to prevent lens discoloration, and quick snap holding arms to quickly attach to a recessed can. With the new beveled look, these downlights provide smooth even light in the color temperature you need.

Reasons to choose the LED Recessed Downlights from TCP

- Long, 35,000 hour life minimizes replacement and maintenance costs
- Excellent color consistency and CRI enhances colors of the focal point while maintaining uniformity throughout lighting installation
- Very low heat generation makes the downlight perfect for sensitive display lighting
- Durable PMMA plastic housing prevents discoloration
- Easy installation that mounts directly to either a 4” or 6” recessed can, as well as both E26 and direct wire power options
- Smooth, uniform dimming from 100 - 5%

Ideal Applications

- Commercial
- Industrial
- Retail
- Residential
- Healthcare

Specifications:

Color Temperatures 2700K, 3000K, 4100K, 5000K
 Wattage options 11W, 12W, 16.5W
 Input Line Voltage 120 VAC
 Input Line Frequency 50/60HZ
 Lamp Life (Rated) 35,000 hours

Minimum Starting Temp -22°F/-30°C
 Maximum Operating Temp 104°F/40°C
 CRI 80
 IC-rated for direct contact with insulation
 UL approved for damp location (indoor only)—outdoor environment may cause yellowing of the white trim. This is not covered by warranty.




Specifications:



6 inch Dimmable
Downlight



4 inch Dimmable
Downlight

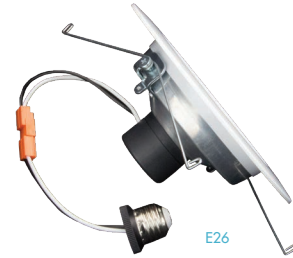

E26



Direct Wire

ITEM #	DESCRIPTION	VOLTAGE	WATTS	INCANDESCENT WATTS	LPW	LUMENS	COLOR	HOURS	CRI	MOL (inches)	DIA (inches)	BEAM ANGLE	BASE	WARRANTY YEARS
LED 75W Equivalent Options														
11W DR4 Downlight • Dimmable • 35,000 Hour														
L75DR4D3527K	LED 11W DR4 DIM 2700K	120V	11	75	77.3	850	2700K	35,000	80	3.0	5	120°	E26	5
L75DR4D3530K	LED 11W DR4 DIM 3000K	120V	11	75	77.3	850	3000K	35,000	80	3.0	5	120°	E26	5
L75DR4D3541K	LED 11W DR4 DIM 4100K	120V	11	75	77.3	850	4100K	35,000	80	3.0	5	120°	E26	5
L75DR4D3550K	LED 11W DR4 DIM 5000K	120V	11	75	77.3	850	5000K	35,000	80	3.0	5	120°	E26	5
12W DR56 Downlight • Dimmable • 35,000 Hour														
L75DR56D3527K	LED 12W DR56 DIM 2700K	120V	12	75	70.8	850	2700K	35,000	80	3.0	7.4	120°	E26	5
L75DR56D3530K	LED 12W DR56 DIM 3000K	120V	12	75	70.8	850	3000K	35,000	80	3.0	7.4	120°	E26	5
L75DR56D3541K	LED 12W DR56 DIM 4100K	120V	12	75	70.8	850	4100K	35,000	80	3.0	7.4	120°	E26	5
L75DR56D3550K	LED 12W DR56 DIM 5000K	120V	12	75	70.8	850	5000K	35,000	80	3.0	7.4	120°	E26	5
LED 120W Equivalent Options														
16.5W DR56 Downlight • Dimmable • 35,000 Hour														
L120DR56D3527K	LED 16.5W DR56 DIM 2700K	120V	16.5	120	84.8	1400	2700K	35,000	80	3.0	7.4	120°	E26	5
L120DR56D3530K	LED 16.5W DR56 DIM 3000K	120V	16.5	120	84.8	1400	3000K	35,000	80	3.0	7.4	120°	E26	5
L120DR56D3541K	LED 16.5W DR56 DIM 4100K	120V	16.5	120	84.8	1400	4100K	35,000	80	3.0	7.4	120°	E26	5
L120DR56D3550K	LED 16.5W DR56 DIM 5000K	120V	16.5	120	84.8	1400	5000K	35,000	80	3.0	7.4	120°	E26	5