



Simple **SOPHISTICATION**

Look below the surface and discover an innovative LED solution unlike any other on the market. Designed for commercial, new construction, remodel, and residential applications, the **LiteBox** surface mount embraces an installation system that is versatile, simple and seamless.

Available in 5 inch or 7 inch.



LBS5LEDA



LBSQ5LEDA



LBS5LEDA6L DG



LBSLEDA



LBSQLEDA
7" ONLY



Performance and Economy

The Surface Mount Series is leading the industry in LED technology. The state-of-the-art design eliminates the need for a traditional LED driver. The series demonstrates superior efficiency and performance providing cost-effective solutions for customers and partners.

	5" Surface Mount	7" Surface Mount
Lumens:	632	1032
Watts:	13 input power	17 input power
Voltage:	120V	120V
Life:	42,000 hours*	42,000 hours*
CRI:	90+	90+

*Flicker-free dimming to 15% with many electronic low-voltage dimmers. 5" lumen output comparable to a 65W incandescent lamp; 7" comparable to a 100W incandescent lamp

CATALOG NUMBER:

EXAMPLE: LBS5LEDA6L30K9 WH

TRIM	LED COLOR	CRI	TRIM COLOR
<input type="checkbox"/> LBS5LEDA6L 5" Round Surface Mount	<input type="checkbox"/> 30K' 3000 Kelvin	<input type="checkbox"/> 9 90+ CRI	<input type="checkbox"/> WH White
<input type="checkbox"/> LBSQ5LEDA6L 5" Square Surface Mount			



CATALOG NUMBER:

EXAMPLE: LBS5LEDA6L30K9 WH DG

TRIM	LED COLOR	CRI	TRIM COLOR	ELEMENT
<input type="checkbox"/> LBS5LEDA6L 5" Round Surface Mount	<input type="checkbox"/> 30K 3000 Kelvin	<input type="checkbox"/> 9 90+ CRI	<input type="checkbox"/> WH White	<input type="checkbox"/> DG Drop Glass




LBS5LEDA6L DG

The 5" round surface mount is now available in a decorative round LED fixture with etched glass addition, for both residential and commercial markets. LBS5LEDA6L DG is also wet location listed and is a cost effective solution for adding architectural elements to your space.

Sleek Profile
1 1/4"

5" (LBS5LEDA) & 7" (LBSLEDA and LBSQLEDA)

Surface Mount J-Box Installation

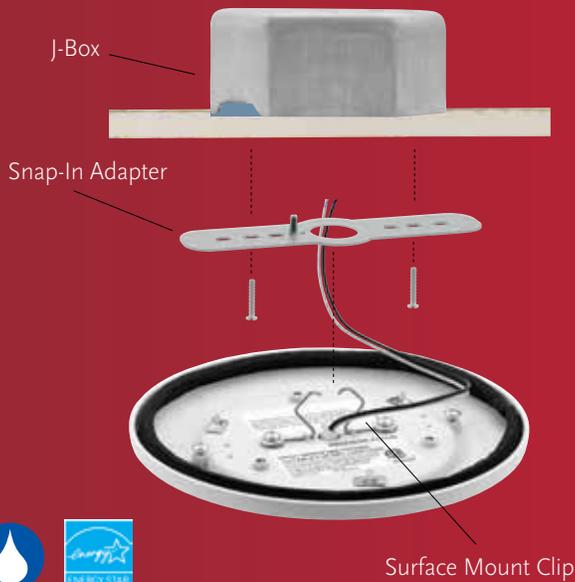

The surface mount uses an intuitive snap-in system that makes surface mount installation easier than ever. Simply install the snap-in adapter onto the junction box and connect wires. To finish the installation, snap the fixture into place using the surface mount clip. A great solution for fire rated applications when used in conjunction with a fire rated j-box.

(All hardware included)

The LBSLEDA (7" only) is also easily adapted to install into Prescolite and many competitive 4", 5", or 6" recessed cans with optional mounting kit LBSMTGKIT.



CATALOG NUMBER:

EXAMPLE: LBSLEDA10L30K9 WH

TRIM	LED COLOR	CRI	TRIM COLOR	ACCESSORIES
<input type="checkbox"/> LBSLEDA10L 7" Surface Mount Round LED Module	<input type="checkbox"/> 27K¹ 2700 Kelvin	<input type="checkbox"/> 8 80+ CRI	<input type="checkbox"/> WH White	<input type="checkbox"/> LBSMTGKIT Mounting Kit for LiteBox LED Surface fixtures to install into most 4", 5", or 6" recessed cans. Set of 8. Not required for J-Box mounting.
<input type="checkbox"/> LBSQLEDA10L 7" Surface Mount Square LED Module	<input type="checkbox"/> 30K¹ 3000 Kelvin	<input type="checkbox"/> 9 90+ CRI	<input type="checkbox"/> BL Black	
	<input type="checkbox"/> 35K¹ 3500 Kelvin		<input type="checkbox"/> Z Zet	
	<input type="checkbox"/> 40K² 4000 Kelvin		<input type="checkbox"/> BZ Bronze	
	<input type="checkbox"/> 50K² 5000 Kelvin			

Notes

¹Available only in 90 CRI

²Available only in 80 CRI





HUBBELL
Lighting, Inc.

701 Millennium Blvd.
Greenville, SC 29607
hubbellighting.com

ALERA LIGHTING

ARCHITECTURAL AREA LIGHTING

BEACON PRODUCTS

COLUMBIA LIGHTING

COMPASS

DEVINE LIGHTING

DUAL-LITE

HUBBELL BUILDING AUTOMATION

HUBBELL INDUSTRIAL LIGHTING

HUBBELL OUTDOOR LIGHTING

KIM LIGHTING

KURT VERSEN

PRESCOLITE

PROGRESS LIGHTING

SPAULDING LIGHTING

SPORTSLITER SOLUTIONS

STERNER

WHITEWAY

