
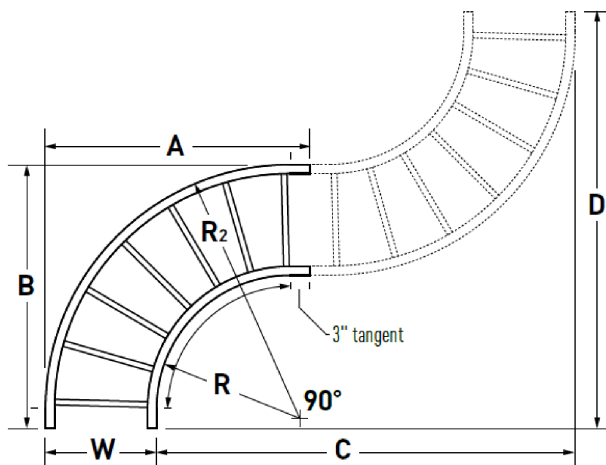
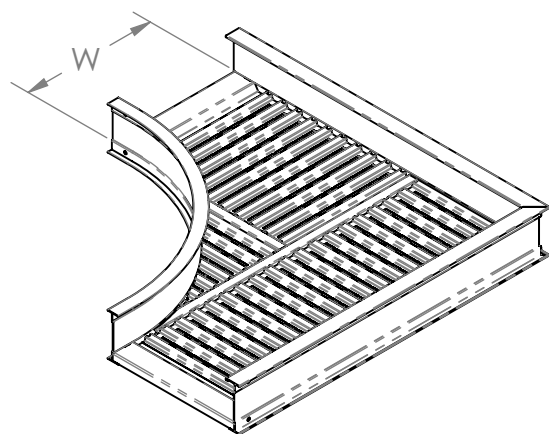


90HB
Horizontal 90° Elbow



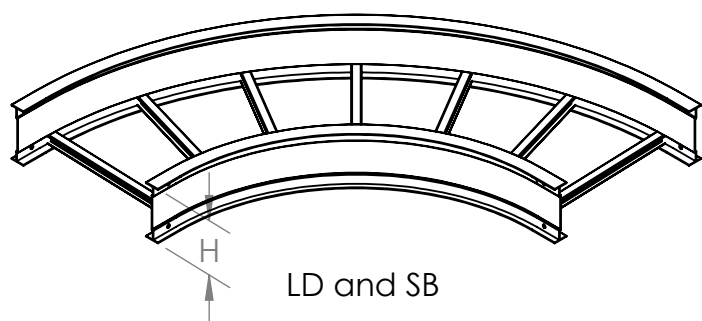


Radius R	Width W	Radius R2	A	B	C	D
12	6	18	21	21	36	36
	9	21	24	24	39	39
	12	24	27	27	42	42
	18	30	33	33	48	48
	24	36	39	39	54	54
	30	42	45	45	60	60
	36	48	51	51	66	66
24	6	30	33	33	60	60
	9	33	36	36	63	63
	12	36	39	39	66	66
	18	42	45	45	72	72
	24	48	51	51	78	78
	30	54	57	57	84	84
	36	60	63	63	90	90
36	6	42	45	45	84	84
	9	45	48	48	87	87
	12	48	51	51	90	90
	18	54	57	57	96	96
	24	60	63	63	102	102
	30	66	69	69	108	108
	36	72	75	75	114	114

ITRAY HORIZONTAL ELBOW CATALOG NUMBERING EXAMPLE:			
BOTTOM TYPE	LD - 4 A - 90 HB 12 - 06	WIDTH	
VENTED			06 - 6"
LD - Ladder Rung			09 - 9"
VC - Vented Corrugated			12 - 12"
NON-VENTED			18 - 18"
SC - Solid Corrugated			24 - 24"
SB - Solid Bottom			30 - 30"
			36 - 36"
	RAIL HEIGHT	FITTING CODE	RADIUS
	4 - 4"		12 - 12"
	5 - 5"		24 - 24"
	6 - 6"		36 - 36"
	7 - 7"		
	MATERIAL		
	A		

- **Material:** Aluminum Alloy 6063 and 5052
- **Finish:** Plain
- **Bottom:** LD: 1" wide rung
SB: Flat sheet over Rung
SC: Solid Corrugated
VC: Vented Corrugated
- **Construction:** Welded
- **Tray Design:** Tray construction and markings are per the latest edition of NEMA Standards Publication VE1, CSA C22.2 No. 126
- **Connectors:** All fittings are supplied with necessary connectors and fasteners
- **Fitting heights (H):** 4", 5", 6", 7"

90HB
Horizontal 90° Elbow

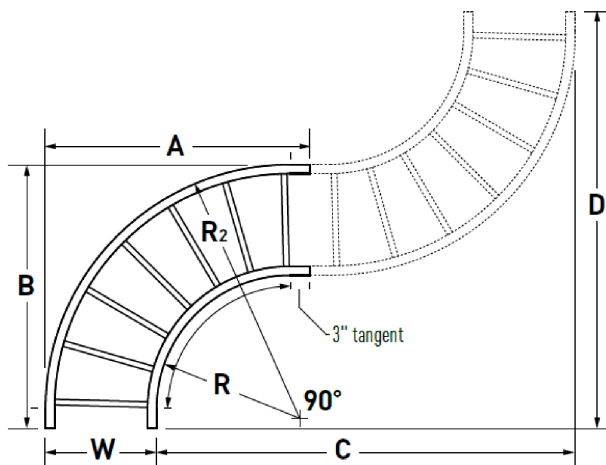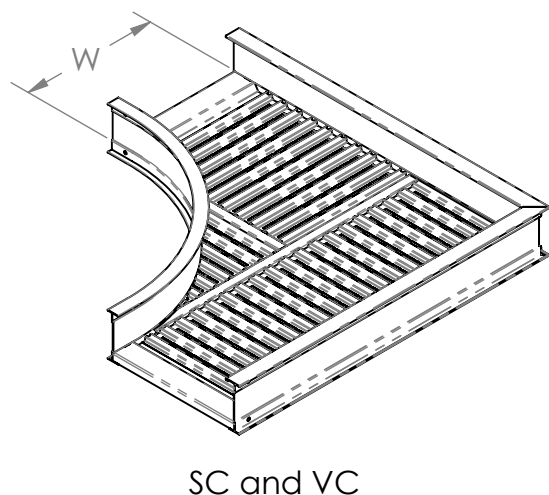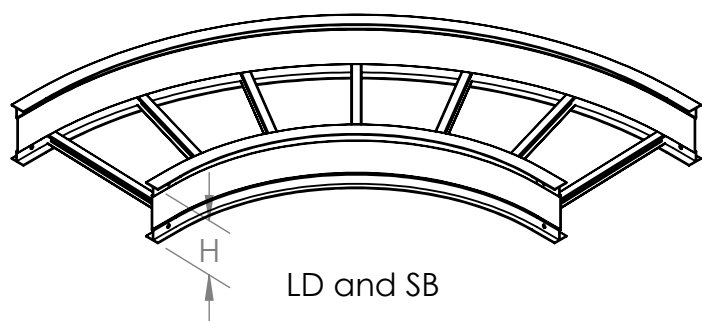

Radius R	Width W	Radius R2	A	B	C	D
12	6	18	21	21	36	36
	9	21	24	24	39	39
	12	24	27	27	42	42
	18	30	33	33	48	48
	24	36	39	39	54	54
	30	42	45	45	60	60
	36	48	51	51	66	66
24	6	30	33	33	60	60
	9	33	36	36	63	63
	12	36	39	39	66	66
	18	42	45	45	72	72
	24	48	51	51	78	78
	30	54	57	57	84	84
	36	60	63	63	90	90
36	6	42	45	45	84	84
	9	45	48	48	87	87
	12	48	51	51	90	90
	18	54	57	57	96	96
	24	60	63	63	102	102
	30	66	69	69	108	108
	36	72	75	75	114	114

ITRAY HORIZONTAL ELBOW CATALOG NUMBERING EXAMPLE:

BOTTOM TYPE		L D - 4 A - 90 H B 12 - 0 6		WIDTH	
VENTED		RAIL HEIGHT	↓	FITTING CODE	06 - 6"
LD - Ladder Rung					09 - 9"
NON-VENTED		MATERIAL	↓	RADIUS	12 - 12"
VC - Vented Corrugated					18 - 18"
SC - Solid Corrugated					24 - 24"
SB - Solid Bottom					30 - 30"
					36 - 36"

- **Material:** Aluminum Alloy 6063 and 5052
- **Finish:** Plain
- **Bottom:** LD: 1" wide rung
SB: Flat sheet over Rung
SC: Solid Corrugated
VC: Vented Corrugated
- **Construction:** Welded
- **Tray Design:** Tray construction and markings are per the latest edition of NEMA Standards Publication VE1, CSA C22.2 No. 126
- **Connectors:** All fittings are supplied with necessary connectors and fasteners
- **Fitting heights (H):** 4", 5", 6", 7"