



# Universal Surface Mount and Recessed Edgelit LED Exit Sign

## LED Edgelit Exit Signs

120 or 277 Voltage, Damp Location


### Features and Benefits:

- LED damp location exit with battery backup
- Universal 120/277 VAC dual voltage operation
- Replaceable acrylic exit panel with removable directional indicators
- Aluminum housing with high grade acrylic panel
- Removable cover for ease of installation and battery maintenance
- 90+ minute emergency operation
- Energy saving red or green LED lamps
- Damp location listed
- Suitable for indoor or outdoor applications


Catalog Number

Notes

Type

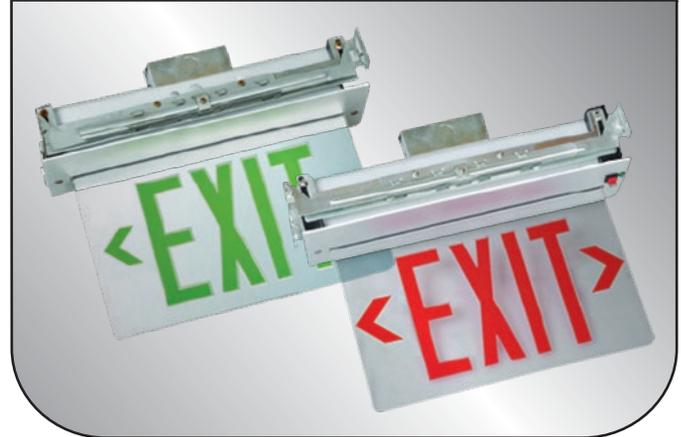

### Dimensions:

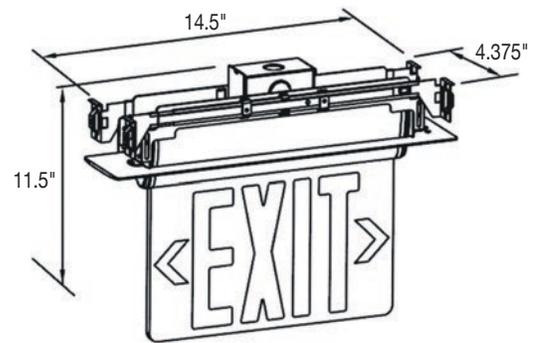

Warranties & Compliances:



Ni-Cd battery

5 YEAR WARRANTY

Unit

5 YEAR WARRANTY

LED Strip

25 YEAR WARRANTY

Item #

Description

LED Color

Power

Voltage Input

Background

Housing Color

### Ordering Information:

Item #	Description	LED Color	Power	Voltage Input	Background	Housing Color
UNIVRSC	Universal Surface and Recessed Mount Edgelit, Single Face	Red	BBUP	120/277	Clear Surface	Aluminum
UNIVRSCWH	Universal Surface and Recessed Mount Edgelit, Single Face	Red	BBUP	120/277	Clear Surface	White
UNIVRSM	Universal Surface and Recessed Mount Edgelit, Single Face	Red	BBUP	120/277	Mirror Surface	Aluminum
UNIVRDM	Universal Surface and Recessed Mount Edgelit, Double Face	Red	BBUP	120/277	Mirror Surface	Aluminum
UNIVGSC	Universal Surface and Recessed Mount Edgelit, Single Face	Green	BBUP	120/277	Clear Surface	Aluminum
UNIVGSCWH	Universal Surface and Recessed Mount Edgelit, Single Face	Green	BBUP	120/277	Clear Surface	White
UNIVGSM	Universal Surface and Recessed Mount Edgelit, Single Face	Green	BBUP	120/277	Mirror Surface	Aluminum
UNIVGDM	Universal Surface and Recessed Mount Edgelit, Double Face	Green	BBUP	120/277	Mirror Surface	Aluminum

For the most up-to-date specs, please visit [www.tcpi.com](http://www.tcpi.com)

TCP®

325 Campus Dr. | Aurora, Ohio 44202 | P: 1-800-324-1496 | F: 877.487.0516 | [tcpi.com](http://tcpi.com)

©TCP OCT 2014/54190