



# ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

## KT-LED11.5BR40-8XX

REPLACEMENT LAMP

### DESCRIPTION

11.5W BR40 Lamp | 2700–5000K | >80 CRI | Standard Flood



<b>LAMP TYPE:</b> BR40
<b>BASE TYPE:</b> E26 (Medium)
<b>WATTAGE:</b> 11.5W
<b>COLOR TEMPERATURE:</b> 2700–5000K
<b>COLOR RENDERING INDEX (CRI):</b> >80
<b>WARRANTY:</b> 3 Years
<b>RATED LIFE:</b> L70 (15,000 Hours)



### TYPICAL APPLICATIONS

- Recessed downlights
- Track lighting
- Surface-mount ceiling fixtures

### PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, uniform dimming
- Smooth, diffused lens for comfortable glare-free performance
- Durable plastic housing lowers the risk for breakage
- Long life minimizes replacement and maintenance costs
- Suitable for use in damp locations
- Operating temperature range –4°F/–20°C to 95°F/35°C
- PF >0.70
- ANSI compliant construction ensures fitment for intended applications
- UL Listed
- Meets Energy Star requirements
- Complies with Part 15 of FCC


### ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Beam Angle	Dimmable	Efficacy
KT-LED11.5BR40-827	BR40 bulb; Standard flood; Dimmable	2700K	120V	11.5W	75W/65W halogen	E26	940 lm	>80	110°	Yes	82 lm/W
KT-LED11.5BR40-830	BR40 bulb; Standard flood; Dimmable	3000K	120V	11.5W	75W/65W halogen	E26	940 lm	>80	110°	Yes	82 lm/W
KT-LED11.5BR40-835	BR40 bulb; Standard flood; Dimmable	3500K	120V	11.5W	75W/65W halogen	E26	940 lm	>80	110°	Yes	82 lm/W
KT-LED11.5BR40-840	BR40 bulb; Standard flood; Dimmable	4000K	120V	11.5W	75W/65W halogen	E26	940 lm	>80	110°	Yes	82 lm/W
KT-LED11.5BR40-850	BR40 bulb; Standard flood; Dimmable	5000K	120V	11.5W	75W/65W halogen	E26	940 lm	>80	110°	Yes	82 lm/W

## KT-LED11.5BR40-8XX

### REPLACEMENT LAMP

#### PHYSICAL CHARACTERISTICS

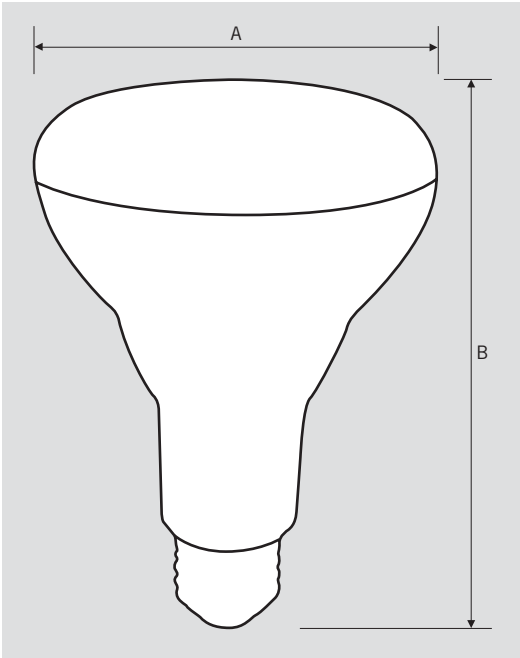

#### LAMP DIMENSIONS

A (Diameter)	4.49"
B (Length)	5.98"

BASE TYPE: E26 (Medium)

#### PACKAGING

Carton Quantity	6 pcs
Carton Dimensions	14.88" × 10.08" × 7.6"
Carton Weight	4.52 lbs

#### ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	EASY CODE	UPC
KT-LED11.5BR40-827	6 pcs	NUN-54	843654127088
KT-LED11.5BR40-830	6 pcs	WBW-85	843654127095
KT-LED11.5BR40-835	6 pcs	RXC-11	843654130309
KT-LED11.5BR40-840	6 pcs	PJJ-97	843654127101
KT-LED11.5BR40-850	6 pcs	WWW-33	843654127118

#### CATALOG NUMBER BREAKDOWN

## KT-LED11.5BR40-8XX

1 2 3 4 5 6

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 800 Series
- 6 Color Temperature