



# ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

## KT-LED13A19-0-8XX /G2

### 100W REPLACEMENT LAMP

#### DESCRIPTION

13W A19 Lamp | 2700–5000K | >80 CRI | Omni-Directional



<b>LAMP TYPE:</b> A19
<b>BASE TYPE:</b> E26 (Medium)
<b>WATTAGE:</b> 13W
<b>COLOR TEMPERATURE:</b> 2700–5000K
<b>COLOR RENDERING INDEX (CRI):</b> > 80
<b>WARRANTY:</b> 3 Years
<b>RATED LIFE:</b> L70 (25,000 Hours)



#### TYPICAL APPLICATIONS

- Table, Desk, and Floor Lamps
- Wall Sconces
- Surface Mount Ceiling Fixtures
- General Lighting
- Pendant Lights

#### PRODUCT FEATURES

- 80%+ energy savings and less heat generation vs legacy equivalents
- 25,000hr lifetime means fewer replacements and lower maintenance cost
- Smooth diffused lens for comfortable, glare free performance
- Durable plastic housing for lower risk of breakage
- ANSI compliant construction ensures fit for intended applications
- ETL listed
- Suitable for use in enclosed fixtures
- Suitable for dry and damp locations
- PF > 0.50
- Operating temperature range: 4°F/–20°C to 95°F/35°C
- Complies with FCC Part 15


#### ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Base Type	Input Voltage	Wattage	Equiv. Legacy Wattage	Lumens	CRI	Available CCT	Beam Angle	Dimmable	Efficacy
KT-LED13A19-0-827 /G2	E26	120V	13W	100W	1600	>80	2700K	220°	Yes	123 lm/W
KT-LED13A19-0-830 /G2	E26	120V	13W	100W	1600	>80	3000K	220°	Yes	123 lm/W
KT-LED13A19-0-835 /G2	E26	120V	13W	100W	1600	>80	3500K	220°	Yes	123 lm/W
KT-LED13A19-0-840 /G2	E26	120V	13W	100W	1600	>80	4000K	220°	Yes	123 lm/W
KT-LED13A19-0-850 /G2	E26	120V	13W	100W	1600	>80	5000K	220°	Yes	123 lm/W

## KT-LED13A19-O-8XX /G2

### 100W REPLACEMENT LAMP

#### PHYSICAL CHARACTERISTICS

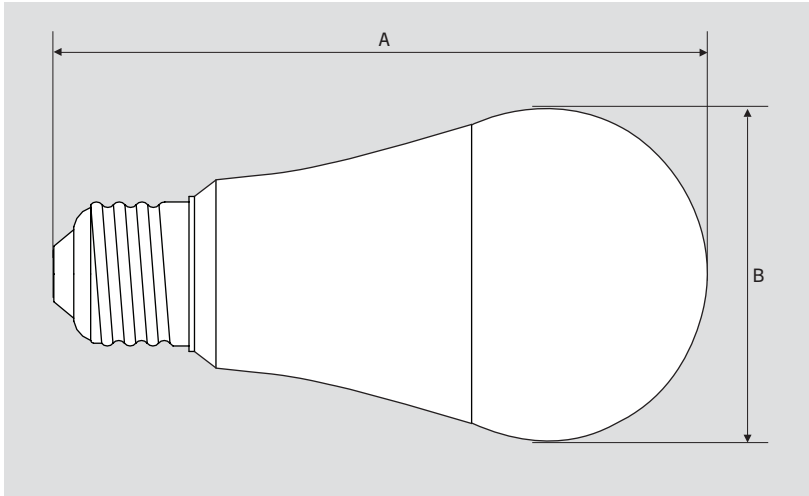

#### PACKAGING

Carton Quantity	60 pcs
Carton Dimensions	15.55" × 13.07" × 10"
Carton Weight	10.6 lbs

#### LAMP DIMENSIONS

A (Length)	2.36"
B (Diameter)	4.57"

BASE TYPE: E26 (Medium)

#### ORDERING INFORMATION

CATALOG NUMBER	CARTON QUANTITY	UPC	EASY CODE
KT-LED13A19-O-827 /G2	60 pcs	843654149950	CRJ-74
KT-LED13A19-O-830 /G2	60 pcs	843654149967	XTO-99
KT-LED13A19-O-835 /G2	60 pcs	843654149974	ZTT-01
KT-LED13A19-O-840 /G2	60 pcs	843654149981	DJF-36
KT-LED13A19-O-850 /G2	60 pcs	843654149998	HLK-14

#### CATALOG NUMBER BREAKDOWN

## KT-LED13A19-O-8XX /G2

1 2 3 4 5 6 7 8

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 80 CRI
- 7 Color Temperature
- 8 Second Generation