



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED15BR40-8XX

REPLACEMENT LAMP

DESCRIPTION

15W BR40 Lamp | 2700–5000K | >80 CRI | Standard Flood



RoHS Compliant

2YEAR WARRANTY

LAMP TYPE: BR40
BASE TYPE: E26 (Medium)
WATTAGE: 15W
COLOR TEMPERATURE: 2700–5000K
COLOR RENDERING INDEX (CRI): >80
WARRANTY: 2 Years
RATED LIFE: L70 (15,000 Hours)



TYPICAL APPLICATIONS

- Recessed Downlights
- Track Lighting
- Surface Mount Ceiling Fixtures

PRODUCT FEATURES

- Energy Efficient, 80%+ Energy Savings over Legacy Equivalents
- Lower Heat Generation than Legacy Equivalents
- PF >0.70
- Complies with Part 15 of FCC
- Durable Plastic housing lowers the risk for breakage
- Smooth diffused lens for comfortable glare free performance
- Smooth, uniform dimming
- Operating temperature range –4°F/–20°C to 95°F/35°C
- Long Life minimizes replacement and maintenance costs
- ANSI complaint construction ensures fitment for intended applications
- Meets Energy Star requirements
- UL Listed


ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Light Distribution	Dimmable	Efficacy
KT-LED15BR40-827	BR40 bulb. Standard flood, dimmable	2700K	120V	15W	90W/85W halogen	E26	1300	>80	110°	Yes	87 lm/W
KT-LED15BR40-830	BR40 bulb. Standard flood, dimmable	3000K	120V	15W	90W/85W halogen	E26	1300	>80	110°	Yes	87 lm/W
KT-LED15BR40-840	BR40 bulb. Standard flood, dimmable	4000K	120V	15W	90W/85W halogen	E26	1300	>80	110°	Yes	87 lm/W
KT-LED15BR40-850	BR40 bulb. Standard flood, dimmable	5000K	120V	15W	90W/85W halogen	E26	1300	>80	110°	Yes	87 lm/W

KT-LED15BR40-8XX

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

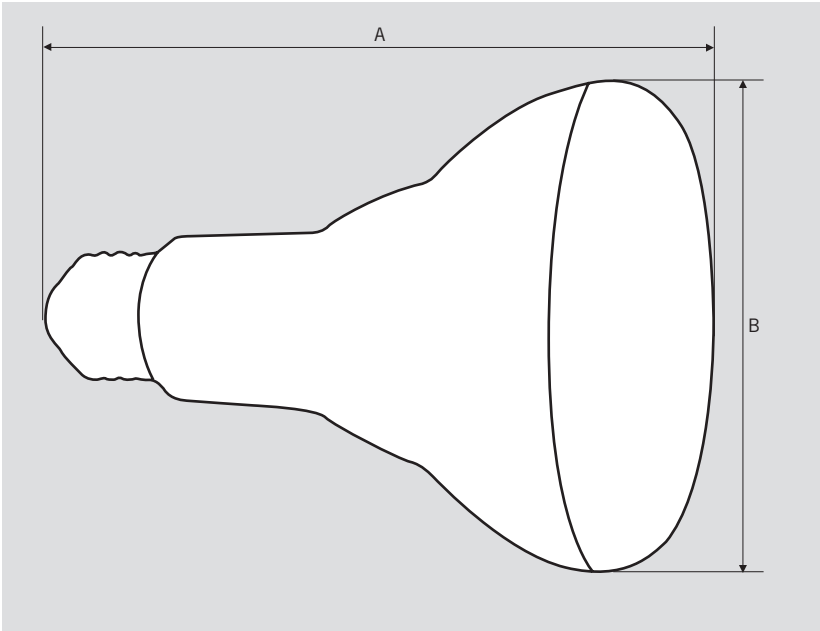

PACKAGING

Carton Quantity	6 pcs
Carton Dimensions	14.88" × 10.08" × 7.6"
Carton Weight	4.52 lbs

LAMP DIMENSIONS

A (Length)	6.22"
B (Diameter)	4.92"

BASE TYPE: E26 (Medium)

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ITEM STATUS
KT-LED15BR40-8XX	6 pcs	Active

CATALOG NUMBER BREAKDOWN

KT-LED15BR40-8XX

1 2 3 4 5 6

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 800 Series
- 6 Color Temperature