



KT-LEDXXA21-O-E26-8XX-DIM /G2

REPLACEMENT LAMP

DESCRIPTION

14W and 20W Commercial A21 Lamp | 2700–5000K | > 80 CRI | Omnidirectional



LAMP TYPE: Commercial A21
BASE TYPE: E26 (Medium)
WATTAGE: 14W, 20W
COLOR TEMPERATURE: 2700–5000K
COLOR RENDERING INDEX (CRI): > 80
WARRANTY: 5 Years



PRODUCT FEATURES

- Up to 75% energy saving compared to legacy equivalent lamps
- Can be used in base-up or base-down position
- THD < 20%
- PF > 0.90
- Operating temperature range –4°F/–20°C to 113°F/45°C; 95°F/35°C max for fully enclosed fixture
- Ideal for post top, bollards, and outdoor corridor lighting
- Suitable for dry and damp location
- Rated for open and enclosed fixtures
- Energy Star listed
- Meets UL 1993 standards

PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Lamp Wattage	CCT	Lumens	Efficacy	Input Voltage	Legacy Equivalent Wattage	Base Type	Dimmable*	Light Distribution	CRI
KT-LED14A21-O-E26-827-DIM /G2	14W	2700K	1760	126 lm/W	120-277V	100W incand.	E26	Yes	340°	> 80
KT-LED14A21-O-E26-830-DIM /G2	14W	3000K	1760	126 lm/W	120-277V	100W incand.	E26	Yes	340°	> 80
KT-LED14A21-O-E26-840-DIM /G2	14W	4000K	1760	126 lm/W	120-277V	100W incand.	E26	Yes	340°	> 80
KT-LED14A21-O-E26-850-DIM /G2	14W	5000K	1760	126 lm/W	120-277V	100W incand.	E26	Yes	340°	> 80
KT-LED20A21-O-E26-827-DIM /G2	20W	2700K	2600	130 lm/W	120-277V	150W incand.	E26	Yes	340°	> 80
KT-LED20A21-O-E26-830-DIM /G2	20W	3000K	2600	130 lm/W	120-277V	150W incand.	E26	Yes	340°	> 80
KT-LED20A21-O-E26-840-DIM /G2	20W	4000K	2600	130 lm/W	120-277V	150W incand.	E26	Yes	340°	> 80
KT-LED20A21-O-E26-850-DIM /G2	20W	5000K	2600	130 lm/W	120-277V	150W incand.	E26	Yes	340°	> 80


*Note: Lamp is TRIAC dimmable only at 120v.



KT-LEDXXA21-O-E26-8XX-DIM /G2 REPLACEMENT LAMP

PHOTOMETRIC SPECIFICATIONS FOR KT-LED14A21-O-E26-8XX-DIM /G2

POLAR CANDELA DISTRIBUTION

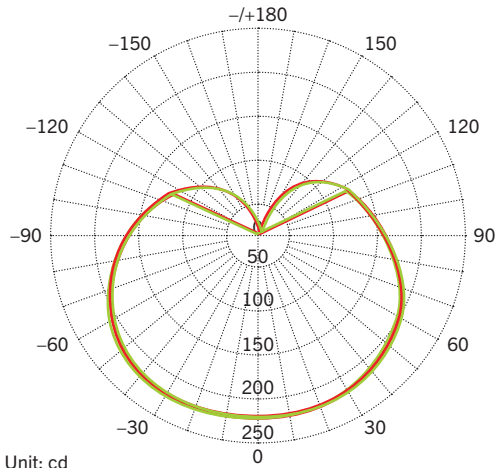


Unit: cd

— C0 / 180,230.2

— C90 / 270,230.0

SPECTRAL DISTRIBUTION

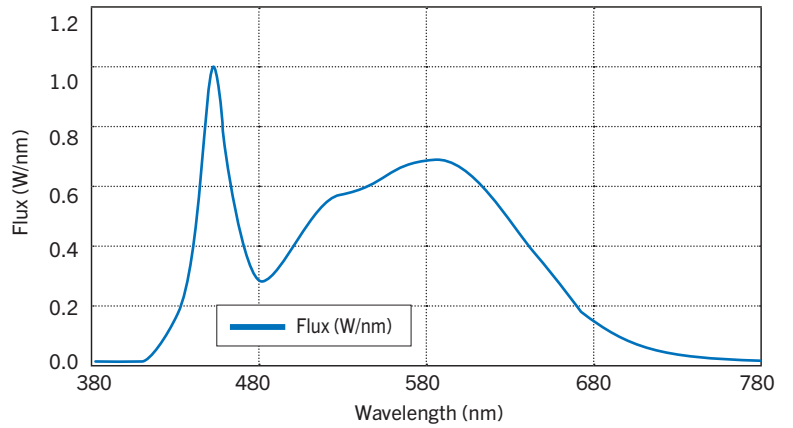


RATED LIFE

L70 (Hours)	25,000
-------------	--------

PHOTOMETRICS SPECIFICATIONS FOR KT-LED20A21-O-E26-8XX-DIM /G2

POLAR CANDELA DISTRIBUTION

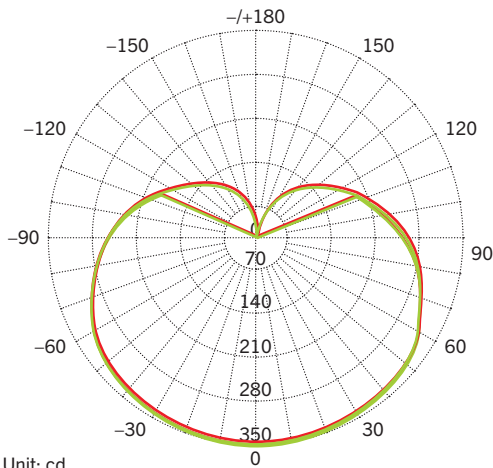


Unit: cd

— C0 / 180,225.9

— C90 / 270,226.1

SPECTRAL DISTRIBUTION

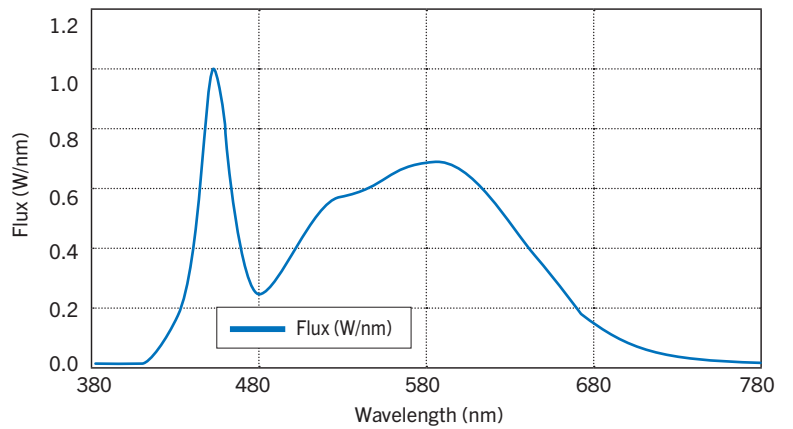

RATED LIFE


L70 (Hours)	25,000
-------------	--------



KT-LEDXXA21-O-E26-8XX-DIM /G2

REPLACEMENT LAMP

PHYSICAL SPECIFICATIONS

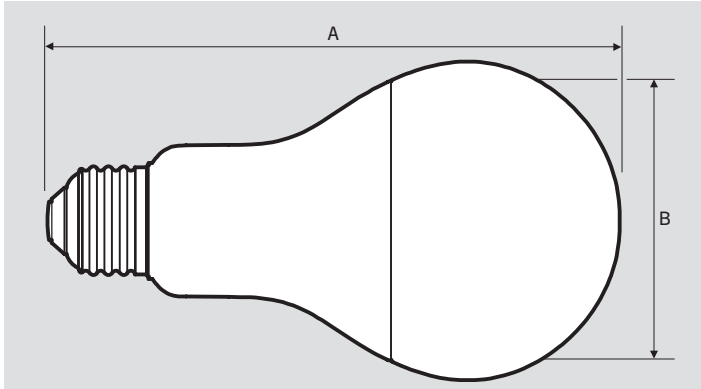

LAMP DIMENSIONS

A (Length)	5.43"
B (Diameter)	3.03"

BASE TYPE: E26 (Medium)

PACKAGING

Carton Quantity	50pcs
Carton Dimensions	15.75" x 15.75" x 11.57"
Carton Weight	18 lbs

ORDERING INFORMATION

CATALOG NUMBER	PACK QTY.	UPC	EASY CODE
KT-LED14A21-O-E26-827-DIM /G2	50 pcs	843654149424	FKE-01
KT-LED14A21-O-E26-830-DIM /G2	50 pcs	843654149431	QFD-17
KT-LED14A21-O-E26-840-DIM /G2	50 pcs	843654149448	JDO-52
KT-LED14A21-O-E26-850-DIM /G2	50 pcs	843654149455	GGs-16
KT-LED20A21-O-E26-827-DIM /G2	50 pcs	843654149462	JFF-72
KT-LED20A21-O-E26-830-DIM /G2	50 pcs	843654149479	LAY-44
KT-LED20A21-O-E26-840-DIM /G2	50 pcs	843654149486	BCL-90
KT-LED20A21-O-E26-850-DIM /G2	50 pcs	843654149493	BMX-20



KT-LEDXXA21-O-E26-8XX-DIM /G2

REPLACEMENT LAMP

CATALOG NUMBER BREAKDOWN

KT-LEDXXA21-O-E26-8XX-DIM /G2

1 2 3 4 5 6 7 8 9 10

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Style
- 5 OmniDirectional
- 6 Base Type
- 7 80 CRI
- 8 Color Temperature
- 9 Dimming
- 10 Second Generation