



# ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

## KT-LED6A19-O-8XX

### REPLACEMENT LAMP

#### DESCRIPTION

6W A19 Lamp | 2700–5000K | >80 CRI | Omni-Directional



RoHS Compliant

**2YEAR** WARRANTY

<b>LAMP TYPE:</b> A19
<b>BASE TYPE:</b> E26 (Medium)
<b>WATTAGE:</b> 6W
<b>COLOR TEMPERATURE:</b> 2700–5000K
<b>COLOR RENDERING INDEX (CRI):</b> >80
<b>WARRANTY:</b> 2 Years
<b>RATED LIFE:</b> L70 (15,000 Hours)



#### TYPICAL APPLICATIONS

- Table, Desk, and Floor Lamps
- Wall Sconces
- Surface Mount Ceiling Fixtures
- General Lighting
- Pendant Lights

#### PRODUCT FEATURES

- Energy Efficient, 80%+ Energy Savings over Legacy Equivalents
- Lower Heat Generation than Legacy Equivalents
- PF >0.90
- Complies with Part 15 of FCC
- ANSI complaint construction ensures fitment for intended applications
- UL enclosed rated, suitable for use in totally enclosed luminaires
- Operating temperature range –4°F/–20°C to 95°F/35°C
- Long Life minimizes replacement and maintenance costs
- Meets Energy Star requirements
- UL Listed
- Smooth diffused lens for comfortable glare free performance
- Durable Plastic housing lowers the risk for breakage
- Smooth, uniform dimming


#### ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Light Distribution	Dimmable	Efficacy
KT-LED6A19-O-827	A19 bulb. Omni-Directional, dimmable	2700K	120V	6W	40W halogen	E26	450	>80	230°	Yes	75 lm/W
KT-LED6A19-O-830	A19 bulb. Omni-Directional, dimmable	3000K	120V	6W	40W halogen	E26	450	>80	230°	Yes	75 lm/W
KT-LED6A19-O-850	A19 bulb. Omni-Directional, dimmable	5000K	120V	6W	40W halogen	E26	450	>80	230°	Yes	75 lm/W

## KT-LED6A19-0-8XX

### REPLACEMENT LAMP

#### PHYSICAL CHARACTERISTICS

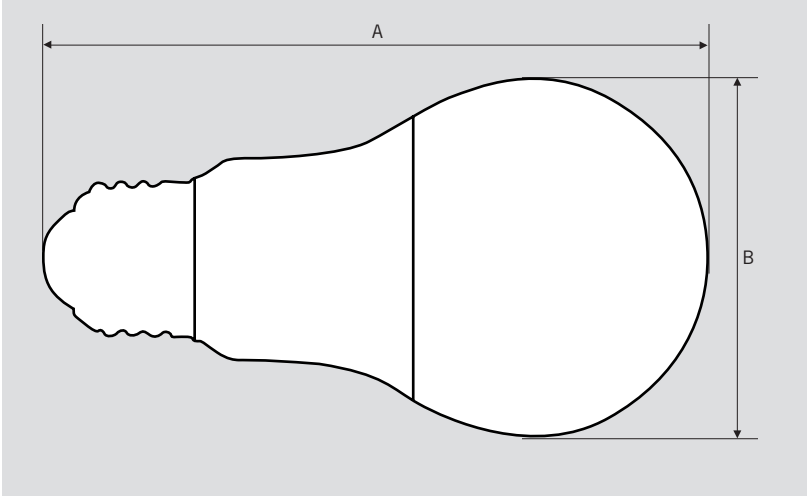

#### PACKAGING

Carton Quantity	60 pcs
Carton Dimensions	15.55" × 13.07" × 10"
Carton Weight	10.6 lbs

#### LAMP DIMENSIONS

A (Length)	4.33"
B (Diameter)	2.36"

BASE TYPE: E26 (Medium)

#### ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ITEM STATUS
KT-LED6A19-0-8XX	60 pcs	Active

#### CATALOG NUMBER BREAKDOWN

## KT-LED6A19-0-8XX

1 2 3 4 5 6 7

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 800 Series
- 7 Color Temperature