



# ESSENTIAL SERIES

## GENERAL PURPOSE LED BULBS

### KT-LED6A19-0-9XX

#### REPLACEMENT LAMP

#### DESCRIPTION

6W A19 Lamp | 2700–5000K | >90 CRI |  
Omni-Directional



**LAMP TYPE:** A19

**BASE TYPE:** E26 (Medium)

**WATTAGE:** 6W

**COLOR TEMPERATURE:** 2700–5000K

**COLOR RENDERING INDEX (CRI):** >90

**WARRANTY:** 3 Years

**RATED LIFE:** L70 (15,000 Hours)



#### TYPICAL APPLICATIONS

- Table, desk, and floor lamps
- Wall sconces
- Surface-mount ceiling fixtures
- General lighting
- Pendant lights

#### PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, uniform dimming
- Durable plastic housing lowers the risk for breakage
- Smooth, diffused lens for comfortable glare-free performance
- HiCRI LEDs offer enhanced color rendering vs. 80 CRI LEDs, providing ideal clarity, representation, uniformity of illuminated area/objects
- Long life minimizes replacement and maintenance costs
- Suitable for use in damp locations
- Operating temperature range –4°F/–20°C to 95°F/35°C
- PF >0.90
- ANSI compliant construction ensures fitment for intended applications
- UL Listed
- Meets Energy Star requirements
- Complies with Part 15 of FCC
- Title 20 compliant
- Title 24 JA8 compliant (excluding 5000K lamps)


#### ELECTRICAL AND PERFORMANCE SPECIFICATIONS

| Keystone Catalog Number | Description                          | Color Temp | Input Voltage | Rated Lamp Wattage | Legacy Equivalent Wattage | Base Type | Lumens | CRI | Beam Angle | Dimmable | Efficacy |
|-------------------------|--------------------------------------|------------|---------------|--------------------|---------------------------|-----------|--------|-----|------------|----------|----------|
| KT-LED6A19-0-927        | A19 bulb; Omni-directional; Dimmable | 2700K      | 120V          | 6W                 | 40W halogen               | E26       | 450 lm | >90 | 230°       | Yes      | 75 lm/W  |
| KT-LED6A19-0-930        | A19 bulb; Omni-directional; Dimmable | 3000K      | 120V          | 6W                 | 40W halogen               | E26       | 450 lm | >90 | 230°       | Yes      | 75 lm/W  |
| KT-LED6A19-0-950        | A19 bulb; Omni-directional; Dimmable | 5000K      | 120V          | 6W                 | 40W halogen               | E26       | 450 lm | >90 | 230°       | Yes      | 75 lm/W  |

# KT-LED6A19-0-9XX

## REPLACEMENT LAMP

### PHYSICAL CHARACTERISTICS

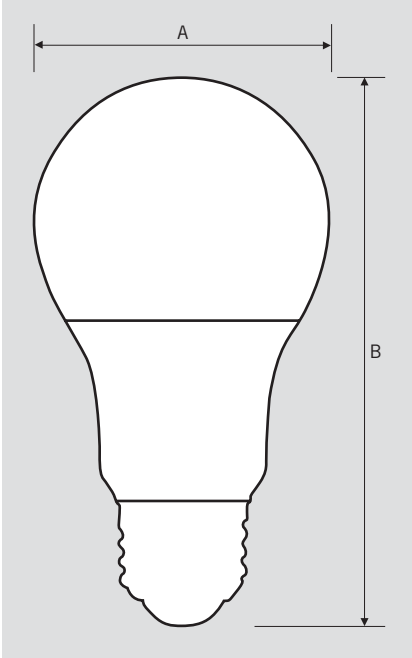

### LAMP DIMENSIONS

|              |       |
|--------------|-------|
| A (Diameter) | 2.36" |
| B (Length)   | 4.33" |

BASE TYPE: E26 (Medium)

### PACKAGING

|                   |                       |
|-------------------|-----------------------|
| Carton Quantity   | 60 pcs                |
| Carton Dimensions | 15.55" × 13.07" × 10" |
| Carton Weight     | 10.6 lbs              |

### ORDERING INFORMATION

| ORDER CODE       | CARTON QUANTITY | ITEM STATUS | EASY CODE | UPC          |
|------------------|-----------------|-------------|-----------|--------------|
| KT-LED6A19-0-927 | 60 pcs          | Active      | BTW-26    | 843654126319 |
| KT-LED6A19-0-930 | 60 pcs          | Active      | EWG-19    | 843654126326 |
| KT-LED6A19-0-950 | 60 pcs          | Active      | KFN-73    | 843654126333 |

### CATALOG NUMBER BREAKDOWN

# KT-LED6A19-0-9XX

1 2 3 4 5 6 7

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 900 Series
- 7 Color Temperature