



# KT-LED94P-H-8CSE-S

## 4-PIN LED LAMP



### DESCRIPTION

9.5W 4-Pin LED Lamp | Color Select 3000/3500/4000K |  $\geq 82$  CRI

<b>LAMP TYPE:</b> Compact
<b>BULB TYPE:</b> 4-Pin LED
<b>BASE TYPE:</b> G24q
<b>WATTAGE:</b> 9.5W
<b>SELECTABLE COLOR TEMPERATURE:</b> 3000/3500/4000K
<b>COLOR RENDERING INDEX (CRI):</b> $\geq 82$
<b>WARRANTY:</b> 5 Years



### PRODUCT FEATURES

- Replacement for conventional CFL 26W, 32W, or 42W G24q lamps
- Keystone Smart Drive technology: compatible with most legacy CFL ballasts
- Instant startup
- Frosted lens eliminates pixelation
- UL listed
- Save 50% on energy consumption when compared to a typical CFL lamp
- Environmentally friendly: no mercury used
- Operating temperature:  $-20^{\circ}\text{C}/-4^{\circ}\text{F}$  to  $45^{\circ}\text{C}/113^{\circ}\text{F}$
- Extend the useful life up to four times
- Install quickly with our plug and play design
- Not for use in enclosed fixtures

### OPERATING SPECIFICATIONS

#### ELECTRICAL CHARACTERISTICS

Input Voltage	Lamp Wattage	Power Factor	System Wattage
Ballast Dependent	9.5W	$>0.9$	11W

#### RATED LIFE

L70 (Hours)	50,000


#### PHOTOMETRIC CHARACTERISTICS

Color Temperature (CCT)	3000K*	3500K	4000K
<b>Luminous Flux</b>	960	1020	1050
<b>Color Rendering Index (CRI)</b>	$\geq 82$	$\geq 82$	$\geq 82$
<b>Bare Lamp Efficacy</b>	101	107	111

\*Preset to 3000K

### PHYSICAL CHARACTERISTICS

#### LAMP DIMENSIONS

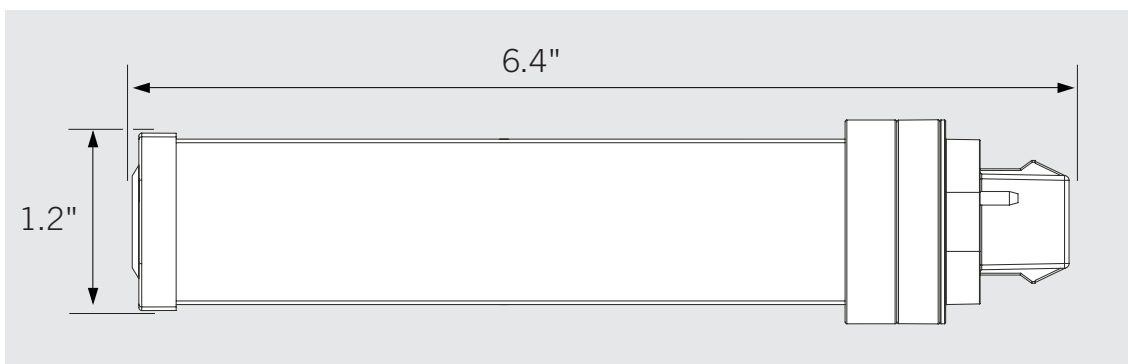



# KT-LED94P-H-8CSE-S

## 4-PIN LED LAMP

**ORDERING INFORMATION**

ORDER CODE	PACK QTY.	UPC	EASY CODE
KT-LED94P-H-8CSE-S	50	843654137711	WHY-96

**CATALOG NUMBER BREAKDOWN**

# KT-LED94P-H-8CSE-S

- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 4-Pin Lamp Type
- 5 Horizontal Orientation
- 6 80 CRI
- 7 Color Select
- 8 Color Select Designation
- 9 Smart Drive Series

**8 Color Select Designation**  
E 3000/3500/4000K