



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED9A19-O-8XX-ND-CS

REPLACEMENT LAMP

DESCRIPTION

9W A19 Lamp | 2700–5000K | ≤ 80 CRI | Omni-Directional



LAMP TYPE: A19

BASE TYPE: E26 (Medium)

WATTAGE: 9W

COLOR TEMPERATURE: 2700–5000K

COLOR RENDERING INDEX (CRI): ≤ 80

WARRANTY: 3 Years

RATED LIFE: L70 (11,000 Hours)

TYPICAL APPLICATIONS

- Table, Desk, and Floor Lamps
- Wall Sconces
- Surface Mount Ceiling Fixtures
- General Lighting
- Pendant Lights

PRODUCT FEATURES

- Energy Efficient, 80%+ Energy Savings over Legacy Equivalents
- Lower Heat Generation than Legacy Equivalents
- PF >0.50
- Complies with Part 15 of FCC
- Durable Plastic housing lowers the risk for breakage
- ANSI compliant construction ensures fitment for intended applications
- Operating temperature range $-4^{\circ}\text{F}/-20^{\circ}\text{C}$ to $95^{\circ}\text{F}/35^{\circ}\text{C}$
- Long Life minimizes replacement and maintenance costs
- UL Listed
- Smooth diffused lens for comfortable glare free performance
- Rated for open, recessed, and enclosed fixtures
- Non-dimming
- Suitable for damp locations


ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Beam Angle	Dimmable	Efficacy
KT-LED9A19-O-827-ND-CS	A19 bulb. Omni-Directional, non-dimmable	2700K	120V	9W	60W	E26	800	≤ 80	200°	No	89 lm/W
KT-LED9A19-O-830-ND-CS	A19 bulb. Omni-Directional, non-dimmable	3000K	120V	9W	60W	E26	800	≤ 80	200°	No	89 lm/W
KT-LED9A19-O-835-ND-CS	A19 bulb. Omni-Directional, non-dimmable	3500K	120V	9W	60W	E26	800	≤ 80	200°	No	89 lm/W
KT-LED9A19-O-840-ND-CS	A19 bulb. Omni-Directional, non-dimmable	4000K	120V	9W	60W	E26	800	≤ 80	200°	No	89 lm/W
KT-LED9A19-O-850-ND-CS	A19 bulb. Omni-Directional, non-dimmable	5000K	120V	9W	60W	E26	800	≤ 80	200°	No	89 lm/W

KT-LED9A19-O-8XX-ND-CS

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

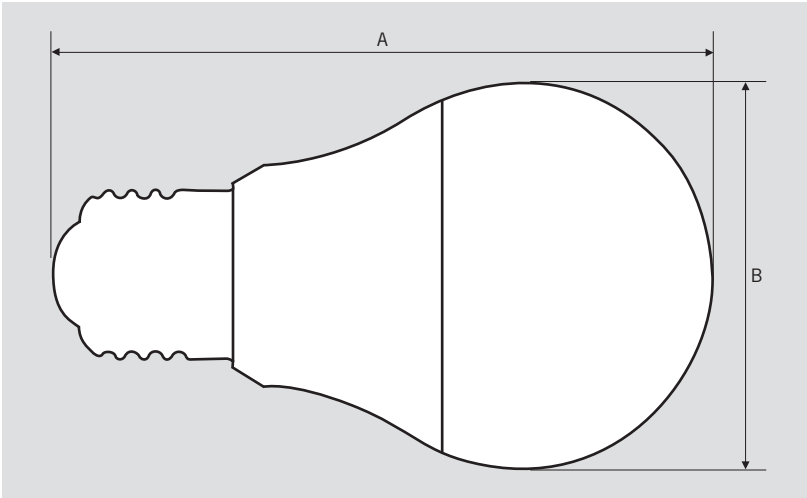

PACKAGING

Carton Quantity	60 pcs
Carton Dimensions	24.61" × 14.76" × 4.72"
Carton Weight	7.34 lbs

LAMP DIMENSIONS

A (Length)	3.94"
B (Diameter)	2.36"

BASE TYPE: E26 (Medium)

ORDERING INFORMATION

CATALOG NUMBER	CARTON QUANTITY	EASY CODE	UPC
KT-LED9A19-O-827-ND-CS	60 pcs	YEE-21	843654130040
KT-LED9A19-O-830-ND-CS	60 pcs	TSQ-57	843654130057
KT-LED9A19-O-835-ND-CS	60 pcs	UHU-72	843654130064
KT-LED9A19-O-840-ND-CS	60 pcs	QJU-13	843654130071
KT-LED9A19-O-850-ND-CS	60 pcs	YST-05	843654130088

CATALOG NUMBER BREAKDOWN

KT-LED9A19-O-8XX-ND-CS

1 2 3 4 5 6 7 8 9

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 800 Series
- 7 Color Temperature
- 8 Non Dimming
- 9 Contractor Series