



LP-2X4-60W-50K-DS
LP-2X4-60W-40K-DS
LP-2X4-60W-35K-DS
LP-2X4-60W-30K-DS
LP-2X4-60W-27K-DS

LED PANEL LIGHTS (2X4) 60W

Ideal for hotel, offices, retail outlets, restaurant, parking garages, storage room, conference room, education facilities and more.

ELECTRICAL SPECIFICATIONS:

- Voltage: 100-277VAC, 50/60Hz
- Wattage: 60W
- Current: 1500mA
- Power factor: >0.90
- Efficacy: 110LM/W, 105LM/W, 90LM/W
- THD: <15%

HOUSING SPECIFICATIONS:


- External driver mounted on top
- Earthquake hooks and suspension hooks pre-installed
- Operating temperature: -68°F ~ 104°F
- Lifespan: 50,000 Hrs.

CERTIFICATIONS: FC, UL



DIMENSIONS:

47.75"(L) x 23.75"(H) x 1.71"(D)

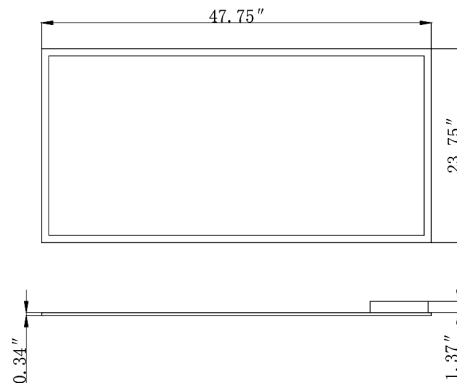

47.75" x 23.75" x 1.71"

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LP-2X4-60W-50K-DS	60W	100~277VAC	6600LM	5000K
LP-2X4-60W-40K-DS	60W	100~277VAC	6600LM	4000K
LP-2X4-60W-35K-DS	60W	100~277VAC	6300LM	3500K
LP-2X4-60W-30K-DS	60W	100~277VAC	5400LM	3000K
LP-2X4-60W-27K-DS	60W	100~277VAC	5400LM	2700K

LIGHTING SPECIFICATIONS:

- Dimming: 0~10V dimmable
- LED type: 4014SMD LM80
- No. of LED: 384
- Total lumens: 6600LM/6300LM/5400LM
- Color temperature: 5000K/4000K/3500K/2700K
- Color rendering index: >80
- Soft and wide light emitting
- No infrared rays, no ultraviolet radiation, no thermal effect
- No flickering, no humming, no RF interference

WARRANTY: 5 years

