



Accessorize your LFLED with a NEMA Type: 3H x 3V or 3H x 2V spot lens.

Color: Bronze

Weight: 0.3 lbs

<b>Project:</b>	<b>Type:</b>
<b>Prepared By:</b>	<b>Date:</b>

Driver Info		LED Info	
Type	Constant Current	Watts	0W
120V	N/A	Color Temp	N/A
208V	N/A	Color Accuracy	N/A
240V	N/A	L70 Lifespan	N/A Hours
277V	N/A	Lumens	N/A
Input Watts	N/A	Efficacy	N/A

**Technical Specifications**

**Compliance**

**UL Listed:**

Suitable for wet locations. Suitable for ground mounting.

**Construction**

**Lens:**

Microprismatic diffusion lens for smooth and even light distribution

**Housing:**

Precision die-cast aluminum

**Finish:**

Formulated for high durability and long-lasting color

**Optical**

**NEMA Type:**

Fixture has a NEMA Type 3H x 3V

**Other**

**Compatibility:**

Compatible with [LFLED5B](#).


**Patents:**

The design of the LSFLED is protected by patents pending in US, Canada, China, Taiwan and Mexico

**Buy American Act Compliance:**

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

**Dimensions**

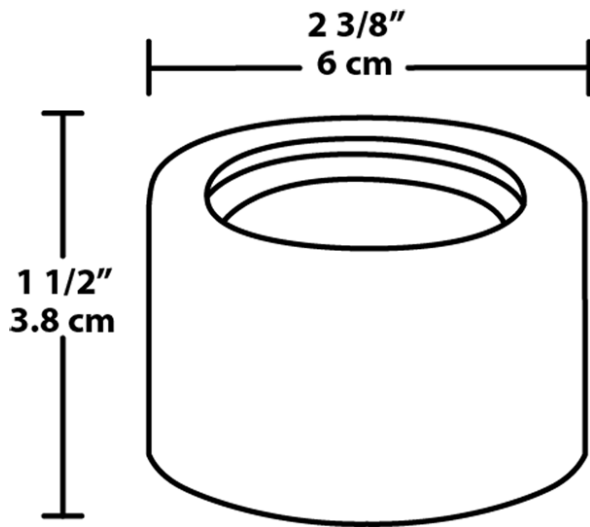

**Features**

- Microprismatic diffusion lens for smooth and even light distribution
- Precision die-cast aluminum housing
- 5-Year, No-Compromise Warranty