


LT Series
Recessed Baffle Canless LED Downlights

HALO

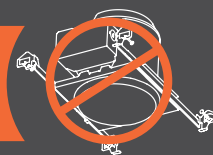

NO HOUSING REQUIRED
Repositionable driver j-box included




The LT Canless Series are all-purpose LED downlights designed to mount directly to ceilings – no housing required. Install into remodel or use canless mounting frames/plates for new construction applications. Flip the switch to select between 5 color temperatures from soft white (2700K) to daylight (5000K) and discover the perfect color temperature lighting for any project. Fixtures offer a safe, non-conductive dead-front baffle and a regressed diffuse flat lens for low-glare downlighting. In addition to matte white baffle fixtures, smooth splay decorative overlays can be ordered in paintable matte white and matte black finishes.

When you're looking for the ideal balance of features and affordability, LT Series fixtures are the perfect choice.

Product Features

- Round 3", 4", & 6" sizes available with baffle trims
- Smooth splay decorative overlays in paintable matte white or matte black (sold separately)
- No housing required - for remodel and new construction installations
- For new construction, use with canless mounting frames/plates
- Suitable for IC (insulation contact) or non-IC applications
- Matte white or matte black plastic non-conductive dead-front trim and regressed flat diffuse lens
- 5-Color Field-SeleCCTable™: 2700K, 3000K, 3500K, 4000K, 5000K; 90+ CRI
- Lumens: 3 in. – 580 lm; 4 in. – 740 lm, 6 in. – 835 lm (nominal)
- Dims to 10% (phase cut LE/TE); 120V input
- AIR-TITE, wet location-listed, IC-rated, and ENERGY STAR® certified
- 35,000 hrs of maintenance-free operation
- 5-year warranty

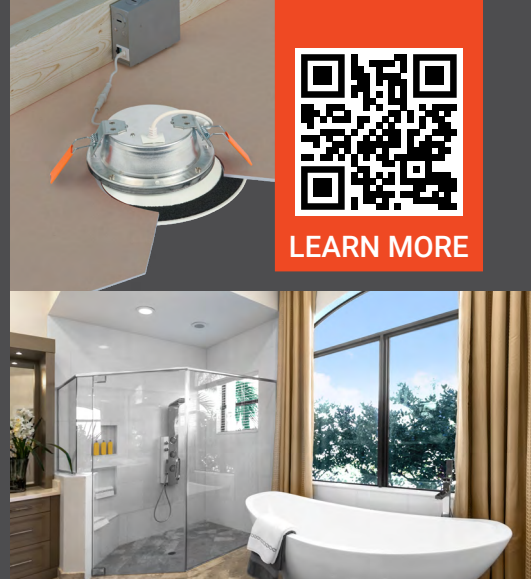

LEARN MORE

EASY CANLESS INSTALLATION

Mounts directly to ceiling



Complete HALO LTC 5CCT LED Ordering Table

Catalog Number	Description	Finish	Packaging	UPC	Accessories			
					Decorative Overlays	New Construction Mounting Frames	New Construction Smash Plate	Extension Cables
LTC305FS5B	3-inch LT Series Baffle Canless LED Downlight 580 lumens 90+ CRI, field selectable CCT: 2700K, 3000K, 3500K, 4000K, 5000K 120V 60Hz, LE & TE phase cut 10% dimming	Matte White	Plastic-free & Fully Recyclable	080083297047	LT30MW 3" Smooth Splay Paintable Matte White LT30MB 3" Smooth Splay Matte Black	HL3RSMF 3" Round/Square Mounting Frame		
LTC305FS5BMB		Matte Black		080083309382				
LTC406FS5B	4-inch LT Series Baffle Canless LED Downlight 740 lumens 90+ CRI, field selectable CCT: 2700K, 3000K, 3500K, 4000K, 5000K 120V 60Hz, LE & TE phase cut 10% dimming	Matte White	Plastic-free & Fully Recyclable	80083297061	LT40MW 4" Smooth Splay Paintable Matte White LT40MB 4" Smooth Splay Matte Black	MF4RC 4" Round Mounting Frame with 1/2" Drywall Collar HL4RSMF 4" Round/Square Mounting Frame	SP346RS 3"/4"/6" Round/Square Smash Plate	HLB06FSEC 6-ft. extension cable HLB12FSEC 12-ft. extension cable HLB20FSEC 20-ft. extension cable
LTC406FS5BMB		Matte Black		080083309405				
LTC608FS5B	6-inch LT Series Baffle Canless LED Downlight 835 lumens 90+ CRI, field selectable CCT: 2700K, 3000K, 3500K, 4000K, 5000K 120V 60Hz, LE & TE phase cut 10% dimming	Matte White	Plastic-free & Fully Recyclable	080083297085	LT60MW 6" Smooth Splay Paintable Matte White LT60MB 6" Smooth Splay Matte Black	MF6RC 6" Round Mounting Frame with 1/2" Drywall Collar HL6RSMF 6" Round/Square Mounting Frame (Included)		
LTC608FS5BMB		Matte Black		080083309429				



Refer to ENERGY STAR® Certified Products List. Can be used to comply with California Title 24 High Efficacy requirements. Certified to California Appliance Efficiency Database under JA8.
NOTE: Due to T20 changes as of July 1st 2019 consult factory for current catalog number and availability for T20 compliant products.



Cooper Lighting Solutions
1121 Highway 74 South
Peachtree City, GA 30269
P: 770-486-4800
cooperlighting.com

Canada Sales
5925 McLaughlin Road
Mississauga, Ontario L5R 1B8
P: 905-501-3000
F: 905-501-3172

© 2025 Cooper Lighting Solutions
All Rights Reserved
Publication No. BR51824325
July 2025

Product availability, specifications, and compliances are subject to change without notice.